



Long Barrel Aluminum Lug

T&B Catalog Number:

61130

UPC Number:

78621061130

Status:

I

Description:


Aluminum One-Hole Compact Size Equipment Lug, Long Barrel, Blind End, Max 35kV, 1/0 AWG Wire, 3/8 Bolt Size, Tin Plated, Die Code 45, Die Color Code Gold

Features

For use with aluminum cables only. Can be directly substituted for equipment mechanical lugs in most applications.

Electro Tin-Plated for Corrosion Resistance. Factory-filled with joint compound. Supplied with Neoprene insulating covers.

Cable Area Clearly Identified on Lug. Only 7 dies handle all 14 lug sizes.

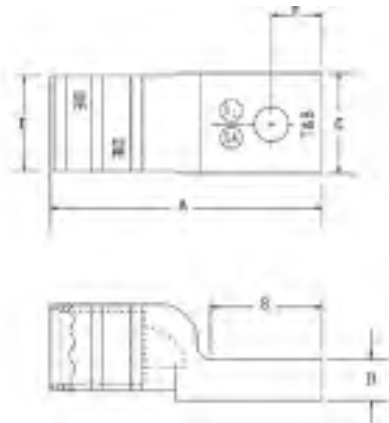

General

Style	Compact Size
Insulation Type	Neoprene
Material	Aluminum
Finish	Tin Plated
Wire Size	1/0 AWG
Aluminum Range Taking	#8-1/0
Strip Length (inches)	3/4
Number of Studs	1
Stud Size (inches)	3/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Gold
Die Code	45

Dimension Information

Strip Length (inches)	3/4
A (inches)	2
B (inches)	.83
C (inches)	.64
D (inches)	.2
E (inches)	.57
F (inches)	.38

Specifications

Temperature Rating	90°C
Voltage Rating	600V

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	7 lbs. per 100

Application Support

Overview Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

For range-taking capability, use TBM8750 or TBM8750M1Smart Tool.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com