


Workstation

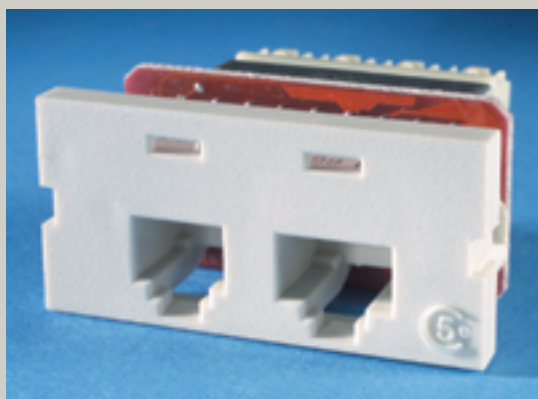

Part Number: OR-60950090

Description: Series II, two-port (1 RJ25C, 1 Category 5e T568B), 180°

Series II Two-Port Module provides one Category 5e T568B wired eight-position jack and one RJ25 six-position jack in a one unit footprint. Series II is a family of front removable snap-in modules that make moves, adds and changes easy and time saving. The rugged high strength construction of Series II makes it one of Ortronics most popular workstation choices

■ Specifications

Category Performance/ Application	Category 5e/UTP
Footprint	Series II
Wiring Scheme	T568 A/B
Color	Fog White
Number of Ports	2-port
Critical Size (No. Gangs)	1 unit
Labeling & Identification	YES
Height	.92" (23.37 mm)
Width	1.89" (48.01 mm)
Wire Gauge	22-26 AWG
UL Listing No.	E131600
UL Standard	UL 1863
CUL Standard	UL 1863
CUL Listing No.	E131600
FCC Standard	Part 68
Product Type or Accessory	Modular Jack

■ Construction

	Material	Finish/Plating
Plastic Series II Housing	High Impact Thermoplastic ABS 94V-0	
One array of six linear modular contacts and one array of eight linear modular contacts	Phosphor bronze	Nickel plating and a minimum of 50 micro inches of selective gold plating in contact area
IDC contacts, 110 D4	Phosphor bronze	Nickel plating and tin lead over plate
Printed circuit board	Two-sided FR-4 epoxy resin/glass base with solder mask	

■ Features

- Linear 110 paired punch down
- Front removable
- Rugged snap-in design
- Icon compatible

■ Benefits

- Faster than other termination methods
- Less intrusive access for adds, moves, changes
- Quick and easy
- Supports TIA/EIA 606 standard