


# Workstation

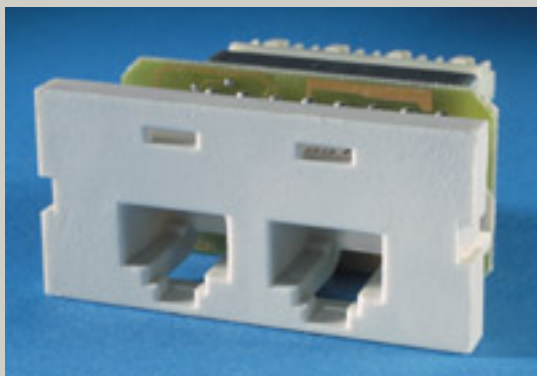

**Part Number:** OR-60900038

**Description:** Series II, two-port, USOC (RJ61X), 180°

Series II Module provides two RJ61X, eight-position USOC wired jacks in a one unit footprint. Series II is a family of front removable snap-in modules that make moves, adds and changes easy and time saving. The rugged high strength construction of Series II makes it one of Ortronics most popular workstation choices

## ■ Specifications

Category Performance/ Application	USOC eight-position
Footprint	Series II
Color	Fog White
Number of Ports	2-port
Critical Size (No. Gangs)	1 unit
Labeling & Identification	YES
Height	.92" (23.37 mm)
Width	1.90" (48.26 mm)
Depth	1.29" (32.77 mm)
UL Listing No.	E131600
UL Standard	UL 1863
CUL Standard	UL 1863
CUL Listing No.	E131600
FCC Standard	Part 68
Product Type or Accessory	Modular Jack

## ■ Construction

	Material	Finish/Plating
Plastic Series II Housing	High Impact Thermoplastic ABS 94V-0	
Two arrays of eight linear modular contacts	Phosphor bronze	Nickel plating and a minimum of 50 micro inches of selective gold plating in contact area
IDC contacts, 110 D4	Phosphor bronze	Nickel plating and tin lead over plate
Printed circuit board	Two-sided FR-4 epoxy resin/glass base with solder mask	

## ■ Features

- Linear 110 paired punch down
- Front removable
- Rugged snap-in design
- Icon compatible

## ■ Benefits

- Faster than other termination methods
- Less intrusive access for adds, moves, changes
- Quick and easy
- Supports TIA/EIA 606 standard



www.ortronics.com  
800-934-5432  
860-445-3900 (sales)  
860-405-2992 (fax)  
125 Eugene O'Neill Drive  
New London, CT 06320