


Racks

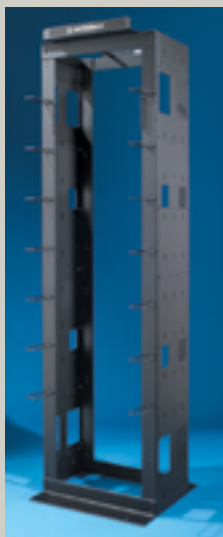

Part Number: OR-60400163

Description: Mighty Mo II Cable Management Rack
14" channel depth, 23.5" x 24" x 7', black

■ Specifications

Family	Mighty Mo II
Product	Mighty Mo II Cable Management Racks
Color	Black
Width	23.75" (603 mm)
Depth	24" (619 mm)
Height	86" (2.2 m)

■ Features

■ Benefits

■ Features

- 44 rack units front and rear; 7' height
- Rack provided with 28 vertical cable management rings and top trough
- Patented 14" channel
- Open channels top and bottom
- EIA hole pattern front and rear
- Can be assembled as a 19" or 23" rack
- Footprint 23.75" W x 16.50" D (when assembled as a 19" rack)
- Aluminum construction
- 24 cable support hook and loop type straps included with rack

■ Benefits

- High density racking system
- Allows efficient routing of patch and cross connect cables while ports and designation remain visible on p panels and equipment
- The 14" channel depth allows cross connect equipment to be mounted back to back, which doubles the wiring capacity
- Protects and conceals your horizontal cables like no other rack
- Supports split equipment shelves and heavy electronic devices
- Allows floor and ceiling access for the horizontal cables
- Power strips and other accessories can be mounted on the rear rail without using additional rack space
- No additional hardware required; no need to stock two sizes of racks
- Stays within a 2' square footprint
- High strength
- Manages horizontal cables in channel or use for additional patch cord management