


Cross-Connect Blocks / Accessories

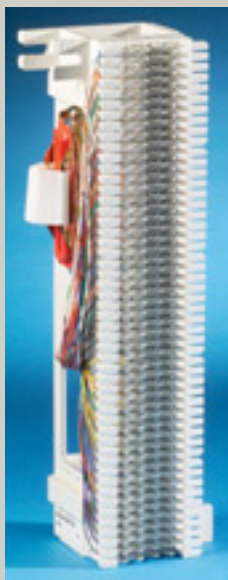

Part Number: OR-8050F66M150

Description: Modular 66 Connecting Block with 25-pair F Telco on left side

Modular 66M150 Connecting Block with 25-pair female telco connector prewired to the left side of block on 89D bracket top cable entry

■ Specifications

Performance Category	Voice
Pair Count	25
Width	2.84" (7.21mm)
Depth	2.71" (6.88mm)
Height	10.00" (25.40mm)
UL Listing No.	E131600
UL Standard	UL1863
CUL Listing No.	E131600
CUL Standard	UL1863

■ Construction

	Material	Finish/Plating
66M150 Block	Polyphenylene Oxide, Flame Retardant Thermoplastic	
570 Clips IDC Contact	Phosphor Bronze with Tin Lead Plating	
89D Bracket	Flame Retardant Thermoplastic	
Hold Down Strap	Hook and Loop	
25-pair Female Connector Housing	Polyphenylene	
25-pair Female Contacts	Copper with Gold over Nickel	
Strain Relief	Polyphenylene	

■ Features

- Prewired to 50-pin (RJ21) telco connectors
- Supports multiple tip and ring arrangements

■ Benefits

-
- Pretested and saves installation labor
- Allows field configuration for voice and data equipment
- Provides wall mount with cable pathway