

FDC® Unit Splice Housings

A LANscape® Solutions Product

Corning
Cable Systems

Applications


- Rack-mount, 19-in (48 cm) or 23-in (58 cm); wall-mount optional
- Transition splice between UL-listed and unlisted cable at building entrance or pigtail splicing when used in conjunction with FDC® Unit Connector Module Housings

Description


The Corning Cable Systems FDC-SMH-3 and FDC-SMH-5 Splice Housings provide storage and protection of fiber splices in individually accessible trays. The housings can be mated with other FDC Unit connector housings for pigtail splicing or can be used individually as a rack-mounted splice housing. The units accommodate a wide variety of Corning Cable Systems splice trays.

Features / Benefits

- Rack-mountable on standard 19-in (48 cm) or 23-in (58.5 cm) equipment rack (brackets included); wall-mountable option
- Single-cabinet construction
- Suitable for loose tube, tight-buffered and ribbon cables
- Slide-out shelf for easy tray access with improved slide mechanism
- Optional Universal Cable Clamp (FDC-UCC) for additional, enhanced cable strain-relief
- Hinged front and rear doors
- Front and rear door slide latches for easier access

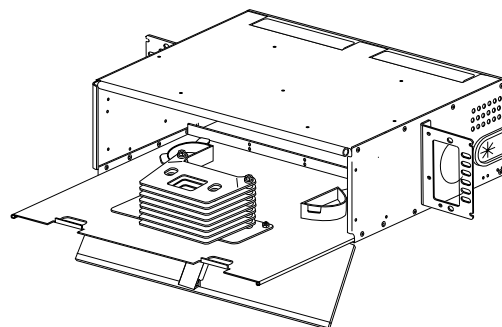

FDC-SMH-3 | Drawing CPC-220/5/47

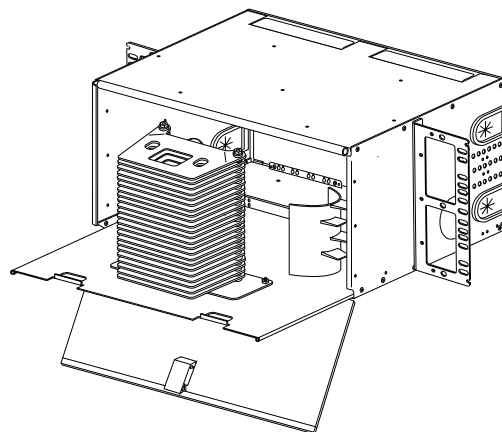

FDC-SMH-5 | Drawing CPC-220/5/48

Specifications and Ordering Information

Part Number	Description	Dimensions (H x W x D) cm (in)	Shipping Weight kg (lb)
FDC-SMH-3	Splice housing; accepts eight 0.2-in tall (Type 2R, 2S, 2M) Corning Cable Systems splice trays; 96-fiber capacity @ 12 splices per tray	13.3 x 43.2 x 28.0 (5.2 x 17.0 x 11.0)	5.8 (13.0)
FDC-SMH-3-F	Splice housing; accepts five 0.4-in tall (Type 4R, 4S, 4A) Corning Cable Systems splice trays; 60-fiber capacity @ 12 splices per tray	13.3 x 43.2 x 28.0 (5.2 x 17.0 x 11.0)	5.8 (13.0)
FDC-SMH-5	Splice housing; accepts 22 0.2-in tall (Type 2R, 2S, 2M) Corning Cable Systems splice trays; 264-fiber capacity @ 12 splices per tray	22.2 x 43.2 x 28.0 (8.7 x 17.0 x 11.0)	6.3 (14.0)
FDC-SMH-5-F	Splice housing; accepts 14 0.4-in tall (Type 4R, 4S, 4A) Corning Cable Systems splice trays; 168-fiber capacity @ 12 splices per tray	22.2 x 43.2 x 28.0 (8.7 x 17.0 x 11.0)	6.3 (14.0)

Note: For higher splice capacity, use 24-fiber splice trays. Splice trays must be ordered separately.

Accessories

FD5-WALLBKT	Wall-Mounting Kit for 5.25-in tall housings
FDC-CMH-WALLBKT	Wall-Mounting Kit for 8.75-in tall housings
FDC-FLSHMNT-SM	Flush-Mounting Kit for 5.25-in tall housings
FDC-FLSHMNT-LG	Flush-Mounting Kit for 8.75-in tall housings
FDC-FRTDR-MT-L	Front Door with lock kit, metal door, for 8.75-in tall housings
FD5-FRTDR-MT-L	Front Door with lock kit, metal door, for 5.25-in tall housings

Corning Cable Systems LLC • PO Box 489 • Hickory, NC 28603-0489 USA

1-800-743-2675 • FAX: +1-828-901-5973 • International: +1-828-901-5000 • <http://www.corning.com/cablesystems>

Corning Cable Systems reserves the right to improve, enhance and modify the features and specifications of Corning Cable Systems' products without prior notification. LANscape and FDC are registered trademarks of Corning Cable Systems Brands, Inc. Discovering Beyond Imagination is a trademark of Corning Incorporated. All other trademarks are the properties of their respective owners. Corning Cable Systems is ISO 9001 certified. © 1999, 2003 Corning Cable Systems. All rights reserved. Published in the USA. LAN-302-EN / June 2003 / pdf