
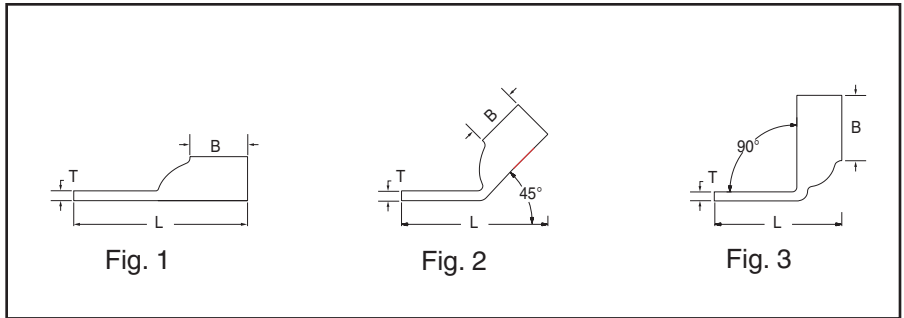


ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL

TYPES YA-L, YA-L-TC

COPPER COMPRESSION TERMINAL

UL Listed 90° C,
600 Volts to 35 KV ◆

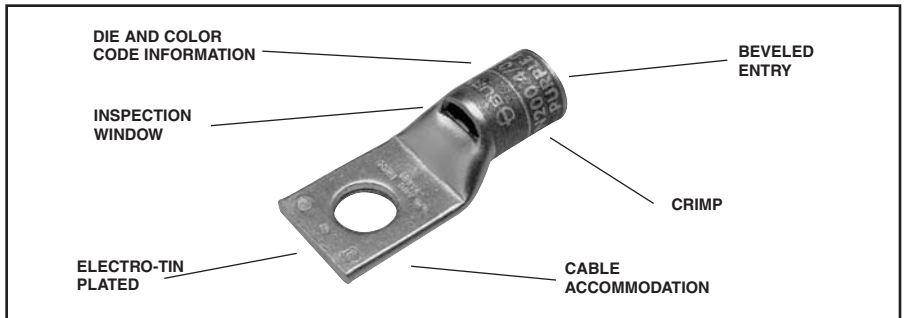

C-11

Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions			Dieless (# of crimps)	▲ Installation Tooling					Wire Strip Length									
		*** AWG	MM²			(B)	(T)	(L)		Mechanical MD6, OUR840, MD7-34R	Hydraulic		Color Code	Die Index										
											BCT500HS, Y500CTHS	Y35, Y39, Y750, Y46*, PAT750												
YAV10-45-BOX	2	#14-#10 STR	6	8-10	.38"	.405"	.058"	.92"	Y8MRB-1 (1)	-	-	-	-		7/16"									
YAV10-BOX	1					.405"	.058"	1.02"																
YAV10R-BOX	3					.375"	.058"	.77"																
YAV10R3-BOX	3					1/4"	.47"	.405"								.047"	.83"							
YAV10T2-BOX	1					5/16"	.53"	.38"								.047"	1.12"							
YAV10T3-45-BOX	2	#12-#10 SOL		1/4"	.47"	.405"	.047"	1.10"																
YAV10T3-BOX	1					1/4"	.47"	.405"								.047"	1.10"							
YAV10T4-BOX	1					3/8"	.56"	.38"								.047"	1.18"							
YA8CL1-BOX	1	#8 AWG	† 10	1/4"	.44"	.44"	.08"	1.26"	Y1MR (1) Y8MRB-1 (1) Y2MR (1) MY29-3 (1) MY29-11 (1) MRC840 (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W8CVT (1) W8CRT (1) X8CRT (1)	W8CVT (1) W8CRT (1) X8CRT (1)	U8CRT (1)	Red	49	7/16"									
YA8CL1-45	2							1.24"																
YA8CL1-90	3							.80"																
YA8CL2-BOX	1					5/16"	.52"	.44"								.06"	1.38"							
YA8CL2-45	2																1.34"							
YA8CL2-90	3			37/24		3/8"	.58"	.44"								.06"	1.51"							
YA8CL3-BOX	1																1.45"							
YA8CL3-45	2																1.04"							
YA8CL3-90	3																1.76"							
YA8CL4-BOX	1																1.67"							
YA8CL4-45	2	#6 SOLID		1/2"	.71"	.44"	.05"	1.28"																
YA8CL4-90	3							1.16"																
YA8CL-BOX	1							8-10								.41"	.44"	.08"	1.16"					
YA8CL-45	2																							
YA8CL-90	3																		.71"					
YA6CL-BOX	1	#6 AWG		1/4"	.45"	.54"	.08"	1.18"	Y1MR (1) MY29-3 (1) MY29-11 (1) MRC840 (1) Y2MR (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W5CVT (1) W5CRT (1) X5CRT (1) X8CART (1)	W5CVT (1) W5CRT (1) X5CRT (1) X8CART (1)	U5CRT (1)	Blue	7	7/8"									
YA6CL-45	2																1.08"							
YA6CL-90	3																.81"							
YA6CL1-BOX	1							8-10								.41"	.54"	.09"	.99"					
YA6CL1-45	2																		.41"	.54"	.09"	.89"		
YA6CL1-90	3			.42"	.54"	.09"	.72"																	
YA6CL3-BOX	1			5/16"	.52"	.54"	.07"	1.24"																
YA6CL3-45	2							1.06"																
YA6CL3-90	3							.93"																

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
 ** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.
 *** The MM² conductor sizes listed are the recommendations for Class 2 conductor.


† The MM² conductor size listed is for both Class 2 and Class 5 conductor.
 ▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.
 Note: All dimensions shown are for reference only.

BURNDY® Products FCI

Compression

ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL (Continued)

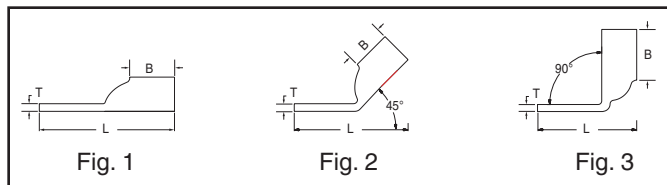

C-12


Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions			Dieless (# of crimps)	▲ Installation Tooling						Wire Strip Length			
		AWG	*** MM ²			(B)	(T)	(L)		Mechanical MD6, OUR840, MD7-34R	Hydraulic		Color						
											BCT500HS, Y500CTHS	Y35, Y39, Y750, Y46*, PAT750	Color Code	Die Index					
YA6CL4-BOX	1	#6 AWG		3/8"	.63"	.54"	.06"	1.28"	Y1MR (1) MY29-3 (1) MY29-11 (1) MRC840 (1) Y2MR (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W5CVT (1) W5CRT (1) X5CRT (1) X8CART (1)	W5CVT (1) W5CRT (1) X5CRT (1) X8CART (1)	U5CRT (1) UBCABT (1)	Blue	7	7/8"				
YA6CL4-45	2							1.17"											
YA6CL4-90	3							1.05"											
YA6CL6-BOX	1			1/2"	.75"	.54"	.12"	1.60"											
YA6CL6-45	2							1.54"											
YA6CL6-90	3							1.30"											
YA5CL-BOX	1	#5 AWG		1/4"	.44"	.81"	.07"	1.65"	Y1MR (2) MY29-3 (1) MY29-11 (1) MRC840 (1) Y2MR (2) Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W5CVT (1) W5CRT (1) X5CRT (1)	W5CVT (1) W5CRT (1) X5CRT (1)	U5CRT (1)	Blue	7	7/8"				
YA5CL-45	2							1.31"											
YA5CL-90	3							.81"											
YA4CL-BOX	1	#4 AWG		1/4"	.50"	.81"	.09"	1.74"		W4CVT (1) W4CRT (1) X4CRT (1)	W4CVT (1) W4CRT (1) X4CRT (1)					U4CRT (1) U6CABT (1)	Gray	8	7/8"
YA4CL-45	2							1.44"											
YA4CL-90	3							.84"											
YA4CL1-BOX	1			8-10	.50"	.81"	.09"	1.58"											
YA4CL1-45	2							1.28"											
YA4CL1-90	3							.75"											
YA4CL3-BOX	1			5/16"	.58"	.81"	.08"	1.92"											
YA4CL3-45	2							1.68"											
YA4CL3-90	3							.96"											
YA4CL4-BOX	1			3/8"	.58"	.81"	.08"	1.92"											
YA4CL4-45	2							1.68"											
YA4CL4-90	3							1.08"											
YA4CL6-BOX	1			1/2"	.71"	.81"	.06"	2.20"											
YA4CL6-45	2							2.02"											
YA4CL6-90	3							1.32"											
YA3CL	1	# 3 STR # 2 SOL	25	5/16"	.55"	.88"	.09"	1.88"	Y1MR (2) MY29-3 (1) MY29-11 (1) MRC840 (1) Y2MR (2) Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W3CRT (1)	W3CRT (1)	U3CRT (1)	White	9	15/16"				
YA3CL-45	2							1.76"											
YA3CL-90	3							.98"											
YA2CL2-BOX	1	#2 AWG	35	1/4"	.61"	.88"	.11"	1.88"	W2CVT (1) W2CRT (1) X2CRT (1)	W2CVT (1) W2CRT (1) X2CRT (1)	U2CRT (1)	Brown	10	15/16"					
YA2CL2-45	2							1.55"											
YA2CL2-90	3							.89"											
YA2CL-BOX	1			5/16"	.61"	.88"	.11"	1.93"											
YA2CL-45	2							1.62"											
YA2CL-90	3							1.01"											
YA2CL4-BOX	1			3/8"	.61"	.88"	.11"	2.06"											
YA2CL4-45	2							1.74"											
YA2CL4-90	3							1.14"											
YA2CL6-BOX	1			1/2"	.73"	.88"	.09"	2.32"											
YA2CL6-45	2							2.17"											
YA2CL6-90	3							1.37"											
YA1CL2	1	#1 AWG	50	1/4"	.68"	.88"	.10"	1.81"	Y1MR (2) MY29-3 (1) MY29-11 (1) MRC840 (1) Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W1CVT (1) W1CRT-1 (1) X1CRT-1 (1)	W1CVT (1) W1CRT-1 (1) X1CRT-1 (1)	U1CRT-1 (1) U4CABT (1)	Green	11	15/16"				
YA1CL2-45	2							1.70"											
YA1CL2-90	3							.91"											
YA1CL-BOX	1			5/16"	.68"	.88"	.01"	1.94"											
YA1CL-45	2							1.82"											
YA1CL-90	3							1.03"											
YA1CL4-BOX	1			3/8"	.68"	.88"	.10"	2.06"											
YA1CL4-45	2							1.95"											
YA1CL4-90	3							1.16"											
YA1CL6-BOX	1			1/2"	.73"	.88"	.09"	2.37"											
YA1CL6-45	2							2.22"											
YA1CL6-90	3							1.40"											

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.

*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.
▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.
Note: All dimensions shown are for reference only.

ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL (Continued)

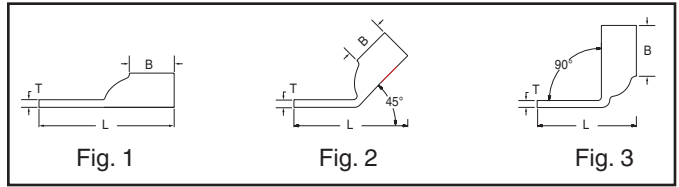

Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions			Dieless (# of crimps)	▲ Installation Tooling						Wire Strip Length
		AWG	*** MM²			Figure Dimensions		Mechanical MD6, OUR840, MD7-34R		Hydraulic BCT500HS, Y500CTHS		Y35, Y39, Y750, Y46*, PAT750	Color Code	Die Index		
						(B)	(T)			(L)						
YA25L2-BOX	1	1/0 AWG		1/4"	.75"	.88"	.12"	1.84"	W25VT (2) W25RT (2) X25RT (2)	W25VT (2) W25RT (2) X25RT (2)	U25RT (1) U2CABT (1)	Pink	12	15/16"		
YA25L2-45	2							1.76"								
YA25L2-90	3							.94"								
YA25L4-BOX	1			3/8"	.75"	.88"	.12"	2.09"								
YA25L4-45	2							2.01"								
YA25L4-90	3							1.19"								
YA25L6-BOX	1			1/2"	.75"	.88"	.12"	2.34"								
YA25L6-45	2							2.26"								
YA25L6-90	3							1.44"								
YA25L-BOX	1			5/16"	.75"	.88"	.12"	1.96"								
YA25L-45	2							1.88"								
YA25L-90	3							1.07"								
YA26L2-BOX	1	2/0 AWG	70	1/4"	.83"	.94"	.12"	1.94"	MY29-3 (1) MY29-11 (1) MRC840 (2) Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W26VT (2) W26RT (2) X26RT (2)	W26VT (2) W26RT (2) X26RT (2)	U26RT (1)	Black	13	1"	
YA26L2-45	2							1.78"								
YA26L2-90	3							.96"								
YA26L3-BOX	1			5/16"	.83"	.94"	.12"	2.06"								
YA26L3-45	2							1.91"								
YA26L3-90	3							1.09"								
YA26L-BOX	1			3/8"	.83"	.94"	.12"	2.19"								
YA26L-45	2							2.03"								
YA26L-90	3							1.21"								
YA26L60	1			3/4"	.96"	.94"	.12"	2.96"								
YA26L60-45	2							2.77"								
YA26L60-90	3			1/2"	.83"	.94"	.12"	1.89"								
YA26L6-BOX	1							2.44"								
YA26L6-45	2			5/8"	.88"	.94"	.11"	2.28"								
YA26L6-90	3							1.46"								
YA26L7-BOX	1			5/16"	.62"	.94"	.13"	2.69"								
YA26L7-45	2							2.50"								
YA26L7-90	3							1.71"								
YA26LNT516	1							2.62"								
YA27L2-BOX	1	3/0 AWG		1/4"	1.00"	1.00"	.13"	2.04"	MY29-3 (1) MY29-11 (1) MRC840 (2) Y644HS (1) Y81KFT (2) Y81KFTMBH (2) PAT81KFT-18V (2)	W27VT (2) W27RT (2) X27RT (3)	W27VT (2) W27RT (2) X27RT (3)	U27RT (1)	Orange	14	1-1/16"	
YA27L2-45	2							1.91"								
YA27L2-90	3							.99"								
YA27L3	1			5/16"	.91"	1.00"	.13"	2.16"								
YA27L3-45	2							2.03"								
YA27L3-90	3			3/8"	.91"	1.00"	.13"	1.12"								
YA27L4-BOX	1							2.29"								
YA27L4-45	2			1/2"	.91"	1.00"	.13"	1.91"								
YA27L4-90	3							.99"								
YA27L-BOX	1			3/8"	.76"	1.00"	.12"	2.54"								
YA27L-45	2							2.41"								
YA27L-90	3							1.49"								
YA27LNT38																
YA28L17-BOX	1	4/0 AWG		5/8"	1.02"	.88"	.14"	2.71"	W28VT (2) W28RT (2) X28RT (3)	W28VT (2) W28RT (2) X28RT (3)	U28RT (1)	Purple	15	1-1/8"		
YA28L17-45	2							2.64"								
YA28L17-90	3							1.79"								
YA28L2-BOX	1			1/4"	1.02"	.88"	.14"	1.96"								
YA28L2-45	2							1.89"								

C-13

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.


*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.
▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.
Note: All dimensions shown are for reference only.

BURNDY® Products FCI

Compression

ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL (Continued)

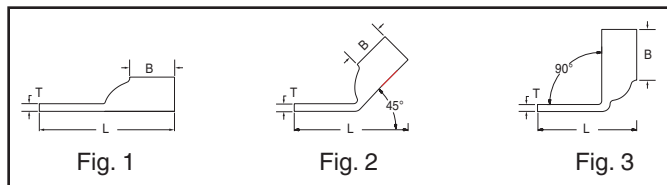

C-14


Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions		Dieless (# of crimps)	▲ Installation Tooling						Wire Strip Length
		AWG	*** MM ²			(B)	(T)		(L)	Mechanical MD6, OUR840, MD7-34R	Hydraulic		Color Code	Die Index	
											BCT500HS, Y500CTHS	Y35, Y39, Y750, Y46*, PAT750			
YA28L2-90	3	4/0 AWG		1/4"	1.02"	.88"	.14"	MY29-3 (1) MY29-11 (1) MRC840 (2) Y644HS (1) Y81KFT (2) Y81KFTMBH (2) PAT81KFT-18V (2)	W28VT (2) W28RT (2) X28RT (2)	W28VT (2) W28RT (2) X28RT (3)	U28RT (1)	Purple	15	1-1/8"	
YA28L3	1			5/16"	1.02"	.88"	.14"								2.08"
YA28L3-45	2														2.01"
YA28L3-90	3			3/8"	1.02"	.88"	.14"								1.16"
YA28L4-BOX	1														2.21"
YA28L4-45	2														2.14"
YA28L4-90	3														1.29"
YA28L56	1			3/4"	1.05"	.88"	.13"								2.90"
YA28L56-45	2														2.81"
YA28L56-90	3			1/2"	1.02"	.88"	.14"								1.97"
YA28L-BOX	1														2.46"
YA28L-45	2			3/8"	.76"	.88"	.16"								2.39"
YA28L-90	3														1.54"
YA28LNT38	1	250 kcmil		3/8"	.76"	.88"	.16"	2.79"	MY29-3 (1) MY29-11 (1) Y644HS (1) Y81KFT (2) Y81KFTMBH (2) PAT81KFT-18V (2)	W29VT (2) X29RT (4)	W29VT (2) W29RT (2) X29RT (4)	U29RT (1)	Yellow	16	1-1/8"
YA29L2	1			1/4"	1.11"	1.06"	.16"	2.17"							
YA29L2-45	2							2.07"							
YA29L2-90	3			3/8"	1.11"	1.06"	.16"	1.08"							
YA29L4	1							2.42"							
YA29L4-45	2							2.32"							
YA29L4-90	3							1.33"							
YA29L7	1			5/16"	1.11"	1.06"	.16"	2.30"							
YA29L7-45	2							2.20"							
YA29L7-90	3			7/8"	1.11"	1.06"	.14"	1.20"							
YA29LTC78	1							3.36"							
YA29LTC78-45	2			3/8"	.96"	1.06"	.16"	3.23"							
YA29LTC78-90	3							2.26"							
YA29LNT38		300 kcmil	150	3/8"	.96"	1.06"	.16"	2.96"	Y644HS (1) Y81KFT (2) Y81KFTMBH (2) PAT81KFT-18V (2)	W30VT (2)	W30VT (2) W30RT (2)	U30RT (2) U28ART (2)	White	17	1-1/16"
YA29L-BOX	1			1/2"	1.11"	1.06"	.16"	2.67"							
YA29L-45	2							5/16"							
YA29L-90	3			1.58"											
YA30L	1			2.69"											
YA30L-45	2			2.60"											
YA30L-90	3			3/8"	1.20"	1.03"	.16"	1.61"							
YA30L1	1							2.31"							
YA30L1-45	2							2.22"							
YA30L1-90	3							1.24"							
YA30L24	1			7/8"	1.20"	1.03"	.16"	2.44"							
YA30L24-45	2							2.35"							
YA30L24-90	3							1.36"							
YA30L27	1			3/4"	1.20"	1.03"	.16"	3.37"							
YA30L27-45	2							3.29"							
YA30L27-90	3							2.30"							
YA30L28	1			5/8"	1.20"	1.03"	.16"	3.12"							
YA30L7	1							2.94"							
YA30L7-45	2							2.85"							
YA30L7-90	3			350 kcmil	185	1/2"	1.29"	1.06"							
YA31L	1								2.75"						
YA31L-45	2								2.75"						
YA31L-90	3								1.65"						
									W31VT (2)	W31VT (2) W31RT (2)	U31RT (2) U29ART (2)	Red	18	1-3/16"	

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.

*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.
▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.
Note: All dimensions shown are for reference only.

ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL (Continued)

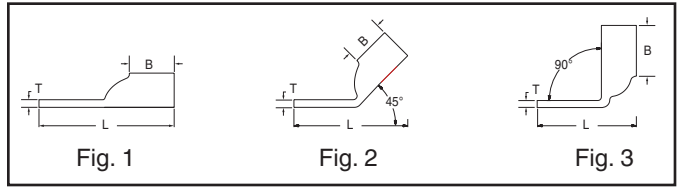

Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions			Dieless (# of crimps)	▲ Installation Tooling					Wire Strip Length
		AWG	*** MM²			Figure Dimensions				Mechanical MD6, OUR840, MD7-34R	Hydraulic		Color Code	Die Index	
						(B)	(T)	(L)			Y35, Y39, Y750, Y46*, PAT750				
YA31L11	1	350 kcmil	185	3/8"	1.29"	1.06"	.18"	2.50"	Y644HS (1) Y81KFT (2) Y81KFTMBH (2) PAT81KFT-18V (2)	W31VT (2)	W31VT (2) W31RT (2)	U31RT (2) U29ART (2)	Red	18	1-3/16"
YA31L11-45	2							2.42"							
YA31L11-90	3							1.40"							
YA31L36	1			7/8"	1.29"	1.06"	.18"	4.02"							
YA31L36-45	2							4.02"							
YA31L36-90	3							3.94"							
YA31L7	1			5/8"	1.29"	1.06"	.18"	3.00"							
YA31L7-45	2							3.00"							
YA31L7-90	3			3/8"	96"	1.06"	.18"	1.90"							
YA31LNT38								3.37"							
YA32L	1	400 kcmil		5/8"	1.38"	1.19"	.19"	3.18"		W32VT (2)	W32VT (2) W32RT (2)	U32RT (2) U30ART (2)	Blue	19	1-1/4"
YA32L-45	2							3.08"							
YA32L-90	3							1.95"							
YA32L1	1			1/2"	1.40"	1.19"	.19"	2.93"							
YA32L1-45	2							2.83"							
YA32L1-90	3							1.70"							
YA32L14	1			3/8"	1.38"	1.19"	.19"	2.68"							
YA32L14-45	2							2.58"							
YA32L14-90	3							1.45"							
YA32LTC78	1			7/8"	1.40"	1.19"	.19"	3.62"							
YA32LTC78-45	2							3.52"							
YA32LTC78-90	3							2.38"							
YA33L	1	450 kcmil		5/8"	1.48"	1.50"	.21"	3.57"		W33VT (2)	W33VT (2) W33RT (2)	U33RT (2)	Gray	326	1-9/16"
YA33L-45	2							3.30"							
YA33L-90	3							2.00"							
YA34L	1	500 kcmil	240	5/8"	1.55"	1.27"	.23"	3.37"		W34VT (2)	W34VT (2) W34RT (2)	U34RT (2) U31ART (2)	Brown	20	1-7/16"
YA34L-45	2							3.30"							
YA34L-90	3							2.03"							
YA34L20	1			1"	1.55"	1.27"	.23"	4.05"							
YA34L20-45	2							3.99"							
YA34L20-90	3							2.72"							
YA34L37	1			3/8"	1.55"	1.27"	.23"	2.87"							
YA34L37-45	2							2.80"							
YA34L37-90	3							1.53"							
YA34L6	1			1/2"	1.55"	1.27"	.23"	3.12"							
YA34L6-45	2							3.05"							
YA34L6-90	3							1.78"							
YA34L8	1			3/4"	1.55"	1.27"	.23"	3.55"							
YA34L8-45	2							3.49"							
YA34L8-90	3							2.22"							
YA34L9	1			7/8"	1.55"	1.27"	.23"	3.80"							
YA34L9-45	2							3.74"							
YA34L9-90	3							2.47"							
YA35L	1	550 kcmil		5/8"	1.65"	1.69"	.25"	3.81"		-	-	U35RT (2)	Yellow	21	1-3/4"
YA35L-45	2							3.67"							
YA35L-90	3							2.08"							
YA36L11	1	600 kcmil	300	1/2"	1.74"	1.38"	.27"	3.29"		-	-	U36RT (2)	Green	22	1-3/4"
YA36L	1							3.72"							
YA36L-45	2			5/8"	1.74"	1.38"	.27"	3.51"							
YA36L-90	3							2.11"							


C-15

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.

*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.
▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.
Note: All dimensions shown are for reference only.

ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL (Continued)

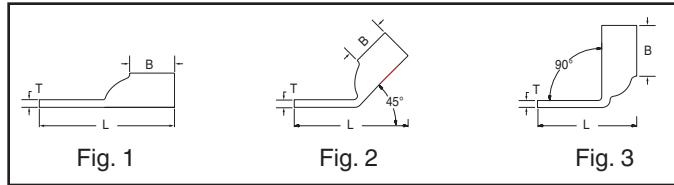

C-16

Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions			▲ Installation Tooling						Wire Strip Length
		AWG	MM²			(B)	(T)	(L)	Dieless (# of crimps)	Mechanical MD6, OUR840, MD7-34R	Hydraulic BCT500HS, Y500CTHS	Y35, Y39, Y750, Y46*, PAT750	Color Code	Die Index	
YA36LTC78	1	600 kcmil	300	7/8"	1.74"	1.38"	.27"	3.97"	Y644HS (1) Y81KFT (2) Y81KFTMBH (2)	-	-	U36RT (2) U32ART (2)	Green	22	1-3/4"
YA36LTC78-45	2							3.95"							
YA36LTC78-90	3							2.55"							
YA37L	1	650 kcmil		5/8"	1.80"	1.39"	.27"	3.57"	Y644HS (1) Y81KFT (3) Y81KFTMBH (3) PAT81KFT-18V (3)	-	-	U37RT (2)	Orange	23	1-15/16"
YA37L-45	2							3.55"							
YA37L-90	3							2.14"							
YA37L1	1	700 kcmil		5/8"	1.84"	1.45"	.27"	3.76"				U38RT (2)	Pink	400	1-15/16"
YA38L	1							3.66"							
YA38L-90	2							3.60"							
YA38L-45	3	750 kcmil		5/8"	1.91"	1.42"	.27"	2.15"				U39RT (2) P39RT (2) **	Black	24	1-15/16"
YA39L	1							3.67"							
YA39L-45	2							3.61"							
YA39L-90	3							2.17"							
YA39L2	1			7/8"	1.91"	1.42"	.27"	4.10"							
YA39L2-45	2							4.05"							
YA39L2-90	3							2.61"							
YA39L9	1			1-1/4"	1.91"	1.42"	.27"	4.85"							
YA39L9-45	2							4.80"							
YA39L9-90	3							3.36"							
YA39LNT38				3/8"	1.12"	1.42"	.27"	4.70"							
YA39L6	1							3.41"							
YA39L6-45	2			1/2"	1.91"	1.42"	.27"	3.36"							
YA39L6-90	3							1.92"							
YA40L	1	800 kcmil	400	5/8"	1.98"	1.42"	.30"	3.81"	Y644HS (1) Y81KFT (3) Y81KFTMBH (3) PAT81KFT-18V (3) Y644MBH (1) PAT644-18V (1)	-	-	P40RT(3) **	Orange	25	1-15/16"
YA40L-45	2							3.69"							
YA40L-90	3							2.21"							
YA41L	1	850 kcmil		5/8"	2.01"	1.88"	.31"	4.15"				-	Gold	26	1-15/16"
YA41L-45	2							4.03"							
YA41L-90	3							2.23"							
YA44L	1	1000 kcmil	500	5/8"	2.19"	1.65"	.33"	4.04"				P44RT(3) **	White	27	1-15/16"
YA44L-45	2							4.01"							
YA44L-90	3							2.32"							
YA44L2	1			1/2"	2.49"	1.65"	.33"	3.98"							
YA44L23	1							4.73"							
YA-45L	1	1250 kcmil		3/4"	2.46"	2.00"	.38"	4.68"				P45RT(3) **	Yellow	29	2-1/16"
YA-45L-45	2							4.64"							
YA-45L-90	3							2.62"							
YA-453L	1	1300 kcmil		3/4"	2.53"	2.00"	.39"	4.71"	-	-	-	-	Orange	30	2-1/16"
YA-453L-45	2							4.68"							
YA-453L-90	3							2.65"							
YA46L	1	1500 kcmil		3/4"	2.69"	2.00"	.40"	4.78"				P46RT (3) **	Green	31	2-1/16"
YA46L-45	2							4.75"							
YA46L-90	3							2.71"							
YA47L	1	1750 kcmil		3/4"	2.90"	2.19"	.42"	5.05"				-	Gray	33	2-1/4"
YA47L-45	2							5.00"							
YA47L-90	3							2.79"							
YA48L	1	2000 kcmil		3/4"	3.10"	2.25"	.46"	5.19"				-	Brown	34	2-1/4"
YA48L-45	2							5.19"							
YA48L-90	3							2.89"							

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.

*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.
▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.
Note: All dimensions shown are for reference only.