

# Basket Trays

Cablofil

## Cable Trays

Anixter No	Vendor No	Description
<b>CABLE TRAY 30MM HIGH</b>		
542506	000011	Cable tray CF 30/50 EZ, length 3m
542507	000021	Cable tray CF 30/100 EZ, length 3m
542508	000031	Cable tray CF 30/150 EZ, length 3m
542509	000041	Cable tray CF 30/200 EZ, length 3m
542510	000051	Cable tray CF 30/300 EZ, length 3m
<b>CABLE TRAY 54MM HIGH</b>		
542511	000061	Cable tray CF 54/50 EZ, length 3m
542512	000071	Cable tray CF 54/100 EZ, length 3m
542513	000081	Cable tray CF 54/150 EZ, length 3m
542514	000091	Cable tray CF 54/200 EZ, length 3m
542515	000101	Cable tray CF 54/300 EZ, length 3m
542516	000201	Cable tray CF 54/400 EZ, length 3m
542517	000251	Cable tray CF 54/450 EZ, length 3m
542518	000301	Cable tray CF 54/500 EZ, length 3m
542519	000401	Cable tray CF 54/600 EZ, length 3m




 

## Cable Tray Installation

Anixter No	Vendor No	Description
<b>CUTTER FOR TABLE TRAY</b>		
542654	559507	COUPFILGM, cutter installation tool




1  
2  
3  
4  
5  
6  
7  
8  
9  
10  
11  
12  
13  
14  
15  
16  
17  
18  
19

**Couplers**

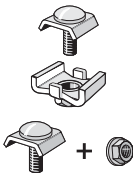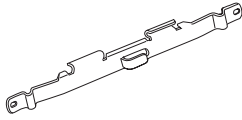

Anixter No	Vendor No	Description
<b>EDNR COUPLER</b>		
542659	558241	EDNR EZ, coupler without nuts and bolts, for fast assembly
<b>FASLOCK BEND COUPLER</b>		
310171	558340	FASLOCK S, GS quick bend coupler, fixing without nuts and bolts, for cable trays from 100 to 200mm wide, pack of 25
278758	558320	FASLOCK XL, GS quick bend coupler, fixing without nuts and bolts, for cable trays from 300 to 600mm wide, pack of 25
<b>COUPLER KITS WITH BOLTS AND NUTS</b>		
542657	558071	KITASSVS, coupling kit, including CE25VS and CE30ES EZ, pack of 50
542658	558061	KITFIXVS, fixing kit, including CE25VS and EEC6 EZ

**Dividers & Covers**

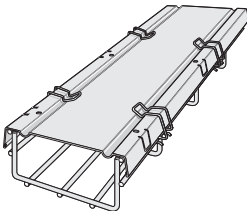


Anixter No	Vendor No	Description
<b>DIVIDERS</b>		
542585	923010	Divider strip COT 30 GS, 30mm high
542586	923020	Divider strip COT 50 GS, 50mm high
<b>COVERS</b>		
542577	629050	Cover CVN 50 GS
542579	629150	Cover CVN 150 GS
542580	629200	Cover CVN 200 GS
542581	629300	Cover CVN 300 GS
542582	629400	Cover CVN 400 GS
542583	629500	Cover CVN 500 GS

## Basket Trays

Cablofil

## Wall Mounting Brackets

Anixter No	Vendor No	Description
<b>UC50 LIGHT DUTY WALLMOUNT BRACKET</b>		
542741	586040	UC50, light duty bracket for mounting trays of 50mm wide. CF30/50 and CF54/50, GS
<b>CM50XL LIGHT DUTY WALLMOUNT BRACKET</b>		
543294	586130	CM50XL, light duty bracket for wallmount attachment of CF30/50, CF30/100, CF54/50 and CF54/100
<b>CSN WALLMOUNT BRACKETS</b> FAS – Fast Assembling System (no screws).		
542726	556100	Bracket CSN 100 GS
542728	556110	Bracket CSN 150 GS
542729	556120	Bracket CSN 200 GS
542730	556130	Bracket CSN 300 GS
<b>CSNC WALLMOUNT BRACKETS</b> FAS – Fast Assembling System (no screws).		
542660	556300	Bracket CSNC 100 GS
542662	556320	Bracket CSNC 200 GS
542663	556330	Bracket CSNC 300 GS
<b>CU UNIVERSAL WALLMOUNT BRACKETS</b> FAS – Fast Assembling System (no screws).		
542731	557400	Universal bracket CU 50 GS, 107mm long
542734	557410	Universal bracket CU 100 GS, 157mm long
542736	557430	Universal bracket CU 200 GS, 257mm long
542737	557440	Universal bracket CU 300 GS, 357mm long
542739	557450	Universal bracket CU 400 GS, 457mm long
542740	557460	Universal bracket CU 500 GS, 557mm long
<b>RCSN RAIL WALLMOUNT BRACKETS</b> FAS – Fast Assembling System (no screws).		
345651	013150	RAIL RCSN 150 GS, threaded rods and nuts ordered separately
542749	013200	RAIL RCSN 200 GS, threaded rods and nuts ordered separately
542750	013300	RAIL RCSN 300 GS, threaded rods and nuts ordered separately
542751	013400	RAIL RCSN 400 GS, threaded rods and nuts ordered separately
542752	013500	RAIL RCSN 500 GS, threaded rods and nuts ordered separately
542761	013030	RAIL RCSN 3000 GS, threaded rods and nuts ordered separately

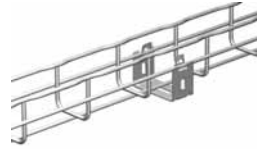

1  
2  
3  
4  
5  
6  
7  
8  
9  
10  
11  
12  
13  
14  
15  
16  
17  
18  
19

**Ceiling Mounting (Suspended)**





Anixter No	Vendor No	Description
<b>MFM MULTIFIX</b>		
542646	585140	MFM 100, MULTIFIX metal plate, 100mm long, GS, threaded rod and nuts ordered separately
542647	585150	MFM 150, MULTIFIX metal plate, 150mm long, GS, threaded rod and nuts ordered separately
<b>SAS SUSPENSION, SINGLE HANGER BRACKET</b>		
543293	586031	SAS suspension single hanger bracket, threaded rod and nuts ordered separately
<b>CE40 SUSPENSION</b>		
542656	558051	CE40 coupling accessory, 2 pieces needed, pack of 25, threaded rod and nuts ordered separately
<b>SCF CENTRAL HANGER FAS – Fast Assembling System (no screws).</b>		
542664	586200	Central hanger SCF 200 GS, 194mm long, threaded rod and nuts ordered separately
542665	586300	Central hanger SCF 300 GS, 294mm long, threaded rod and nuts ordered separately
<b>AS SUSPENSION BRACKETS FAS – Fast Assembling System (no screws).</b>		
542666	586010	AS suspension brackets, threaded rods and nuts ordered separately
<b>RCSN RAIL SUSPENSION APPLICATION</b>		
542749	013200	RAIL RCSN 200 GS, threaded rods and nuts ordered separately
542750	013300	RAIL RCSN 300 GS, threaded rods and nuts ordered separately
542751	013400	RAIL RCSN 400 GS, threaded rods and nuts ordered separately
542752	013500	RAIL RCSN 500 GS, threaded rods and nuts ordered separately
542761	013030	RAIL RCSN 3000 GS, threaded rods and nuts ordered separately
Note: Order RCSN 100mm extra than width of tray. For example, if using CF54300, order RCSN 400.		
<b>UNDER FLOOR MOUNTING</b>		
542747	559220	UFC clamp, for attaching brackets to floor pedestal (underfloor system), contains U bolt, 2 nuts and support plate. Pedestal not included
542746	586080	Higher support R55 GS

## Basket Trays

Cablofil

## Accessories

Anixter No	Vendor No	Description
<b>SUBD JUNCTION BOX MOUNTING PLATE</b>		
542650	585120	SUBD, universal junction box support, GS543294
<b>SBDN CONDUIT MOUNTING PLATE</b>		
324300	585410	SBDN mounting plate
<b>EARTHING (GROUNDING)</b>		
324299	585090	SBU, earth terminal support, GS
542651	585050	SB, earth terminal support
542652	585080	SCMT, earth cable support hook, pack of 100
542653	585067	Grounding lug, copper
<b>EARTHING (GROUNDING) GRIFEQUIP</b>		
310172	585327	GRIFEQUIP, grounding clamp
<b>MFPOLYA MULTIFIX PVC PLATE</b>		
542648	585145	MFPOLYA, multifix plate, polyamide
<b>CABLE EXIT PLATE</b>		
542645	585160	DEV 100, protector for cable exiting and entering tray
<b>FAS ROLLER</b>		
542638	011100	FAS Roller, cable pulling tool, box including 6 rollers
<b>IDENTIFICATION CLIPS</b>		
542639	559147	Coloured identification clip, orange
542640	559157	Coloured identification clip, yellow
542641	559167	Coloured identification clip, green
542643	559177	Coloured identification clip, blue
542642	559197	Coloured identification clip, grey

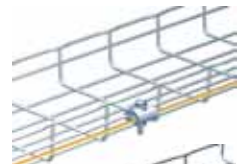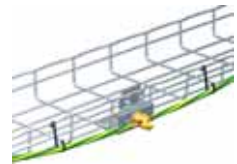

Accessories Continued



Anixter No	Vendor No	Description
<b>THREADED RODS</b>		
542671	801701	TF 6 threaded rod, EZ, 1000mm long, M6
542672	018001	TF 8 threaded rod, EZ, 1000mm long, M8
<b>THREADED SLEEVE</b>		
542762	801741	MF6 x 20 threaded sleeve, diameter 6mm, 20mm long, pack of 50
542763	801751	MF8 x 20 threaded sleeve, diameter 8mm, 20mm long, pack of 50
<b>PROFILE END CAP PVC</b>		
542644	559605	EPVCSN, end cap PVC to protect bracket end (GSN, RCSN etc)
<b>SCREWS, NUTS AND WASHERS</b>		
542669	801201	EEC 6 nut, EZ, M6, pack of 100
278702	801211	EEC 8 nut, EZ, M8, pack of 100
543291	801611	HM 8 nut, EZ, M8, pack of 100
542668	801511	M8 washers EZ, pack of 100
284584	558081	KITASSTR, standard coupling kit for cable tray, pack of 50, contains CE25, CE30 and BTRCC 6 x 20 (including EEC6)

1  
2  
3  
4  
5  
6  
7  
8  
9  
10  
11  
12  
13  
14  
15  
16  
17  
18  
19