


## Loaded Enclosures

### 1U (1.75-inch) MT-RJ Jack Rack Mount Patch Enclosure

**PART NUMBER 1206704-4**

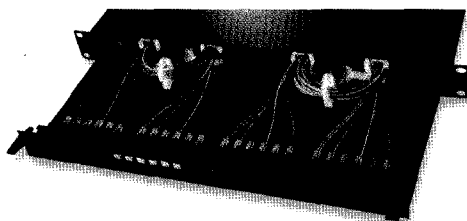


#### Fiber Densities

Insert Type	Fiber Density (max)	Duplex Port Density (max)
2-Fiber MT-RJ Jacks	48	24

#### Product Facts

- ▣ 1U (1.75") 48-Fiber Rack Mount Enclosure high-density solution
- ▣ Loaded with housings for MT-RJ Patch Panel Jacks
- ▣ Holds up to twenty-four (standard or secure) MT-RJ Patch Panel Jacks or MT-RJ Pigtail Jack Cable Assemblies (each purchased separately, see pages 220)
- ▣ Slide and tilt drawer
- ▣ Quick release front panel
- ▣ Cable strain relief and management rings included
- ▣ Forward, flush or recessed mounting
- ▣ Fit standard TIA 19" racks
- ▣ Accepts icons for identification (see page 283)

### 1U (1.75-inch) SC and ST Rack Mount Patch Enclosures

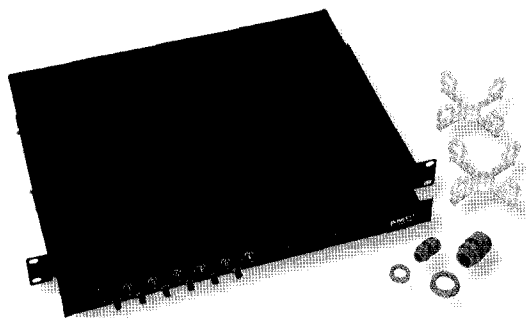

#### Product Facts

- ▣ Enclosures pre-loaded with SC or ST Adapters
- ▣ Slide and tilt drawer
- ▣ Quick release front panel
- ▣ Cable strain relief and management rings included
- ▣ Forward, flush or recessed mounting
- ▣ Fit standard TIA 19" racks
- ▣ Each enclosure will accept up to two (2) splice trays on page 250

Description			Coupler Color	Fiber Density	Duplex Port Density	Part Number
ST	Simplex	Multimode	Metallic	12	6	2-1206114-4
				24	12	4-1206114-4
	Accepts Simplex Couplers		—	—	24 (max.)	12 (max.)
SC	Duplex	Multimode	Beige	12	6	2-1206138-4
				24	12	4-1206138-4
		Single-mode	Blue	12	6	2-1348960-4
				24	12	4-1348960-4

4.7

RACK MOUNT ENCLOSURES & ACCESSORIES