



# CONTEG DATA SHEET

version: 27-09-2010

ACCESSORIES

## SHELVING SHELVING ACCESSORIES

**CONTEG, spol. s r.o.**

**Headquarters Czech Republic:**  
Na Vítězné pláni 1719/4  
140 00 Prague 4

Tel.: +420 261 219 182  
Fax: +420 261 219 192  
[conteg@conteg.com](mailto:conteg@conteg.com)  
[www.conteg.com](http://www.conteg.com)

**Local Offices:**

Austria:	+43 699 1819 7071
Benelux:	+32 477 957 126
Eastern Europe:	+49 172 848 4346
France:	+33 686 074 386
Germany:	+49 170 523 4958
Russia:	+7 495 506 1328



## 19" FIXED LITE SHELVES SERIES DP-PT

- Made of 1.5mm sheet steel
- Supporting brackets included
- Load rating max. 20kg balanced load; maximum load rating decreased to 25% when mounted only on front pair of vertical extrusions (shelves depth 150, 250, and 350mm)
- Longer supporting bracket DP-PO-PD can be used

See the table "Supporting brackets" below

Code	W	D in mm	H	min-max dist. <sup>1</sup>	max. dist. <sup>2</sup>
DP-PT-150	19"	150	1U	75-121	370
DP-PT-250	19"	250	1U	125-221	470
DP-PT-350	19"	350	1U	175-321	570
DP-PT-450	19"	450	1U	225-421	670
DP-PT-550	19"	550	1U	275-521	770
DP-PT-650	19"	650	1U	325-621	870
DP-PT-750	19"	750	1U	375-721	970
DP-PT-850	19"	850	1U	425-821	1070

<sup>1</sup> between standard front and rear brackets in mm  
<sup>2</sup> between front and rear brackets with - DP-PO-PD




## 19" FIXED SHELVES SERIES DP-PO

- Made of 2mm sheet steel
- Possibility of adding supporting brackets
- Load rating max. 60kg balanced load (when supported brackets applied - ordered separately); load rating decreased to 25% when mounted only on front pair of vertical extrusions - shelves depth 150, 250, and 350mm)

SUPPORTING BRACKETS				
Code	Type	Packing	Length in mm	Height
DP-PO-PO	Standard	1 PAIR	88	1U
DP-PO-PD	Extended	1 PAIR	298	1U

\* compatible with DP-PO-xxx, DP-PT-xxx

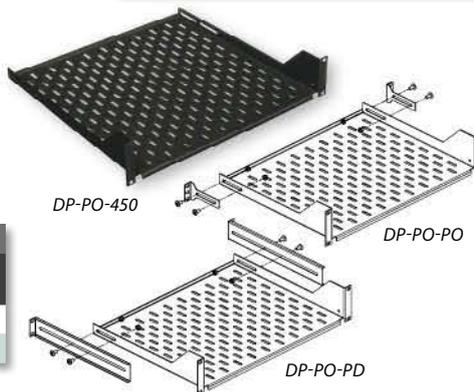


Code	W	D in mm	H	min-max dist. <sup>1</sup>	max. dist. <sup>2</sup>
DP-PO-150	19"	150	1U	75-180	385
DP-PO-250	19"	250	1U	125-265	470
DP-PO-350	19"	350	2U	230-380	585
DP-PO-450	19"	450	2U	260-480	685
DP-PO-550	19"	550	2U	360-580	785
DP-PO-650	19"	650	2U	460-680	885
DP-PO-750	19"	750	2U	560-780	985
DP-PO-850	19"	850	2U	660-880	1085

<sup>1</sup> between standard front and rear brackets in mm  
<sup>2</sup> between front and rear brackets with - DP-PO-PD

## 19" FIXED HIGH-LOAD SHELVES SERIES DP-PZ

- Made of 2mm sheet steel, strengthened by two metal bars
- Four supporting brackets for mounting on vertical extrusions included
- Load rating max. 100kg balanced load

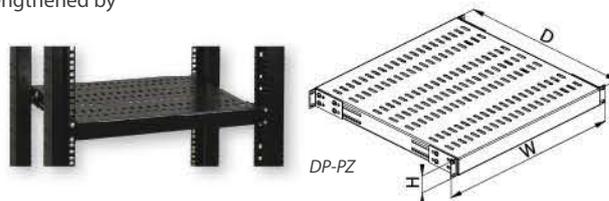


Code	W	D in mm	H	min-max distance <sup>1</sup>
DP-PZ-450	19"	450	1U	113-463
DP-PZ-550	19"	550	1U	213-563
DP-PZ-650	19"	650	1U	313-663
DP-PZ-750	19"	750	1U	413-763
DP-PZ-850	19"	850	1U	513-863

<sup>1</sup> between standard front and rear brackets in mm

## 19" PULL-OUT SHELVES SERIES DP-PO-V

- Made of 1.5mm sheet steel
- Height 1U
- Equipped with one pair of side telescopic rails
- Supporting brackets included
- Load rating max. 25kg balanced load; maximum load rating decreased to 25% when mounted only on front pair of vertical extrusions (shelves depth 250 and 350mm)

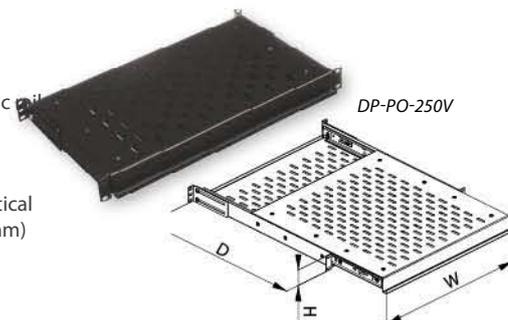


Code	W	D in mm	H	min-max dist. <sup>1</sup>
DP-PO-250V	19"	250	1U	155-370
DP-PO-350V	19"	350	1U	255-470
DP-PO-450V	19"	450	1U	355-570
DP-PO-550V	19"	550	1U	455-670
DP-PO-650V	19"	650	1U	555-770
DP-PO-750V	19"	750	1U	655-870

<sup>1</sup> between standard front and rear brackets in mm

## 19" PULL-OUT HIGH LOAD SHELVES SERIES DP-PZ-V

- Made of 2mm, 2.5mm sheet steel
- Height 1U
- Max. pull-out 450mm
- Load rating max. 80kg balanced load

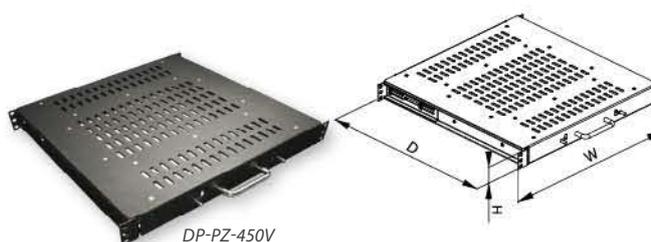


Code	H	W	D in mm	min-max distance <sup>1</sup>
DP-PZ-450V	1U	19"	505	296-507
DP-PZ-550V	1U	19"	605	406-607

<sup>1</sup> between standard front and rear brackets in mm




## SUPPORTING RAILS

- Made of 2mm sheet steel
- Mounting on side holes of vertical extrusions with mounting kits DP-MO-01 (not included)
- Color powder coated RAL (standard RAL 9005)
- Space between rails provides effective cooling of installed active devices
- Load rating max. 50kg balanced load

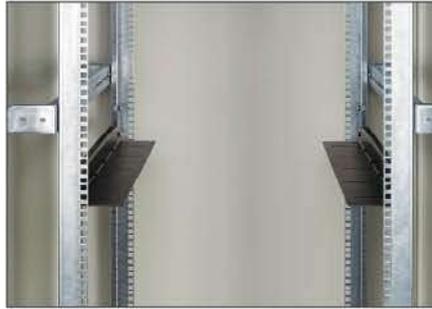

Rack	max. DP-DU
RHF 60/100	900
RDF 80/80	700
RDF 80/100	900
RSF 60/80	700
RSF 60/100	900
RSF 80/80	700
RSF 80/100	900
RSB 60/90 <sup>1</sup>	800
ROF 60/60	500
ROF 60/80	700
ROF 60/100	900
ROF 80/60	500
ROF 80/80	700
ROF 80/100	900
ROP 65/60	500
ROP 65/80	700
RMF 60/60	500
RMF 60/80	700
RMF 60/100	900
RMF 80/80	600
RMF 80/100	800
Rx7 60/60	500
Rx7 60/80	700
Rx7 60/100	900
Rx7 80/80	700
Rx7 80/100	900

SUPPORTING RAILS		
Code	Distance between front and rear vertical L type extrusions (mm)	Depth (D)
DP-DU-300	296	242
DP-DU-400	396	342
DP-DU-500	496	442
DP-DU-600	596	542
DP-DU-700	696	642
DP-DU-800	796	742
DP-DU-900	896	842
DP-DU-1000	996	942

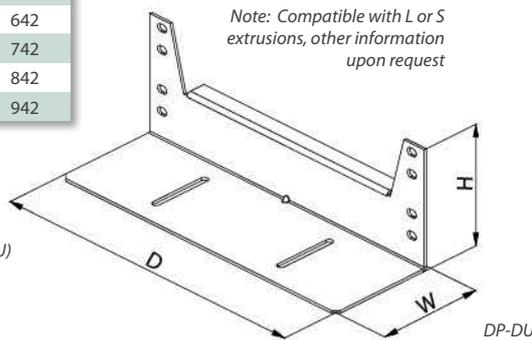


H - 88mm (2U)  
W - 80mm

<sup>1</sup> only if extrusions are installed  
\*NOTE: For installation in racks 1200mm deep is necessary to use S-type extrusions

shelving / shelving accessories

## 19" PULL-OUT DRAWER DP-DD


- Made of 1.25 and 1.5mm sheet steel
- Height 3U
- Max. pull-out distance 280mm
- Load rating max. 10kg balanced load

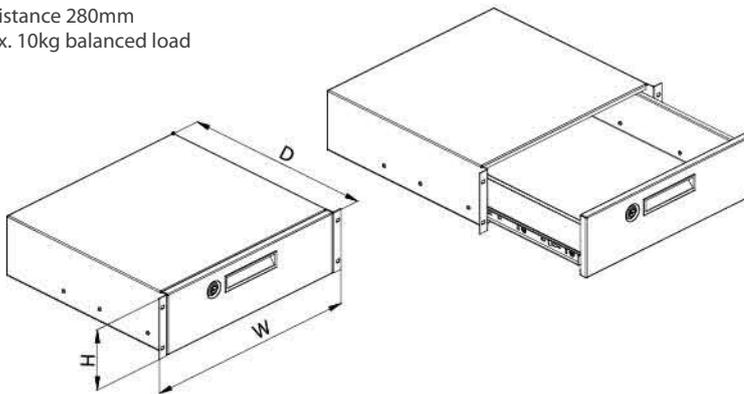

19" PULL-OUT DRAWER			
Code	H in U	W	D in mm
DP-DD-03	3	19"	430

## 19" PULL-OUT KEYBOARD HOLDER SERIES DP-PV

- Made of 1.5mm sheet steel
- Max. keyboard width 400mm and height 36mm
- Depth of shelf 480mm
- Max. pull-out distance 330mm
- Supporting brackets included

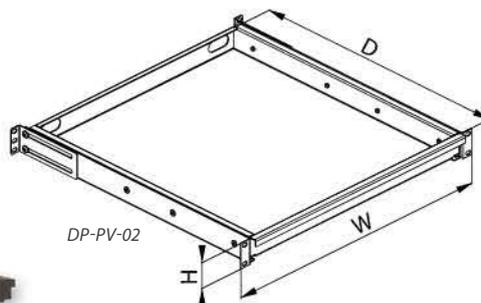

Code	W	D in mm	H
DP-PV-02	19"	480	1U


Supporting brackets DP-PV-PD for installation into racks depth 800 and 1000mm available optionally



## 19" FOLDING KEYBOARD HOLDER SERIES DP-PV


- Enables keyboard placement in front of sliding vertical extrusions
- Max. keyboard size 480x175mm
- Height 1U
- Fix keyboard to shelf using self-adhesive velcro - 8 pcs of size 12 x 25mm included

Code	W	H
DP-PV-01	19"	1U

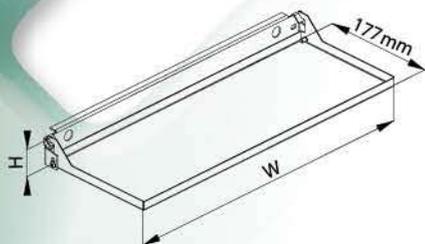

## 21" ADAPTORS

- Allow use of 19" equipment in 21" rack

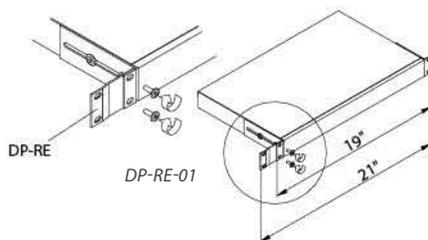

Code	H in Units
DP-RE-01	1
DP-RE-02	2
DP-RE-03	3