





Plinths are installed as an aesthetic and stabilizing element – instead of feet or castors.
When a plinth with filter is used, the plinth supplies a sufficient amount of filtered air. Plinths can also be used for storing cables.

DESCRIPTION:

- Used for racks RDF, RHF, RSF, RSB, ROF, ROP, ROR, RMF, RI7 and RM7 series
- Height of plinth 100mm and 200mm
- Color powder coated RAL (standard RAL 7035 or 9005)
- Delivered unassembled; assembly hardware and instructions included
- Plinth consists of:
 - Set of corners
 - Set of side panels

SET OF PLINTH CORNERS

- Used for all types of free-standing racks.
- Three types of plinth corners:
 - a) DP-PR: fixed height 100 or 200mm; for total load (IT equipment + rack) up to 800kg (applicable also for racks 1200mm deep, in this case load rating is up to 1000kg)
 - b) DP-PR-100-HL: fixed height 100 for total load (IT equipment + rack) 800kg and more
 - c) DP-PR-A: fixed height 100 or 200mm; equipped with adjustable feet; for total load (IT equipment + rack) up to 500kg

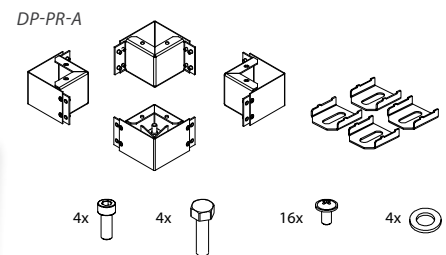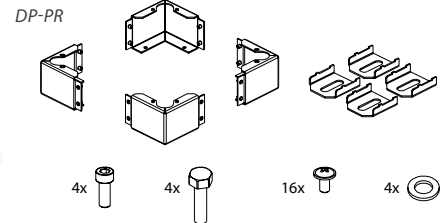


DP-PR-100-HL

Code	Load rating in kg *
DP-PR	800
DP-PR-A	500
DP-PR-100-HL	1700


* Load rating for set (4pcs) of corners incl. weight of rack

SET OF SIDE PANELS

- Consists of:
 - 2pcs of side panels
 - 1pc of front panel
 - 1pc of rear panel with opening for cable entry (size 300x50mm)
 - opening for cable entry covered with removable blank panel
- Two types of side panels:
 - a) with openings for cable entry (in DP-P-PDN-xx/yy)
 - b) with perforation and exchangeable filters (in DP-P-PFN-xx/yy)

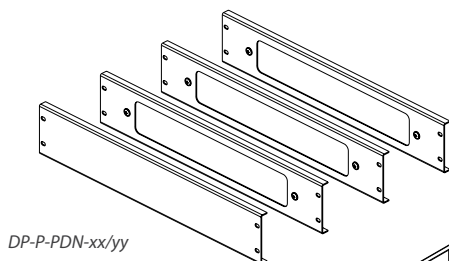


DP-P-PDN-xx/yy

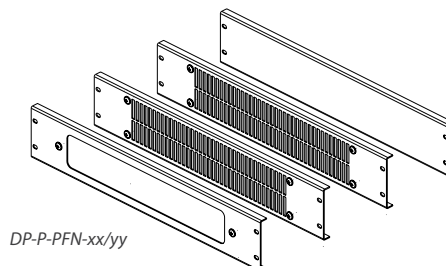

DP-P-PFN-xx/yy

DP-PR-A
DP-P-PDN-xx/yy

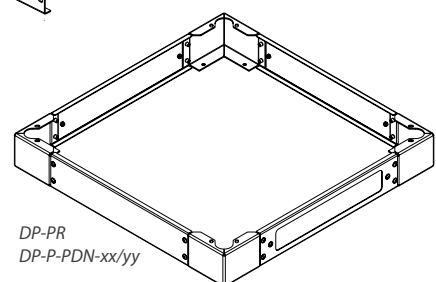

DP-PR
DP-P-PDN-xx/yy

ORDERING MATRIX

PLINTH CORNERS

	1	2
DP - PR	- 100	- A

According to load rating of the rack, choose DP-PR-100-HL, ie. special corners with fixed height 100mm only.

2	- 100	Plinth height 100mm
	- 200	Plinth height 200mm
	- A	Plinth corners with fixed height
	- A	Plinth corners with adjustable feet

SIDE PANELS

	1	2	3	4
DP - P	- PDN	- 60	/	60 - 100

1	PDN	Plinth without filter
	PFN	Plinth with filter
2		Rack width in cm - ie. 60,80
3		Rack depth in cm - ie. 60, 80, 100
- 100		Plinth height 100mm
		Plinth height 200mm

Ordering code for exchangeable filter DP-P-PFN-FI-600 - 600mm length, DP-P-PFN-FI-800 - 800mm length