



# CONTEG DATA SHEET

version: 27-09-2010

ACCESSORIES

## FIBER - OPTIC PRODUCTS

**CONTEG, spol. s r.o.**

**Headquarters Czech Republic:**  
Na Vítězné pláni 1719/4  
140 00 Prague 4

Tel.: +420 261 219 182  
Fax: +420 261 219 192  
[conteg@conteg.com](mailto:conteg@conteg.com)  
[www.conteg.com](http://www.conteg.com)

**Local Offices:**

Austria:	+43 699 1819 7071
Benelux:	+32 477 957 126
Eastern Europe:	+49 172 848 4346
France:	+33 686 074 386
Germany:	+49 170 523 4958
Russia:	+7 495 506 1328




## 19" TELESCOPIC FIBER-OPTIC SPLICE BOXES


Used for termination of optical cables in racks.

### DESCRIPTION:

- Type: telescopic
- Height 1U
- Modular front panels not included - see table on next page
- Up to 24 positions for FO couplings
- Cable entry openings in rear part
- Holes not in use can be covered with blank modules
- Installation in rack with two sliding holders
- Installation kit for splice cassettes and inner organizer included (only ORVM-01)
- Wide range of accessories (optionally)
- Color powder coated RAL (standard RAL 9005)

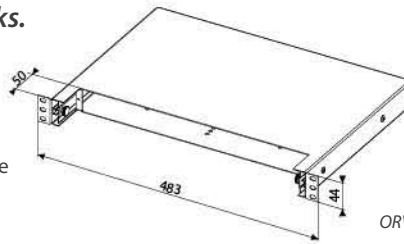

ORVM-01 with front panel

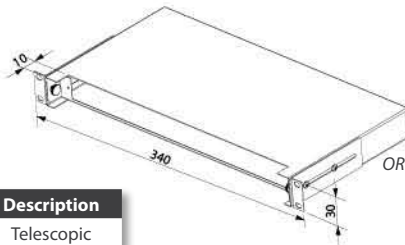

ORVE-01-250 with arestment




Code	W	D in mm	H	Description
ORVM-01	19"	320	1U	Telescopic
ORVE-01-250	19"	250	1U	Telescopic

## 19" FIXED FIBER-OPTIC SPLICE BOX

### DESCRIPTION:

- Type: fixed
- Height 1U
- Modular front panels not included - see table on page 110
- Up to 24 positions for FO couplings
- Cable entry openings in rear part
- Holes not in use can be covered with blank modules
- Installation in rack with two sliding holders
- Installation kit for splice cassettes and inner organizer included
- Wide range of accessories (optionally)
- Color powder coated RAL (standard RAL 9005)

Code	W	D in mm	H	Description
ORPM-01	19"	300	1U	Fixed

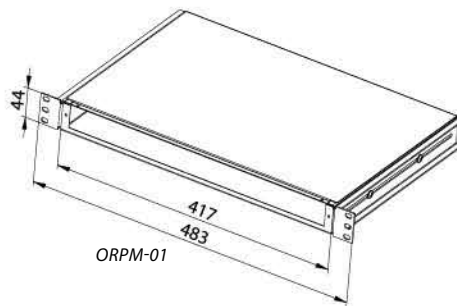

ORPM-01



ORPM-01 with front panel


### ACCESSORIES FOR FIBER-OPTIC SPLICE BOXES

Code	Description
ORO-K2000	Splice cassette
ORO-PG11	PG11 coupling
ORO-PG16	PG16 coupling
ORO-ZPG11	Cover of opening for PG11 coupling
ORO-ZPG16	Cover of opening for PG16 coupling
ORO-01	Front organizer for ORPM
ORO-02	Front organizer for ORVM
ORO-03	Rear organizer


### TYPES OF MODULAR FRONT PANELS

Code	NUMBER OF HOLES FOR FO COUPLINGS			
	8	12	16	24
OR-xxST	yes	yes	yes	yes
OR-xxSC	yes	yes	yes	yes
OR-xxDSC	yes	yes	yes	yes*
OR-xxFC	yes	yes	yes	yes
OR-xxFCD	yes	yes	yes	yes

\* without numbering and holes for screws

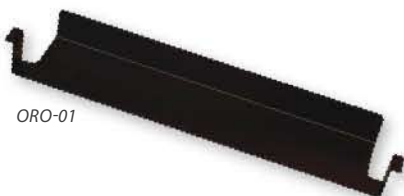

ORO-01

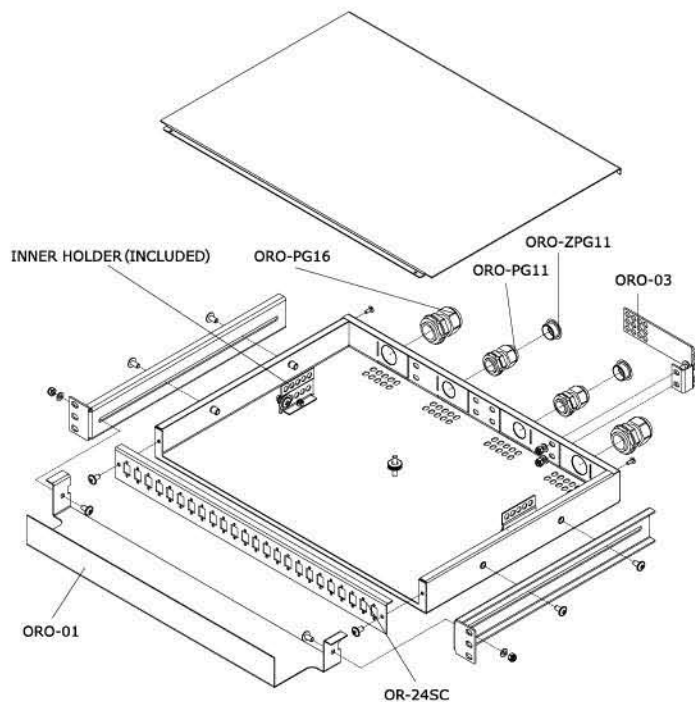



ORO-02



ORO-03




ORO-K2000



ORO-PG16



ORO-ZPG16

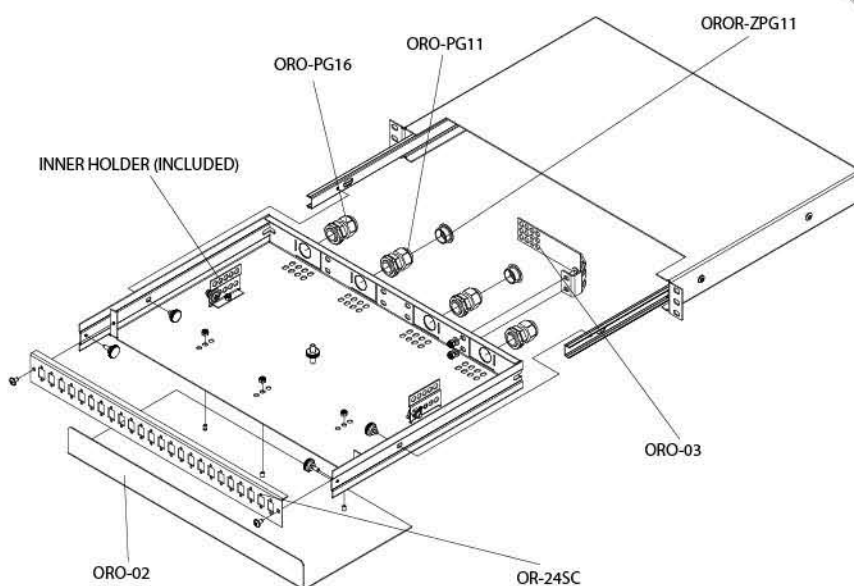

## WALL-MOUNTING FIBER-OPTIC SPLICE BOXES

Wall-mounting fiber-optic splice boxes are used for termination of optical cables.

### DESCRIPTION:

- Types:
  - a) double - size 350x300mm; equipped with double-leaf door and lock
  - b) single - size 300x180mm or 220x180mm
- Modular panels with holes for couplings - see table on page 110
- In double FO splice-box up to 24 positions for ST or SC or FC or 12 DSC or FCD adapters
- In single FO splice-box up to 8 positions for ST or SC or FC or 4 DSC or FCD adapters
- Holes not in use can be covered with blank modules
- Cable entry through PG couplings (PG 9 for ORN-01 and PG 11 for ORN-02)
- Installation kit for splice cassette (ORO-K2000) included
- Color powder coated RAL (standard RAL 7035)

Code	Type	Sizes W x H in mm
ORN-01-30/18	Single	300 x 180
ORN-01-22/18	Single	220 x 180
ORN-02-35/30	Double	350 x 300



ORN-02-35/30




ORN-02-35/30 equipped with ORN-24SC



**PANELS FOR WALL-MOUNTING FIBER-OPTIC SPLICE BOXES**


ORN-01-30/18 and ORN-01-22/18	ORN-02-35/30
ORN-M-8ST	ORN-24ST
ORN-M-8SC	ORN-24SC
ORN-M-4DSC	ORN-12DSC
ORN-M-1PG	ORN-24FC
ORN-M-2PG	ORN-12FC
ORN-M-8FC	ORN-12FCD
ORN-M-4FCD	

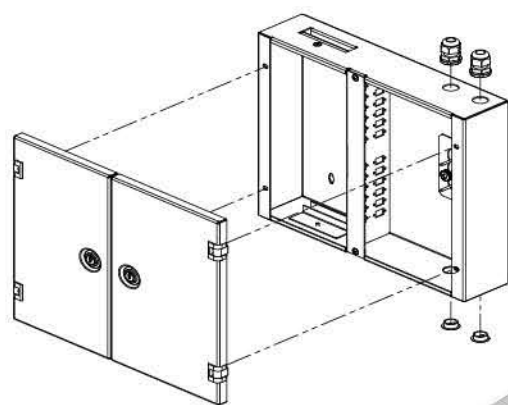

ORN-01-22/18




ORN-01-30/18

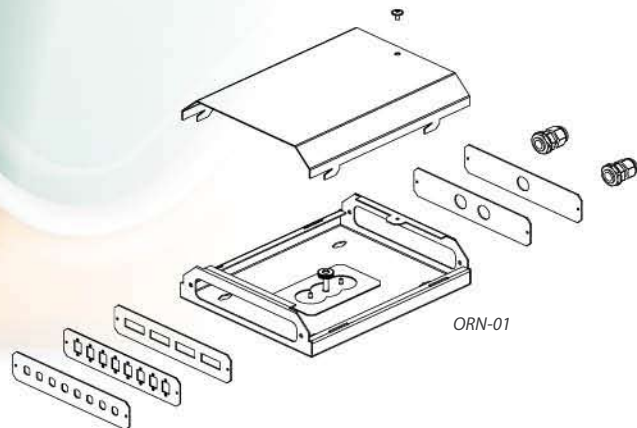

ORN-01

**TYPES OF HOLES FOR FIBER-OPTIC CONNECTORS**

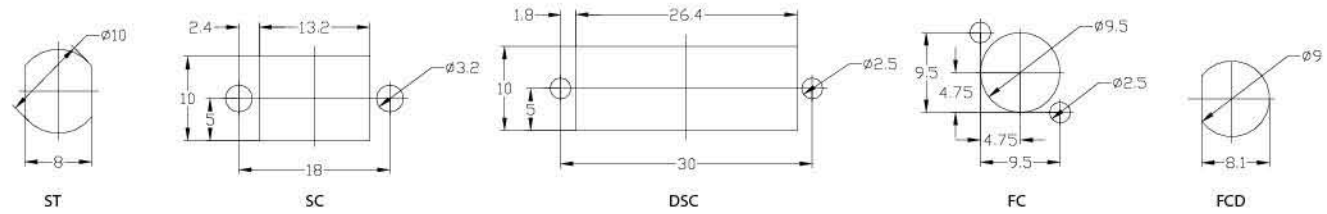

Note: Dimensions before powder coating