




The RON series racks are designed for wall mount installation. Access to the installed equipment is through the front. The rack features a construction with an excellent rigidity. The 19" wall-mounting telecommunication and data racks are designed for the installation of patch panels, active components, etc. Should you need rear access to the installed equipment please refer to the ROD rack series.

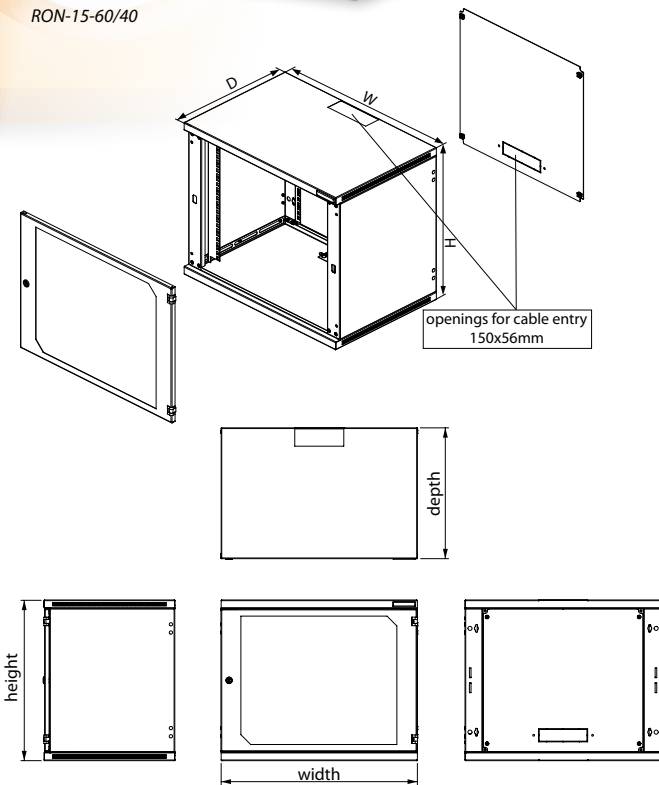

RON-15-60/40



**COLOR SAMPLER:**

RAL 7035

**DESCRIPTION**

**Sizes**

- Height: 4, 6, 9, 12, 15, 18U
- Width: 600mm
- Depth: 400 and 600mm

**Construction**

- 1.25mm sheet steel

**Load rating**

- standard 40kg balanced load

**IP rating**

- Standard IP20

**Colors**

- Standard RAL 7035
- Optionally other colors

**Front door**

- Tinted security glass (EN 12150-1) or sheet steel door
- Reversible door - easy to re-hang to open right or left (at installation site)
- Door opening angle 180°

**Rear door**

- Removable with module for cable entry
- When installed without the rear panel additional holes are exposed for installation of 19" components
- Mounting holes for wall installation on the back

**Cable entries**

- Top and bottom openings for cable entry, size 150x56mm
- Covered with sliding blank panel with butterfly nuts (DP-DB-200x68)
- Variable openings in relation to number of cables entering the rack
- Cable entries on rear edge of enclosure for straight cable path alongside the wall

**Others**

- Drilling template
- Possibility to add extra pair of extrusions (DP-LV-N-xx)

**STANDARD CONFIGURATION:**

- 1 pair of sliding 19" vertical extrusions
- Tinted security glass door (EN 12150-1) with lock
- GND/earthing kit
- 16 mounting kits

Code	H in Units	Dimensions in mm				Dimensions incl. packing in mm			Gross weight in kg
		H	W	D	Useful depth	H	W	D	
RON-04-60/40	4	300	600	400	370	325	625	435	15
RON-06-60/40	6	388	600	400	370	413	625	435	17
RON-09-60/40	9	521	600	400	370	546	625	435	20
RON-12-60/40	12	655	600	400	370	680	625	435	24
RON-15-60/40	15	788	600	400	370	813	625	435	27
RON-18-60/40	18	921	600	400	370	946	625	435	30
RON-06-60/60	6	388	600	600	570	413	625	635	21
RON-09-60/60	9	521	600	600	570	546	625	635	24
RON-12-60/60	12	655	600	600	570	680	625	635	30
RON-15-60/60	15	788	600	600	570	813	625	635	31
RON-18-60/60	18	921	600	600	570	946	625	635	38

RON series 19" wall mount racks