

The RS series frames are used in closed rooms with controlled access and within a suitable operating environment for installed components or wherever racks cannot be used for any reason. These frames are available either in single version (one frame) or in double version (two frames).

DESCRIPTION

Sizes

- Height: 27, 36, 42 and 45U
- Width: 559mm
- Depth: 600mm (base size)

Construction

- 2.0mm sheet steel

Load rating

- 200kg - two post frame
- 400kg - four post frame

IP rating

- IP00 (no protection)

Colors


- Standard RAL 9005

Base


- Produced from sheet steel
- Equipped with feet
- Optionally castors (to be ordered separately)

COLOR SAMPLER:

RAL 9005

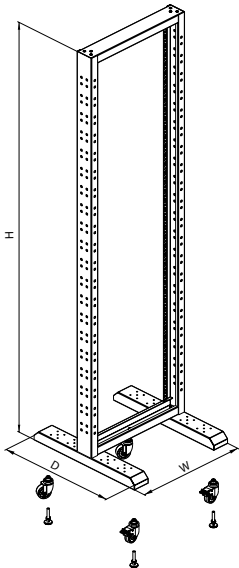

RS-42, RS-P

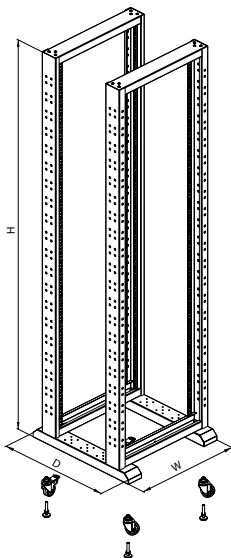

RS-42, RS-42, RS-P

19" TWO POST FRAMES					
H in U	Consist of		W in mm	D in mm	H in mm
	code	pcs			
27U	RS-27	1	559	600	1339
	RS-P	1			
36U	RS-36	1	559	600	1739
	RS-P	1			
42U	RS-42	1	559	600	2005
	RS-P	1			
45U	RS-45	1	559	600	2139
	RS-P	1			

19" FOUR POST FRAMES					
H in U	Consist of		W in mm	D in mm	H in mm
	code	pcs			
27U	RS-27	2	559	600	1339
	RS-P	1			
36U	RS-36	2	559	600	1739
	RS-P	1			
42U	RS-42	2	559	600	2005
	RS-P	1			
45U	RS-45	2	559	600	2139
	RS-P	1			

ACCESSORIES FOR RS FRAMES

CROSS-RAIL FOR FOUR POST FRAMES

Description:

- Used for fixing of four post frame
- Set includes one pair of rails
- Made of 2mm sheet steel
- Set of 12 pcs M5x12 screws included
- Color powder coated RAL (standard RAL 9005)



ACCESSORIES FOR RS FRAMES		
Code	Description	One set includes
RSSD-RAIL	Cross-rail for four post frame	1 pair
RSSD-VP	Wire management panel for four post frame	1 piece
RSSD-BRACE	Stabilizer for two and four post frame	1 pair