


SNCA-POWERBOX

Combined power supply and fixing bracket
--

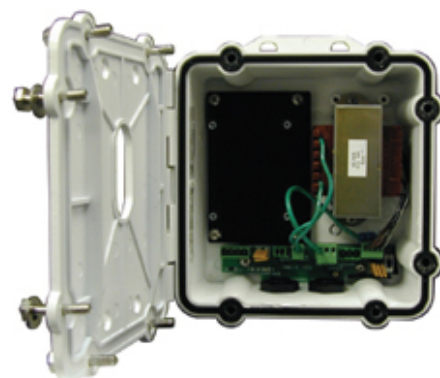

Fixing Method;

- Wall
- SNCA-PM3
- SNCA-CA2

Can be used with models;

- SNCA-WM20G
- SNCA-WM20FC
- SNCA-WM40
- SNCA-WMMD1
- SNCA-WMMD2

Rating;

- IP66 (outdoor)

Input Voltage;

- 110/230 volts AC (selectable)

Output Voltage;

- 24 volts AC (4 amps max.)

Operating temp;

- -40°C to 50°C