



Anixter Part No : AL-12C-RPPVC-P100

Part NO. : 20071207-26

Ver: A0


Product Code : 12C Alarm Cable LSF

Page : 1 / 1

1.CONSTRUCTION

Item		A.Q.L	Description
Conductor	NO./mm	T0.19	Stranded tinned copper
	12 / T0.19 x 7	(+/-0.008)	
Insulation	NO./mm	1.00	Low smoke PVC insulation
	12 / 1.00	(+/-0.10)	
Shield	NO./mm		
	-----	-----	-----
Jacket	NO./mm	5.50	Rip Cord
	5.50	(+/-0.20)	Reduced Propagation PVC jacket

2.DESIGN

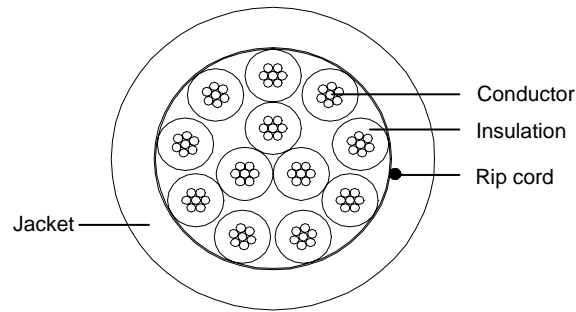

3.CHARACTERISTICS

Item	Description	Standards
1. Cond. Res.	20°C, Conductor DC Resistance	< 10.43 Ω/100M
2. Insul. Res.	20°C, Insulation Resistance	> 200 MΩ.M
3. Rated Tem.	-----	60°C
4. Rated Voltage	-----	300 V

Remark: Please contact us if you have more requirements or specifications subject to change, or else in accordance with the standards.

Prepared: Zhao

Approved by :

Client approved:

Date:2007-12-07