

## specifications

Enclosure shall meet TIA/EIA consolidation point standard requirements. Enclosure shall be mounted recessed into wall or on wall and accepts punchdown bases or patch panels. Optional covers shall be available for in wall or on wall applications. Conduit knockouts shall be available to route cables in and out of enclosure.



**PANDUIT**

NETWORK CONNECTIVITY GROUP

**SPEC SHEET**

**NEW!**

## PANZONE™ Wall Mount Enclosure

### technical information

**TIA/EIA Compliance:** Meets TIA/EIA-568-B.1 standard consolidation point requirements

**Dimensions:**

Base:	HxWxD=24.54x14.25x4.02 in. (623.4x362x102mm)
Hinged cover:	HxWxD=26.04x15.75x1.09 in. (661.5x400x27.7mm)
Flat cover:	HxW=24.54x14.25 in. (623.4x368.3mm)
Patch panel bracket:	3.59x.65 in. (91.2x16.5mm)

**Mounting:** Easily installed recessed into wall or on wall

**Packaging:**

PZB4 supplied with *TAK-TY*® Hook & Loop Cable Ties, mounting screws for punchdown bases and grommet edging

PZB4-FC supplied with screws to secure cover to base

PZB4-HC supplied with two keys and screws to secure cover to base

PZBPPB includes two brackets and mounting screws

**Material:** Made of rugged 16 gauge steel

### key features and benefits

<b>Base capacity</b>	Accepts up to four 100 pair punchdown bases
<b>Conduit knockouts</b>	Available on each side to route cable in and out of enclosure
<b>Cable tie slots</b>	Available for cable management
<b>Optional bracket</b>	Allows 2 RU of standard 19" patch panels to be mounted in enclosure
<b>Choice of covers</b>	Hinged cover includes lock for added security Flat cover provides a flush look for on wall mounting

### applications

PANZONE enclosure allows consolidation of several outlets in one location, saving time and money by reducing the amount of time required to complete moves, adds and changes. The enclosure is designed to hold a variety of PANDUIT products, up to four 100 pair PAN-PUNCH™ bases with legs or three high density/144 pair GP6™ PLUS bases with legs.

The optional hinged door is recommended for mounting the enclosure recessed in wall between two 2"x4" studs that are 16" apart center to center. Metal trim of hinged door covers the irregularities of the drywall surrounding the enclosure and locking feature will add security. Optional flat cover is recommended for on wall installations. Optional bracket allows up to two RU 19" standard patch panels to accommodate a variety of multimedia applications.

#### PANZONE Enclosure

Enclosure bases:	PZB4
Hinged cover:	PZB4-HC
Flat cover:	PZB4-FC
Patch panel bracket:	PZBPPB

#### Punchdown Bases

GP6 PLUS High Density Base w/legs:	GPBW144-X
GP6 PLUS Standard Density Base w/legs:	GPBW24-X
PAN-PUNCH Base w/legs:	P110BW100-X

#### MINI-COM® ULTIMATE ID™ Patch Panels (2 RU)

48 port:	UICMP48BL
----------	-----------

#### MINI-COM Modular Patch Panels (2 RU)

48 port w/labels:	CPPL48WBL
72 port w/labels:	CPPL72WBL
48 port :	CPP48WBL
48 port M6:	CPPL48M6BL

#### MINI-COM Punchdown Patch Panels (2 RU)

48 port DP6™ PLUS Panel:	DP48688TP
48 port DP5e™ Panel:	DP485E88110U


### installer tip

Patch panels can be secured to pre-drilled holes located on the base providing a solid surface while terminating the panel.


Visit our website at: [www.panduit.com/ncg](http://www.panduit.com/ncg)

# PANZONE™ Wall Mount Enclosure


## PZB4

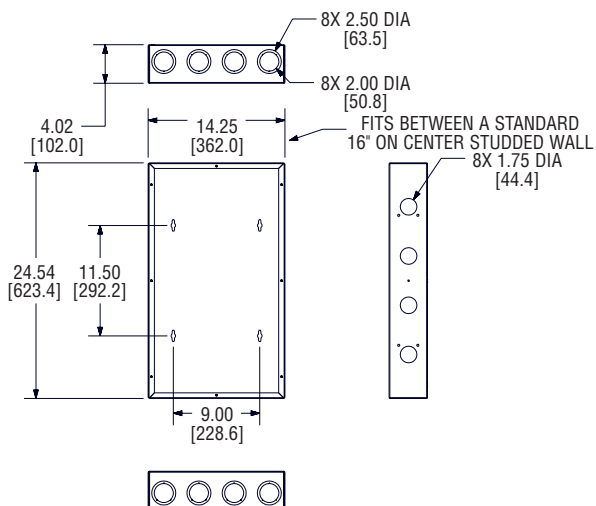


## PZB4-FC

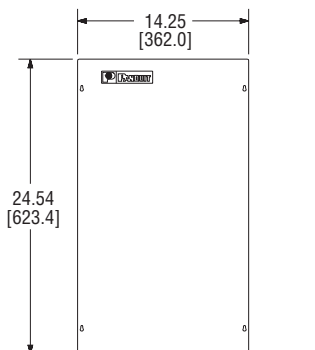

## PZB4-HC

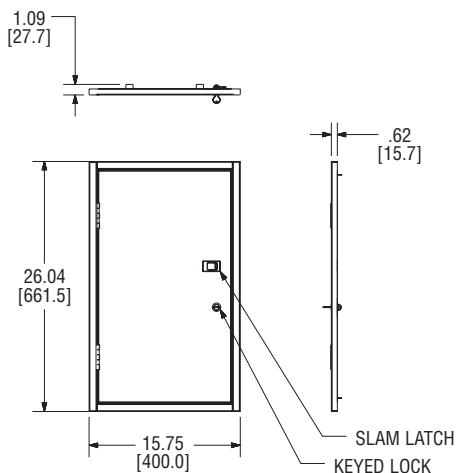

## PZBPPB

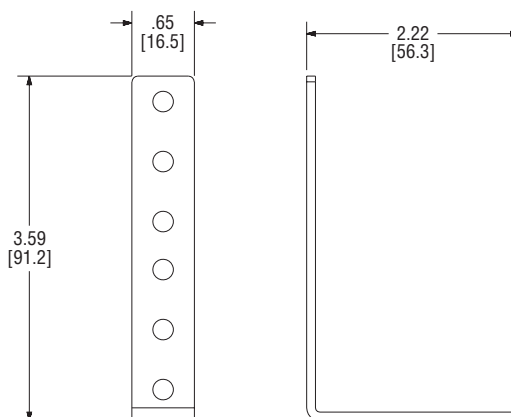

Dimensions are in inches (Dimensions in parentheses are metric)

For a copy of **PANDUIT** product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

For a full line catalog (SA-NC10CB01A), email us at [csteam@panduit.com](mailto:csteam@panduit.com) or call Customer Service at 800-777-3300.



**PANDUIT CORP.**  
Tinley Park, Illinois 60477-3091  
Customer Service: 800-777-3300  
Technical Support: 866-405-6654  
Email: [ncginfo@panduit.com](mailto:ncginfo@panduit.com)  
Website: [www.panduit.com/ncg](http://www.panduit.com/ncg)

**Contact your local authorized **PANDUIT** distributor for pricing. For your local Sales Office call 800-777-3300**

**PANDUIT CANADA**  
Markham, Ontario  
Phone: 800-777-3300

**PANDUIT EUROPE LTD.**  
London, UK  
Phone: 44 208-601-7200

**PANDUIT ASIA PACIFIC PTE. LTD.**  
Republic of Singapore  
Phone: (65) 6379 6700

**PANDUIT JAPAN**  
Tokyo, Japan  
Phone: (81) (3) 3767-7011

**PANDUIT LATIN AMERICA**  
Jalisco, Mexico  
Phone: (52) 3 666-2501

**PANDUIT AUSTRALIA PTY. LTD.**  
Victoria, Australia  
Phone: (61) 3-9794 9020