

LCD-703HD




703HD2-Dual Rack Mount



LCD-703HDL Flush Mount



LCD-703 Back View

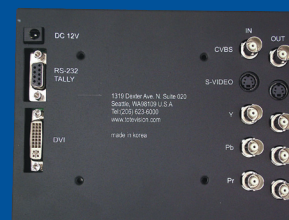

## MODEL NUMBERS

LCD-703HD	
LCD-703HD1	Single Rack Mount
LCD-703HD2	Dual Rack Mount
LCD-703HDL	Flush Mount
LCD-703HDX	No LEDs and no controls showing
LCD-703HDLX	Flush Mount; no LEDs and no controls showing

## DESCRIPTION

HD compatible (supports 480p/i, 576p/i, 720p, 1080p/i)  
Both component & DVI inputs accept 1080p/i

LED backlight provides longer life, uses less power and provides better color saturation

RS-232 feature allows external devices to control the monitor through the serial port

Underscan capability

Blue gun feature provides for easy adjustment of screen display

Anti-glare treatment adds to viewing pleasure

Displays either 16:9 or 4:3 aspect ratio

Front controls for: menu, up, down, On/Off, mode

IR remote control

Case made of durable metal.

A/C adaptor (Part No. AC-1000) included

Built-in interface and proper cable exiting for wall or arm mounting VESA 75mm FPMPMI compliant

Response time: 22ms (Rising), 35ms (Falling)

Mounting pad with ¼-20 threaded socket

703HD KIT: 7" LCD HD field kit with rechargeable battery pack and Tote Bag

703HDX: 7" Free-Standing HD LCD with no front controls

## OPTIONAL ACCESSORIES

HS-1	Hot shoe mount
MB-3	Desk stand
SS-703HD	Metal Sun shield
TB-703	Custom Tote bag with sun shield
WM-30	Wall mount bracket (fixed)

## SPECIFICATIONS

Resolution	800 (H) x 480 (V) dots
Brightness rating	350 cd/m <sup>2</sup> (Nit)
Back Light	LED
PC compatibility	VGA, SVGA, XGA, SXGA, WXGA
Dot Pitch	0.19(H) x 0.19(V)mm
Contrast Ratio	300:1
Display	7" TFT LCD active matrix
Number of Pixels	1.2 M
Pixel Configuration	Stripe
Input Signal	NTSC/PAL (auto sensing)
Video Input Level	1.0 V P-P (positive) 75 Ohm
Viewing angle (L/R/T/B)	65/65/55/60 degrees
LCD-703HDL / LX Flush Mounted Dimensions (WHD)	215 x 175 x 35mm / 8.5" x 6.9" x 1.4"
Installer's Cutout (WH)	180 x 138mm / 7.1" x 5.4"
LCD-703HD1 / 703 HD2 Dimensions (WHD)	482" x 133.4" x 55" / 19" x 5.25" x 2.2" (3RU)
LCD-703HD Dimensions (WHD)	174 x 134 x 35mm / 6.9" x 5.3" x 1.4" (Height including 5mm mounting pad: 134 +5mm = 139mm)
Actual Visible Screen size (WH)	152.4 x 91.4mm / 6" x 3.6"
Operating Temperature	10 ~ 104°F / -12 ~ 40°C
Storage Temperature	13 ~ 140°F / -25 ~ 60°C
Power Requirement / Power Supply	350mA@ 12 VDC (max) + pin, - ground 6~20 VDC, 500mA
Rear Inputs	<b>Composite</b> BNC video IN/OUT <b>Component</b> BNC IN/OUT <b>S-Video</b> IN/OUT <b>RS-232, Tally, HDMI</b> <b>Power</b> 2.1mm DC IN jack
LCD-703HD Weight	<b>Net</b> 0.6 kg / 1.35lbs <b>Gross</b> 0.86 kg / 1.9 lbs <b>Net</b>
LCD-703HDL/HDLX Weight	<b>Net</b> 0.7 kg / 1.5 lbs <b>Gross</b> 1.1 kg / 2.45 lbs <b>Net</b>
LCD-703HD2 Weight	<b>Net</b> 2.5 kg / 5.5 lbs <b>Gross</b> 03.2 kg / 7 lbs <b>Net</b>