

LCD-560 Free-Standing




LCD-560L Flush Mount



LCD-560LX Flush Mount (no front controls)



Video Cable
(Video 1 & 2 / Power)

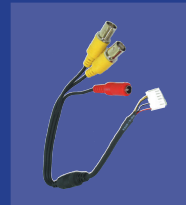

LCD-560X3 Rack Mount



MODEL NUMBERS

- LCD-560
- LCD-560L Monitor in Flush Mount; with Controls
- LCD-560LX Monitor in Flush Mount; no Front Controls
- LCD-560X3 Three Monitors in Rack Mount

DESCRIPTION

LED backlight provides longer life, uses less power and provides better color saturation

LCD-560 and LCD-560L features 2 composite video inputs with front controls for channels A & B, contrast, tint, color, brightness, and power

560 and 560L DIP switches allow user to select mirror image or Up/Down image for both channels A and B, and "auto ON with power" feature

LCD-560X3 tilts 90° in 19" rack for optimum viewing, occupies 3 rack units
Composite video passive loop through capability for all 3 monitors (always active regardless of power). Loop out termination is provided.
Self-powered 3 color tally system. Front controls: contrast, tint, color, brightness, power, video, S-Video

Broadcast quality display by auto termination switch in the BNC connector

560LX: Rear controls: contrast, tint, color, brightness.
Front control for power can be disabled by DIP switch

For color and B&W applications

Low power consumption

LCD-560 and LCD-560L cases made of durable steel

LCD-560X3 case made of durable aluminum & steel

Active matrix technology allows wide viewing angle

Response Time: 22ms

1/4-20 mounting pad included for LCD-560

VESA 75mm compliant / AC adaptor included

LCD-560L: Flush-Mounted 5.6" Monitor (back view below)

LCD-560LX: Flush-Mounted 5.6" Monitor with no front controls
Installers Cut-Out (WH): 140 x 134mm / 5.5" x 5.25"

OPTIONAL ACCESSORIES for the LCD 560

MB-3 Desk stand

SPECIFICATIONS

Resolution	960(H) x 234(V) dots
Brightness Rating	350 cd/m ² (Nit)
Back Light	LED
Dot Pitch	0.118(H) x 0.362(V)
Contrast Ratio	300 : 1
Display	5.6" TFT LCD active matrix
Number of Pixels	224,640 dots
Pixel Configuration	Stripe
Input Signal	NTSC/PAL (auto sensing)
Viewing angle (L/R/T/B)	65/65/55/55
Dimensions (WHD)	560: 134 x 134 x 21mm / 5.3"x5.3"x0.8" 560L/560LX: 174 x 175 x 22mm / 6.8" x 6.8" x 0.9" 560X3: 432 x 132 x 50mm / 19" x 5.2" x 2", 3RU
Visible Screen Size (WH)	114 x 87mm / 4.5" x 3.4"
Operating Temperature	50 ~ 104°F or 10 ~ 40°C
Storage Temperature	-13 ~ 140°F or -25 ~ 60°C
Power Requirement / Consumption	10 ~ 15 VDC, 0.4 A @ 12 VDC / 5 W
LCD-560 / LCD-560L Connections	Cable w/2 female BNC and one 2.1mm DC inputs
LCD-560X3 Rear Connections	BNC video IN/OUT jacks x 3 S-Video IN/OUT jacks x 3 15-pin DB for tally system 2.1mm DC IN jack
Weight	560 Net 400g / 14 oz Gross 0.88 kg / 1.95 lbs 560L/LX Net 700g / 24.6 oz Gross 0.9 kg / 2 lbs 560X3 Net 2.5 kg / 5.2 lbs Gross 2.7 kg / 5.85 lbs

LCD-560 Back View

