



LCD-842HD

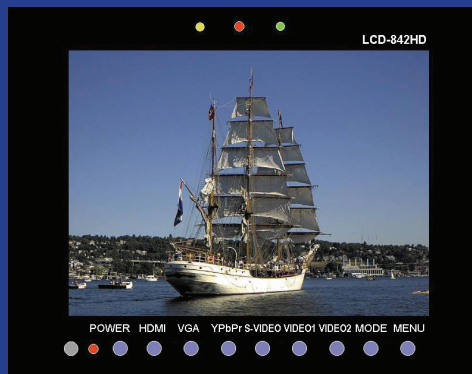

LCD-842HD2 Dual Rack Mount

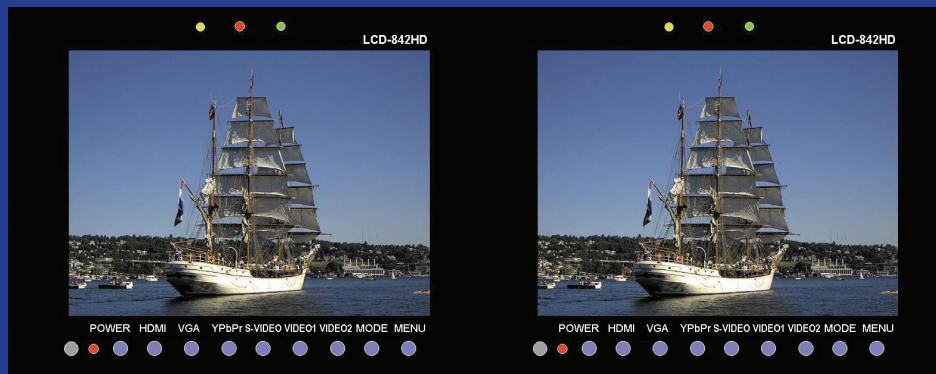

MODEL NUMBERS

LCD-842HD

LCD-842HD2

DESCRIPTION

Blue gun feature provides for easy adjustment of screen display

Underscan capability

Space saving design

Self-powered 3 color tally system is provided for each monitor

Active matrix technology allows wide viewing angle

Active matrix technology eliminates distortion

Switching power supply (included)

Built-in memory saves current setup when unit is powered down

Active loop through feature is always on as long as power is on

Scaler accepts 640 x 480, 800 x 600, 1024 x 768, 1152 x 864, and 1280 x 1024

Response Time: 15ms/25ms (rising/falling)

For color and B/W applications

Built-in color bar generator

Each screen has individual front mounted direct source selector buttons

OPTIONAL ACCESSORIES

DC-1500	Factory approved car cord
HM-400	Under-cabinet hinge mount bracket
WM-30	Wall mount bracket (fixed and locking)
WM-31	Wall mount bracket (fixed)
WM-302	Wall mount with swing arm & 4-way
BP-563	Rechargeable 2200mh NiCad battery pack Provides approximately 6 hrs. operation.
DC-12	Car cord
DC-12D	Dual car cord
HS-1	Hot shoe mount
MB-3	Desk stand
MB-72M	Mounting bracket

SPECIFICATIONS

Resolution	800(H) x 600(V) dots
Brightness Rating	450 cd/m ²
Dot Pitch	0.213mm x 0.213mm
Display	8.4"
Inputs	S-Video, 2x Composite, VGA, YPbPr, HDMI
Outputs	S-Video, 2x Composite loop out, MUX video output
Viewing angle (L/R/T/B)	75/75/75/75
LCD-842D Dimensions	Occupies 4 RU (7") x 1.75" (D)
LCD-842 Dimensions	210(W) x 177(H) x 50(D)mm/ 8.3" x 7" x 2"
Visible Screen Size	6.71" x 5.03"
Input Signal	NTSC/PAL auto recognize
Controls	RS-232, TALLY via 9-pin D-sub connector
Power Requirement / Consumption	12 DCV, 1.5 Amps
Approximate Weight	3 lbs

LCD-842HD (back view)

