



# HUBBELL OptiChannel FSP Adapter Panels

High-Density Versions.  
Loaded, Unloaded or Blank.  
Multimode and Singlemode Applications.

### FEATURES

- Various colors available to differentiate networks and applications.
- Available in loaded, unloaded or blank versions.
- Nylatch fasteners used for quick snap in installation.
- SC Simplex APC (Angled Polish Connector) adapter panels available.

### SPECIFICATIONS

- ◆ Cold roll Steel panel finished with a durable black powder coat finish.
- ◆ Dimensions: 1.1" (28) Wide x 5.1" (130) High.
- ◆ Weight (loaded): 0.1 lbs.
- ◆ FC/PC adapter housings are nickel-plated machined brass.
- ◆ ST-style adapters have black oxide Nickel-plated Zinc die-cast housings.
- ◆ High-retention phosphor bronze alignment sleeves recommended for most applications.
- ◆ Zirconia precision alignment sleeves recommended for Singlemode applications.



Modular FSP series fiber adapter panels snap into all OPTiChannel fiber rack mount panels and wall mount cabinets.

Adapter panels are available as blank plates or with ST-style, SC, FC, MT-RJ, LC, MTP and SC to ST-style adapters. All adapter panels are available in high-density versions.

The JackPack™ keystone 6-port adapter panel accepts multimedia connections.

## FSP Adapter Panels, SC Duplex

### Phosphor Bronze Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	3 SC Duplex, Aqua	Standard	<b>FSPSCDM3AQ</b>
12	6 SC Duplex, Aqua	High-Density	<b>FSPSCDM5AQ</b>
6	3 SC Duplex, Beige	Standard	<b>FSPSCDBE3</b>
12	6 SC Duplex, Beige	High-Density	<b>FSPSCDBE6</b>
6	3 SC Duplex, Black	Standard	<b>FSPSCDM3BK</b>
12	6 SC Duplex, Black	High-Density	<b>FSPSCDM6BK</b>
6	3 SC Duplex, Blue	Standard	<b>FSPSCD3</b>
12	6 SC Duplex, Blue	High-Density	<b>FSPSCD6</b>
6	3 SC Duplex, Green	Standard	<b>FSPSCDG3</b>
12	6 SC Duplex, Green	High-Density	<b>FSPSCDG6</b>
6	3 SC Duplex, Orange	Standard	<b>FSPSCDO3</b>
12	6 SC Duplex, Orange	High-Density	<b>FSPSCDO6</b>
6	3 SC Duplex, Red	Standard	<b>FSPSCDR3</b>
12	6 SC Duplex, Red	High-Density	<b>FSPSCDR6</b>
6	3 SC Duplex, Yellow	Standard	<b>FSPSCDY3</b>
12	6 SC Duplex, Yellow	High-Density	<b>FSPSCDY6</b>

### Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	3 SC Duplex, Blue	Standard	<b>FSPSCDS3</b>
12	6 SC Duplex, Blue	High-Density	<b>FSPSCDS6</b>
6	3 SC Duplex, Orange	Standard	<b>FSPSCDS3OR</b>
12	6 SC Duplex, Orange	High-Density	<b>FSPSCDS6OR</b>
6	3 SC Duplex, Red	Standard	<b>FSPSCDS3R</b>
12	6 SC Duplex, Red	High-Density	<b>FSPSCDS6R</b>
6	3 SC Duplex, Yellow	Standard	<b>FSPSCDS3Y</b>
12	6 SC Duplex, Yellow	High-Density	<b>FSPSCDS6Y</b>



FSPSCDO3



FSPSCDY3



FSPSCD3



FSPSCDG6



FSPSCDY6



FSPSCDR6



FSPSCDBE6


## FSP Adapter Panels, LC Duplex



FSPLC6



 FSPLCO6



FSPLCY6

### Phosphor Bronze Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
12	6 LC Duplex, Aqua	Standard	<b>FSPLCDM6AQ</b>
12	6 LC Duplex, Beige	Standard	<b>FSPLCDM6</b>
12	6 LC Duplex, Black	Standard	<b>FSPLCDM6BK</b>
12	6 LC Duplex, Blue	Standard	<b>FSPLC6</b>
12	6 LC Duplex, Orange	Standard	<b>FSPLCO6</b>
12	6 LC Duplex, Red	Standard	<b>FSPLCDM6R</b>
12	6 LC Duplex, Yellow	Standard	<b>FSPLCY6</b>

### Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
12	6 LC Duplex, blue	Standard	<b>FSPLCDS6</b>
12	6 LC Duplex, aqua	Standard	<b>FSPLCDS6AQ</b>
12	6 LC Duplex, black	Standard	<b>FSPLCDS6BK</b>
12	6 LC Duplex, orange	Standard	<b>FSPLCDS6OR</b>
12	6 LC Duplex, red	Standard	<b>FSPLCDS6R</b>
12	6 LC Duplex, yellow	Standard	<b>FSPLCDS6Y</b>

## FSP Adapter Panels, LC Quad



FSPLCQ3



FSPLCQO3



FSPLCQY3

### Phosphor Bronze Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
12	3 LC Quad, Aqua	Standard	<b>FSPLCQM3AQ</b>
24	6 LC Quad, Aqua	High-Density	<b>FSPLCQM6AQ</b>
12	3 LC Quad, Beige	Standard	<b>FSPLCQM3BE</b>
24	6 LC Quad, Beige	High-Density	<b>FSPLCQM6BE</b>
12	3 LC Quad, Black	Standard	<b>FSPLCQM3BK</b>
24	6 LC Quad, Black	High-Density	<b>FSPLCQM6BK</b>
12	3 LC Quad, Blue	Standard	<b>FSPLCQ3</b>
24	6 LC Quad, Blue	High-Density	<b>FSPLCQ6</b>
12	3 LC Quad, Green	Standard	<b>FSPLCQM3GN</b>
24	6 LC Quad, Green	High-Density	<b>FSPLCQM6GN</b>
12	3 LC Quad, Orange	Standard	<b>FSPLCQO3</b>
24	6 LC Quad, Orange	High-Density	<b>FSPLCQO6</b>
12	3 LC Quad, Red	Standard	<b>FSPLCQM3R</b>
24	6 LC Quad, Red	High-Density	<b>FSPLCQM6R</b>
12	3 LC Quad, Yellow	Standard	<b>FSPLCQY3</b>
24	6 LC Quad, Yellow	High-Density	<b>FSPLCQY6</b>

### Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
12	3 LC Quad, Beige	Standard	<b>FSPLCQS3BE</b>
24	6 LC Quad, Beige	High-Density	<b>FSPLCQS6BE</b>
12	3 LC Quad, Black	Standard	<b>FSPLCQS3BK</b>
24	6 LC Quad, Black	High-Density	<b>FSPLCQS6BK</b>
12	3 LC Quad, Aqua	Standard	<b>FSPLCQS3AQ</b>
24	6 LC Quad, Aqua	High-Density	<b>FSPLCQS6AQ</b>
12	3 LC Quad, Blue	Standard	<b>FSPLCQS3</b>
24	6 LC Quad, Blue	High-Density	<b>FSPLCQS6</b>
12	3 LC Quad, Green	Standard	<b>FSPLCQS3GN</b>
24	6 LC Quad, Green	High-Density	<b>FSPLCQS6GN</b>
12	3 LC Quad, Orange	Standard	<b>FSPLCQS3OR</b>
24	6 LC Quad, Orange	High-Density	<b>FSPLCQS6OR</b>
12	3 LC Quad, Red	Standard	<b>FSPLCQS3R</b>
24	6 LC Quad, Red	High-Density	<b>FSPLCQS6R</b>
12	3 LC Quad, Yellow	Standard	<b>FSPLCQS3Y</b>
24	6 LC Quad, Yellow	High-Density	<b>FSPLCQS6Y</b>



FSPLCQM6AQ



FSPLCQO6



FSPLCQY6



FSPLCQM6BE

### FSP Adapter Panels, ST-style Simplex

#### Phosphor Bronze Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	6 ST-style	Standard	<b>FSPST6</b>
8	8 ST-style	High-Density	<b>FSPST8</b>

#### Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	6 ST-style	Standard	<b>FSPSTSS6</b>



FSPST6



FSPST8

### FSP Adapter Panels, ST-style Duplex

#### Phosphor Bronze Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	3 ST-style Duplex, Blue	Standard	<b>FSPSTD3</b>
12	6 ST-style Duplex, Blue	High-Density	<b>FSPSTD6</b>

#### Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	3 ST-style Duplex, Blue	Standard	<b>FSPSTD3</b>
12	6 ST-style Duplex, Blue	High-Density	<b>FSPSTD6</b>



FSPSTD6

### FSP Adapter Panels, SC to ST-style Duplex

#### Phosphor Bronze Sleeves - Pre-Loaded


Capacity	Type	Version	Catalog No.
6	3 SC to ST-style, Blue	Standard	<b>FSPSCST3</b>
12	6 SC to ST-style, Blue	High-Density	<b>FSPSCST6</b>

#### Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	3 SC to ST-style, Blue	Standard	<b>FSPSCSTDS3</b>
12	6 SC to ST-style, Blue	High-Density	<b>FSPSCSTDS6</b>



FSPSCST3

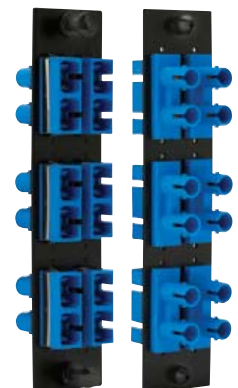

FSPSCST6

### FSP Adapter Panels, MT-RJ

#### Phosphor Bronze Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
12	6 MT-RJ, Beige	Standard	<b>FSPMTRJ6</b>
12	8 MT-RJ, Beige	High-Density	<b>FSPMTRJ8</b>



FSPMTRJ6



FSPMTRJ8

### SC Simplex APC, Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	6 APC, SC Simplex, Green	Standard	FSPSCA6
8	8 APC, SC Simplex, Green	High-Density	FSPSCA8



FSPSCA6



FSPSCA8

### FC/PC Simplex, Zirconia Sleeves - Pre-Loaded

Capacity	Type	Version	Catalog No.
6	6 FC/PC Zirconia split sleeve	Standard	<b>FSPFC6</b>
8	8 FC/PC Zirconia split sleeve	High-Density	<b>FSPFCSS8</b>



FSPFC6

### MTP Adapter Panels - Pre-Loaded

Capacity	Type	Version	Catalog No.
72	6 MTP, Aqua	Standard	<b>FSPMTPAQ6</b>
72	6 MTP, Beige	Standard	<b>FSPMTPBE6</b>
72	6 MTP, Blue	Standard	<b>FSPMTP6</b>



FSPMTPAQ6



FSPMTPBE6



FSPMTP6

### Unloaded FSP Adapter Panels

Capacity	Type	Version	Catalog No.
6	SC Simplex or MT-RJ	Standard	<b>FSPMTRJ6X</b>
8	SC Simplex or MT-RJ	High-Density	<b>FSPMTRJ8X</b>
3	SC Duplex or LC Quad	Standard	<b>FSPSCD3X</b>
6	SC Duplex or LC Quad	High-Density	<b>FSPSCD6X</b>
6	ST-style	Standard	<b>FSPST6X</b>
8	SC Duplex or LC Quad	High-Density	<b>FSPST8X</b>
6	LC Duplex	Standard	<b>FSPLC6X</b>
6	JackPack™ - HXJ jacks/ AV connectors	High-Density	<b>FSPHD6X</b>



FSPMTRJ6X



FSPMTRJ8X



FSPSCD3X



FSPSCD6X



FSPST6X



FSPST8X


### Blank FSP Plates



FSPB

Type	Catalog No.
Blank	<b>FSPB</b>

### DIMENSIONS

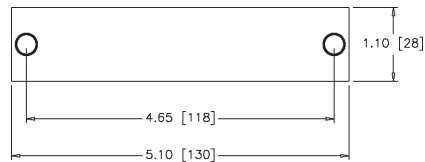

### Hubbell Premise Wiring

HUBBELL INCORPORATED (Delaware)

14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005

Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>

### Worldwide Locations

Hubbell Premise Wiring, Asia Pacific  
Hubbell Canada Inc.  
Hubbell Premise Wiring, Central America  
Hubbell Premise Wiring, China  
Hubbell Premise Wiring, Europe  
Hubbell Wiring Systems, India  
Hubbell Int'l. Inc., Korea Branch

852-2836-7131  
905-839-1138  
506-2260-1616  
86-21-6374 2660  
44-01283 500500  
91-99-0010-3341  
(82 2) 2607 1363

Fax: 852-2836-7132  
Fax: 905-839-9108  
Fax: 506-260-1616  
Fax: 86-21-6374 2799  
Fax: 44-01283 500400  
Fax: 91-80-4022-4033  
Fax: (82 2) 2603 7386

Hubbell Premise Wiring, Latin America  
Hubbell de Mexico, S.A. de C.V.  
Hubbell Premise Wiring, Middle East  
Hubbell Premise Wiring, Puerto Rico  
Hubbell-Taian Co., Ltd., Taiwan  
Hubbell Premise Wiring, Venezuela

305-408-4501  
(5255) 9151-9999  
971-4-393-4192  
787-855-1075  
886-2-2522-1862  
58-212-5156482

Fax: 305-408-8201  
Fax: (5255) 9151-9989  
Fax: 971-4-393-4194  
Fax: 787-855-3265  
Fax: 886-2-2522-1872  
Fax: 58-212-6627258