



ShieldBond


Grounding and Bonding Solutions

Comprehensive Assortment.

Easy to Use.

Pre-Configured Kits.

Pre-Terminated Leads.

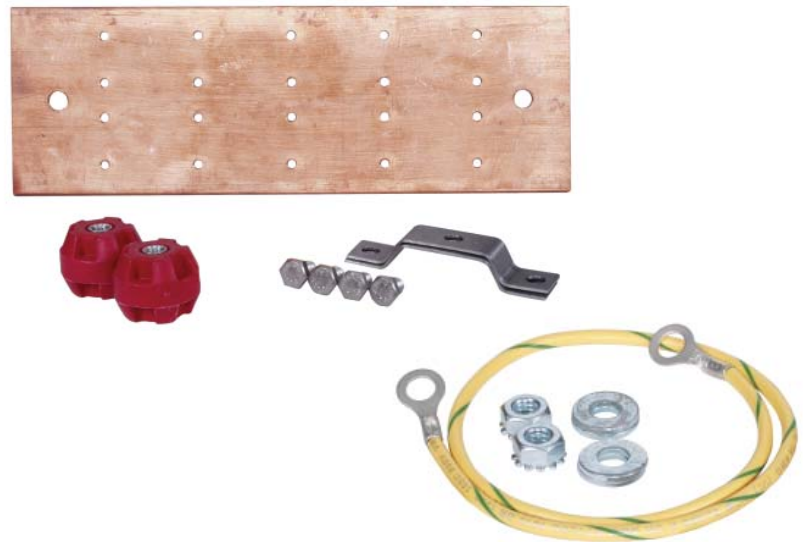

SPECIFICATIONS

- ◆ UL (RKTGB and RKG).
- ◆ NEC Compliant.
- ◆ ANSI/J-STD-607-A (replaces ANSI/EIA/TIA-607).

Grounding and bonding equipment is crucial to maximizing safety, optimizing the performance of active network equipment, and ensuring compliance with codes and standards.

Hubbell grounding and bonding solutions are designed to simplify the task of grounding and bonding by mating quickly into our racks and cabinets and easily connecting together.

19" Rack Mount Ground Bar

Order Information

Assembles into cabinet to provide a common ground for sensitive equipment.

Delivery: 19" x 1" solid copper bar
 (2) #12-24 mounting screws and isolating hardware
 (2) #10-32 mounting screws and isolating hardware

Catalog No. **MCCGBAR**



Wall Mount Cabinet Ground Kit

Order Information

Use as a TGB and to connect doors and chassis to a common ground point on **QUADCAB®** and **RE-BOX®** wall mount cabinets.

Delivery: Ground bar with 1/4"-20 male studs
 (2) 1/4"-20 carriage bolts and isolating hardware
 (2) ground straps

Catalog No. **REKGB**



Economy Ground Strap Kit

Order Information

Delivery: 1 Ground strap with connectors attached

Catalog No. **REKEGS**



Telecom Grounding Bar



Order Information

Provides a common point in the Telecommunications Closet for bonding equipment, cabinets and racks.

Delivery: 12" x 4" x .25" solid copper bus bar (1/4"-20 tapped 20 places)
 Red GFRP isolating standoffs
 (2) .063" thick stainless steel standoff brackets
 (4) 3/8"-16 x .625" hex head bolts and lock washers

Catalog No.

RKTGB

Telecom Bonding Conductor



Order Information

Use to connect common grounding points such as the RKTGB and MCCGBAR to the building ground frame.

Delivery: 7" x .625" universal ground clamp (18ga copper)
 1/4"-20 copper hex nut and brass flat washer
 (1) 1/4"-20 copper ground stud
 (1) brass bell cap
 Solderless ground lug with #12 thru-hole
 (1) #12-24 x .625" #3 Philips combo machine screw with dog point
 (2) #12 ground washers
 15 ft. piece of solid #6 ground wire

Catalog No.

RKG

500A Braided Strap



Order Information

Use to connect sections of runway (ladder rack, etc.) or common grounding points.

Delivery: (10) 15" long (mat'l) straps
 (10) kits mounting hardware

Catalog No.

HPWC GPK10

Bonding Connector



Order Information

Use to field install a screw terminal/connection point in braided strap, service wire, or cable shield.

Delivery: 100 SHIELD BOND® connectors
 1 Field installation tool kit

Catalog No.

BC285SB100



Hubbell Premise Wiring

HUBBELL INCORPORATED (Delaware)

14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005

Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>

Worldwide Locations

Hubbell Premise Wiring, Asia Pacific
 Hubbell Canada Inc.
 Hubbell Premise Wiring, Central America
 Hubbell Premise Wiring, China
 Hubbell Premise Wiring, Colombia
 Hubbell Premise Wiring, Europe
 Hubbell Int'l. Inc., Korea Branch

852-2836-7131
 905-839-1138
 506-309-4158
 8621-6309-0119
 571-245-8940
 44-01283 500500
 82-2-(0)2607-1363

Fax: 852-2836-7132
 Fax: 905-839-9108
 Fax: 506-260-1616
 Fax: 8621-6309-0122
 Fax: 571-340-0925
 Fax: 44-01283 500400
 Fax: 82-2-(0)2603-7386

Hubbell Premise Wiring, Latin America
 Hubbell de Mexico, S.A. de C.V.
 Hubbell Premise Wiring, Middle East
 Hubbell-Taian Co., Ltd., Taiwan
 Hubbell Premise Wiring, Turkey
 Hubbell Premise Wiring, Venezuela

305-408-4501
 (5255) 9151-9999
 971-4-393-4192
 886-2-2522-1862
 90-216-313-5016
 58-416-680-7453

Fax: 305-408-8201
 Fax: (5255) 9151-9989
 Fax: 971-4-393-4194
 Fax: 886-2-2522-1872
 Fax: 90-216-414-8148
 Fax: 58-281-274-7900

DS-M27 10/05