



# HUBBELL QuadCab Wall Mount Enclosure Accessories

## FRONT DOOR

Replacement front doors for QUADCAB® enclosure.

Delivery: 1 door, 1 window (on Plexiglas doors only), 2 hinge barrels, right and left hinges, 4 lock nuts and 4 carriage bolts.

Catalog No. **HQKXDHH\***

**X** = "S" for solid metal door or "W" for window door.

**HH** = Height: "24" for 24"H, "36" for 36"H, or "48" for 48"H.

\* = Finish: Standard finish is Black, for White add "W".



## FAN KIT

Increases ventilation.

Delivery: 1 Fan tray assembly, wired, 1 Kit mounting hardware.

Description	Catalog No.
114 CFM,	<b>HWKF120</b>
120 VAC, 60 Hz, 36 dBA	
114 CFM,	<b>HWKF230</b>
230 VAC, 50 Hz, 36 dBA	



## FAN PLATE/FAN

Fan Delivery: 1 fan, 1 wire guard, 4 lock nuts, screws, and washers and 1 cord with 6' plug.

Description	Catalog No.
Blank plate	<b>H1KB</b>
with 4" fan/PVC conduit knock-out	
Fan, 125V/7A	<b>REKEF</b>



## REUSABLE DUST FILTER

Dust filter for air intake when using fans. Recommended use with gasket kit.

Delivery: A/R Brackets, gaskets, framed filters and 1 Kit assembly hardware.

Catalog No. **HWKFF\***


\* 2 kits are needed for 3' and 4' cabinets.



## THERMOSTAT

Delivery: 1 thermostat, 1 adhesive-backed mounting bracket, 1 wiring harness.

Catalog No. **CTK**

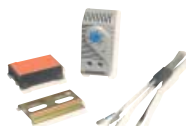

## REAR RAIL KIT

Use to support rear of deep, active equipment or to adapt to accept cage nuts.

Delivery: 2 19" Mounting rails, 1 Kit mounting hardware, 20 screws + 20 washers.

Description	Catalog No.
24"xM6	<b>HWK6M6</b>
36"xM6	<b>HWK9M6</b>
48"xM6	<b>HWK12M6</b>
24"x#12-24	<b>HWK241224</b>
36"x#12-24	<b>HWK361224</b>
48"x#12-24	<b>HWK481224</b>



HWK241224

## MOBILE BASE

Use to convert QUADCAB® Wall Mount Cabinet to floor standing cabinet.

Delivery: 1 mobile base, 4 swivel casters, 4 leveling feet, 1 kit mounting hardware.

Mobile Base	Catalog No.
20" depth	<b>HSQKMB20</b>
26" depth	<b>HSQKMB26</b>
36" depth	<b>HSQKMB36</b>



## 3/4" PLYWOOD BACKBOARD

Provides universal mounting for wall mounted brackets, blocks, splitters, hubs and other devices. Mounts to rear wall.

Delivery: 0.75" APA grade AC plywood painted fire-retardant white, 2 mounting brackets, 1 assembly hardware kit.

Dimensions	Catalog No.
20" x 19"	<b>REKBB20</b>
30" x 19"	<b>REKBB30</b>
40" x 19"	<b>REKBB40</b>



## LOCK KITS

Use to change lock style to meet specific applications.

Delivery: 2 Assembly locks and keys (except CKL716).

Description	Catalog No.
CH751 keyed lock kit	<b>CKL751</b>
333 keyed lock kit	<b>CKL333</b>
Bellcore 7/16 bit lock	<b>CKL716</b>
Cat60 keyed lock kit	<b>CKLCAT60</b>
Cat70 keyed lock kit	<b>CKLCAT70</b>



## FILLER PANEL, 3.5"

Mount to REKZ for use as a shelf. Delivery: 1 panel 2U, 4 HPW screws. Material: 0.09" aluminum. Finish: black anodized.

Catalog No. **MCCBP350**



## Order Information

## PATCH PANEL MOUNTING BRACKET

Use to mount patch panels to rear wall. Provides front access to rear for easy termination.

Delivery: 2 brackets, 1 left hand, 1 right hand.

Finish: Light gray powder coat

Rack units Catalog No.

4 **REK19**

2 **REK19L**



## EQUIPMENT MOUNTING BRACKET

Provides 19" mounting for hubs and other active equipment to rear wall.

Delivery: 2 brackets, 1 left hand, 1 right hand.

Material: 16 gauge steel.

Finish: Light gray powder coat.

Rack units Catalog No.

5 **REKZ**

3 **REKZL**



## 110/66 BLOCK MOUNTING RAILS

Provides mounting for 110 and 66 blocks. Mounts to rear wall.

Delivery: 2 110/66 block mounting rails, 20 #10-24 x 1/2" screws.

Material: 18 ga. cold rolled steel.

Finish: Light gray powder coat.

Catalog No. **REK110**



## DIN RAIL COMMUNICATIONS KIT

Communications DIN rail utility box kit (unloaded).

Catalog No. **HIDRUBCKIT**

See page B28 in the Full Line Catalog for **Style Line®** and Duplex frames.



## DIN RAIL UTILITY BOX

DIN rail compatible: power or data.

Delivery: Box, Surge Receptacle (HBL526GYSA) 15A/125V, mounting strap, clamping plate, terminal screw, grounding screw, auto ground clip, mounting screws.

Material: ABS.

Catalog No. **DRUBTVSS15HI**

See page B28 in the Full Line Catalog for **Style Line®** and Duplex frames.



## 20A POWER KIT

Occupies left or right side of 1 rear panel space.

Delivery:

1 Hubbell surge-protected Duplex receptacle with audible alarm (HBL5262IS).

1 Single-gang work box.

6' Hubbell **POLYTUFF®** non-metallic conduit.

1 Stainless steel face plate.

1 Assembly hardware kit.

Catalog No. **REKP**



## MT10 ADAPTER

Mates MT10 large capacity, 3-channel, surface raceway to the top of **RE-BOX®** cabinets. Routes both electrical and communications cables

Delivery: 1 base, 1 cover, 1 cover hardware kit.

Material: 16 ga. steel construction.

Finish: Powder coat.

Catalog No. **REKMT10**



## FIBER ADAPTER BRACKET

Accepts one fiber FSP adapter panel. Occupies no rear panel spaces.

Delivery: 1 fiber optic bracket.

Material: 16 ga. steel.

Finish: Light gray powder coat.

Catalog No. **REKFP**



## GROUND KITS

Use to ground cabinet components to common ground. Used in conjunction with the MCCGBAR and HPWCGPK10.

Delivery: 1 Grounding bar, 1 Ground strap w/ring terminals, 1 Ground strap w/ring Terminal + Female Faston.

Catalog No. **REKGB**

Delivery: 1 Ground strap with ring terminations.

Catalog No. **REKEGS**



## GASKET KIT

Use to enhance protection against dust and water, and performance of fan and filter.

Delivery: 30' Padded grommet.

Catalog No. **HWKGT**

Delivery: One 10' adhesive-backed foam gasket.

Catalog No. **REKG**



## Hubbell Premise Wiring

HUBBELL INCORPORATED (Delaware)

14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005

Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>

## Worldwide Location

Hubbell Premise Wiring, Asia Pacific  
Hubbell Canada Inc.  
Hubbell Premise Wiring, Central America  
Hubbell Premise Wiring, China  
Hubbell Premise Wiring, Colombia  
Hubbell Premise Wiring, Europe  
Hubbell Int'l. Inc., Korea Branch

852-2836-7131  
905-839-1138  
506-309-4158  
8621-6309-0119  
571-245-8940  
44-01283 500500  
82-2-(0)2607-1363

Fax: 852-2836-7132  
Fax: 905-839-9108  
Fax: 506-260-1616  
Fax: 8621-6309-0122  
Fax: 571-340-0925  
Fax: 44-01283 500400  
Fax: 82-2-(0)2603-7386

Hubbell Premise Wiring, Latin America  
Hubbell de Mexico, S.A. de C.V.  
Hubbell Premise Wiring, Middle East  
Hubbell-Taian Co., Ltd., Taiwan  
Hubbell Premise Wiring, Turkey  
Hubbell Premise Wiring, Venezuela

305-408-4501  
(5255) 9151-9999  
971-4-393-4192  
886-2-2522-1862  
90-216-313-5016  
58-416-680-7453

Fax: 305-408-8201  
Fax: (5255) 9151-9989  
Fax: 971-4-393-4194  
Fax: 886-2-2522-1872  
Fax: 90-216-414-8148  
Fax: 58-281-274-7900