



ZOBOX® Zone Boxes

Access Floor and In-Ceiling

Raised Access Floor Box Capacity
up to 192-Ports.

Ceiling Box Capacity: 4 or 8
Rack Units; 96- and 192-port,
Fully Loaded.

Floor Box Capacity: 5 or 7
Rack Units; 120-port.

FEATURES

Floor Box

- Cover available.
- Cable entry behind the connecting hardware, exits from the face.

Ceiling Box

- Lock kits available.
- Continuous hinged door.
- Door accepts sized ceiling tile panel.

SPECIFICATIONS

- ◆ Aluminum enclosure, .060.
- ◆ Houses 24- and 48-port 19" Patch Panels.
- ◆ Tapped holes in brackets: #12-24.

Floor Box

- ◆ Mounts in standard 24" x 24" raised floor panel spaces.

Ceiling Box

- ◆ Ventilation fan included (9CFM) active unit only.
- ◆ Active equipment max. dimensions: 3.5"H x 15.5"D x 19"W.
- ◆ Mounts in standard 24"x24" drop ceiling panel spaces.
- ◆ Structural mounting hardware supplied by installer.

STANDARDS/LISTINGS/VERIFICATIONS

- UL listed, file no. E129878, plenum rated.

APPLICATIONS

- ▲ Install under raised access floors.
- ▲ Install in ceiling grids.
- ▲ Zone Cabling.

Accepts Hubbell 24- and
48-port patch panels.



Zone Ceiling Box



Swivel down, 45°
mounting brackets.

Access Floor Zone Box

Hubbell's **ZOBOX®** Zone Boxes for raised access floor applications are rugged, high-capacity boxes designed for zone cabling. Engineered for low voltage, standard 19" rack mountable panels, the brackets mount at a 45° angle. The mounting brackets swivel down for easy accessibility when terminating during moves, adds and changes. In addition, the design allows for proper cable bend radius.

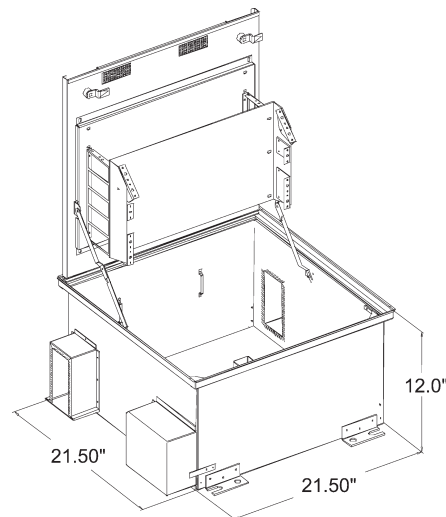
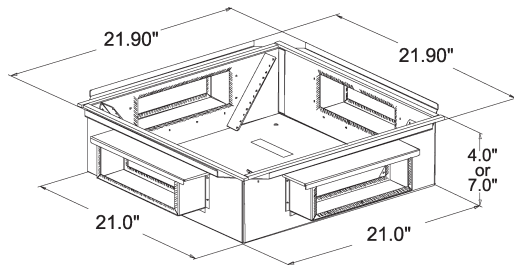
Hubbell's **ZOBOX®** Ceiling Boxes are supplied fully assembled in two different styles. One style is suitable for panels only (passive), while the other is suitable for both passive and active equipment. A ventilation fan is included with Catalog No. ZCB7UA, where active equipment will be used.

ORDERING INFORMATION**ZOBOX® - Access Floor Box****Order Information**

Delivery:	1 aluminum enclosure 4 support brackets		4 fire-rated foam kits for cable entries and exits 4 Cable entry port covers		4 leveler bolts			
Description	Rack Units	Max.Port Capacity	External Dims HxWxD	Internal Dims HxWxD	Weight Lbs.	Min.Floor Depth	Cable Entry Dims	Catalog No.
Zone Access Floor Box	4	96	4.12"x21.9"x21.9"	4"x21"x21"	14	6"	3.5"x11"	ZAFB4U6
Zone Access Floor Box	8	192	7.12"x21.9"x21.9"	7"x21"x21"	15	8"	3.5"x11"	ZAFB8U8
Zone Access Floor Box Cover	-	-	22"X22"	-	5	-	-	ZAFBC
Zone Access Floor Box Lock Key	-	-	-	-	-	-	-	KEY3344

ZOBOX® - In-Ceiling Box**Order Information**

Delivery:	1 Aluminum enclosure 2 fire-rated foam kit for cable entries and exits Hinged door plate 9 CFM, 12 volt fan and transformer (active unit only)			2 knob assemblies Support brackets Equipment mounting assemblies				
Description	Rack Units	Max.Port Capacity	External Dims HxWxD	Door Weight Capacity Lbs.	Weight Lbs.	Total Weight Capacity Lbs.	Cable Entry Dims	Catalog No.
Passive Zone Ceiling Box	5	120	12"x24"x24"	25	38	75	6"x3"	ZCB5UP
Active Zone Ceiling Box	7	120 plus	12"x24"x24"	25	39	75	3.5"x11"	ZCB7UA
2U Active Equip								
Zone Ceiling Box Lock Kit	-	-	-	-	-	-	-	ZCBLKIT
Zone Ceiling Box Lock Key	-	-	-	-	-	-	-	KEY333

DIMENSIONS**Hubbell Premise Wiring**

HUBBELL INCORPORATED (Delaware)

14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005

Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>**Worldwide Locations**

Hubbell Premise Wiring, Asia Pacific
Hubbell Canada Inc.
Hubbell Premise Wiring, Central America
Hubbell Premise Wiring, China
Hubbell Premise Wiring, Colombia
Hubbell Premise Wiring, Europe
Hubbell Int'l. Inc., Korea Branch

852-2836-7131
905-839-1138
506-309-4158
8621-6309-0119
571-245-8940
44-01283 500500
82-2-(0)2607-1363

Fax: 852-2836-7132
Fax: 905-839-9108
Fax: 506-260-1616
Fax: 8621-6309-0122
Fax: 571-340-0925
Fax: 44-01283 500400
Fax: 82-2-(0)2603-7386

Hubbell Premise Wiring, Latin America
Hubbell de Mexico, S.A. de C.V.
Hubbell Premise Wiring, Middle East
Hubbell-Taian Co., Ltd., Taiwan
Hubbell Premise Wiring, Turkey
Hubbell Premise Wiring, Venezuela

305-408-4501
(5255) 9151-9999
971-4-393-4192
886-2-2522-1862
90-216-313-5016
58-416-680-7453

Fax: 305-408-8201
Fax: (5255) 9151-9989
Fax: 971-4-393-4194
Fax: 886-2-2522-1872
Fax: 90-216-414-8148
Fax: 58-281-274-7900

DS-M43 10/05