

Unscreened Category 5e Copper LSZH Patch Cords


Optronics Category 5e unscreened patch cord range exceeds the transmission line performance requirements of IEC and TIA for CLASS D/Category 5e systems. The patch cords are designed for mechanical and electrical reliability, using quality materials and processes, to provide a patch cord solution which delivers a consistent high level of systems performance, whilst incorporating design features that allow a "one style fits all" patch cord application. The low profile moulded boot and snag free latching allows the patch cords to be deployed within even the most densely populated network installations, deploying the latest blade server technology.

Each Category 5e patch cords are manufactured and tested in accordance with IEC 61935-2 and comply with the requirements of ISO/IEC 11801 (2nd Edition): 2010 and support all applications designed for CLASS D/Category 5e applications such as 1000BASE-T (Gigabit Ethernet), ATM 155, 100BASE-Tx, Token Ring 100Mbs-1 and 1G FCBASE-T.

Features/Benefits

- > Class D/Category 5e standards compliant
- > Electrically compliant beyond 100MHz
- > PVC sheathed cable
- > Low profile moulded strain relief boot for use with blade servers
- > Integral anti-snag latch as standard
- > 8 standard colours
- > 7 standard lengths (1m, 2m, 3m, 5m, 10m, 15m & 20m)
- > Other lengths and colours available upon request*
- > Individually bagged with traceability information
- > RoHS compliant
- > REACH / SVHC compliant regulation (EC) No. 1907/2006
- > Part of the 20 year Optronics systems warranty programme

* Subject to MOQ

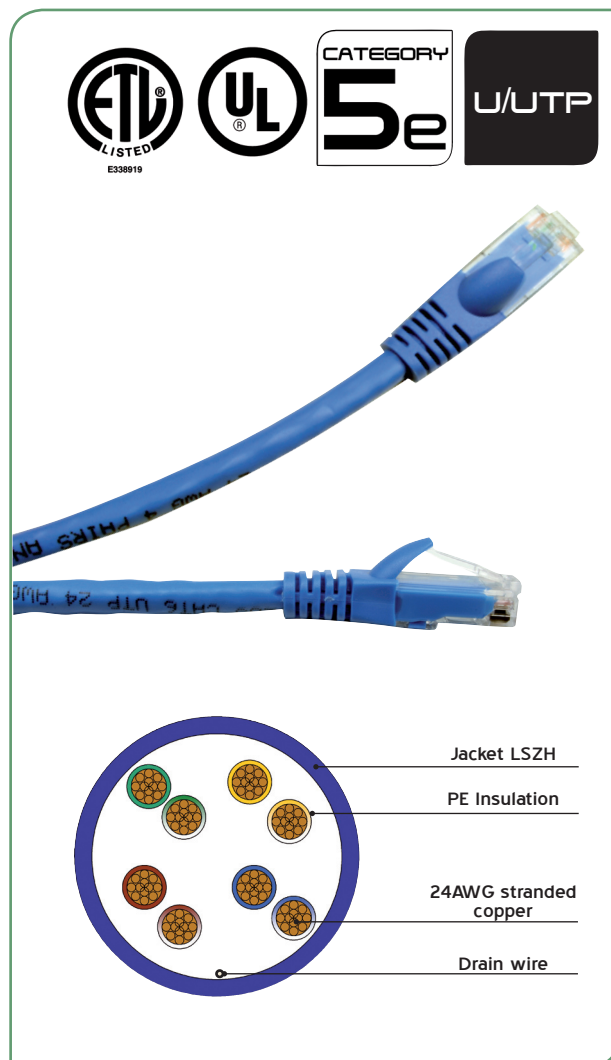

Technical Specification

CONSTRUCTION	VALUE	
Conductors	AWG	24
	Size mm	7/0.20 +/- 0.008
	Material	Bare Copper
Insulators	Diameter mm	0.98+/-0.05
	Material	Polyolefin
Jacket	External O.D.	6.0 +/- 0.20
	Thickness mm	0.5
	Material	LSZH

Unscreened Category 5e Copper LSZH Patch Cords

Ordering Information

	PART NUMBER	METRE
grey	520-101	1
	520-102	2
	520-103	3
	520-105	5
	520-110	10
	520-115	15
red	520-120	20
	520-201	1
	520-202	2
	520-203	3
	520-205	5
	520-210	10
blue	520-215	15
	520-220	20
	520-301	1
	520-302	2
	520-303	3
	520-305	5
	520-310	10
	520-315	15
	520-320	20

	PART NUMBER	METRE
yellow	520-401	1
	520-402	2
	520-403	3
	520-405	5
	520-410	10
	520-415	15
green	520-520	20
	520-501	1
	520-502	2
	520-503	3
	520-505	5
	520-510	10
white*	520-515	15
	520-520	20
	520-601	1
	520-602	2
	520-603	3
	520-605	5
	520-610	10
	520-615	15
	520-620	20

	PART NUMBER	METRE
black*	520-701	1
	520-702	2
	520-703	3
	520-705	5
	520-710	10
	520-715	15
orange*	520-720	20
	520-801	1
	520-802	2
	520-803	3
	520-805	5
	520-810	10
	520-815	15
	520-820	20

*White, Orange and Black may be subject to minimum order quantities