


Beams

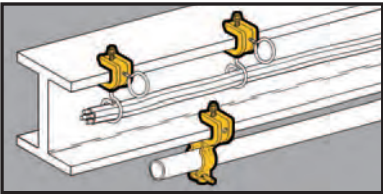

- BC442 fits beam flanges 1/8" to 5/8". BC442-6 fits beam flanges up to 3/4".
- Finish: Zinc Plated
- Static Load Capacity:
BC442 = 100 Lbs.
BC442-6 = 200 Lbs.

Beam Fasteners




UPC/Part Number	Catalog Number	Description	Box Qty.
781011 18278	BC442	Accepts 1/4"-20 Threaded Rod or 1/4"-20 Threaded Bridle Rings	50
781011 04283	BC442-6	Accepts 3/8"-16 Threaded Rod	25



UPC/Part Number	Catalog Number	Conduit Rigid	Size EMT	Box Qty.
781011 19850	BL1400-C442	1/2"	1/2"	50
781011 19851	BL1410-C442	3/4"	3/4"	50
781011 19852	BL1420-C442	1"	1"	50
781011 19853	BL1425-C442	--	1 1/4"	50
781011 19854	BL1430-C442	1 1/4"	1 1/2"	50
781011 19855	BL1440-C442	1 1/2"	--	25
781011 19856	BL1450-C442	2"	2"	25

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

- Can be used with 1/4"-20 and 3/8"-16 threaded rod or bridle rings.
- Fits beam flanges through 1/2" thick.
- Safety Factor of 5.
- Finish: Zinc-Plated

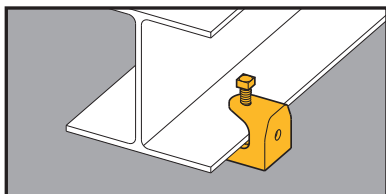

Beam Fasteners



UPC/Part Number	Catalog Number	Rod Size	Static Load Cap.	Box Qty.
781011 55333	B444-1/4	1/4"-20	150 lbs.	50
781011 55338	B444-5/16	5/16"-18	150 lbs.	50
781011 55343	B444-3/8	3/8"-16	350 lbs.	25