


Cat 5e panel blocks, 12-port, T568B, 10.7" x 3.1"

OR-851044559

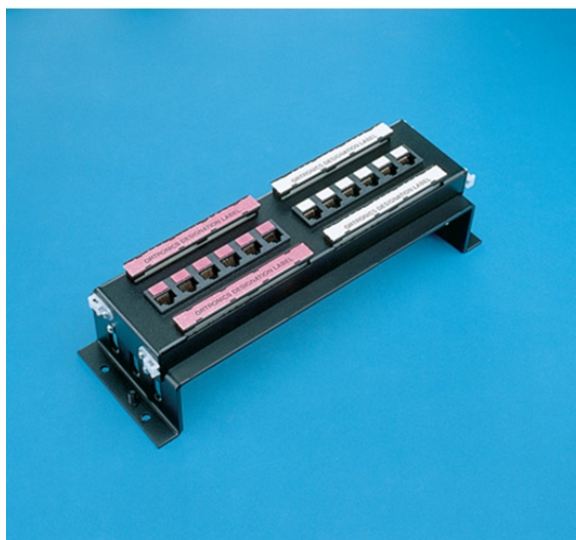

Category 5e Front Access Mini Patch Panel provides a 12-port 110 termination cross connect. It is wall mountable with rack mount options also available. It has T568B wiring and is 10.7" x 3.1".

features & benefits

- Front design
- Wall or rack mount options
- 110 termination for 22, 24, and 26 AWG solid cable
- Standard AT&T 100-pair JP blocks footprint
- Includes snap-on termination designation covers



specifications

General Info

Mod Jack Wiring: T568B
Number Of Ports: 12

Listing Agencies/Third Party Information

CSA Listing Info: LR 90894
CUL Listing No: E131600
UL Listing No: E131600

Construction Information

Component1: Panel & Base
Component2: Panel cover
Component3: Linear modular contact

Component4: 110D connecting block housing

Component5: IDC contact

Finish Plating1: Painted black -texture

Finish Plating2: Painted black - texture

Finish Plating3: 50 micro inch gold or GTX

Finish Plating5: 63/37 Tin Lead Plating

Material1: 12GA. (.105") Cold Rolled Steel

Material2: 0.060" Aluminum

Material3: Phosphor Bronze

Material4: ABS UL94V-0

Material5: Phosphor Bronze

Dimensions

Cable Diameter Range: 22-26 AWG

Depth Metric: 78.74 mm

Height Metric: 90.424 mm

Height U S: 3.56 in

Width Metric: 271.526 mm

Technical Information

Category Rating: Category 5e

Performance Rating: Category 5e