


Replaced by
PHD5E6U48HM.
Please access
product
information for
PHD5E6U48HM.

OR-851044973

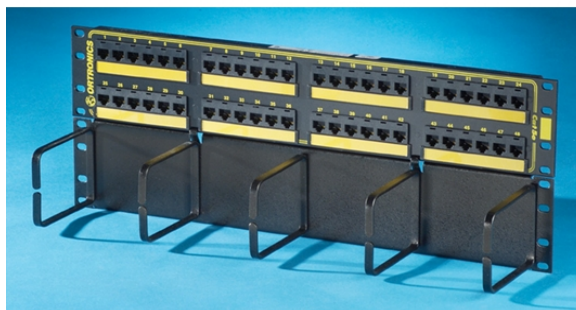

Replaced by PHD5E6U48HM. Please
access product information for
PHD5E6U48HM.

features & benefits



- High density design
- 110 termination
- Hinged front cable management panel
- Wire management bar included
- Front and rear designation strips

specifications

General Info

Mod Jack Wiring: T568B
Number Of Ports: 48

Assembly/Installation Information

Installation Tips: The cables should be routed from both sides of the Relay Rack rather than from one side only.
Maintain pair twist to within .50" (13 mm) of point of termination for maximum data performance.

Listing Agencies/Third Party Information

CSA Listing Info: LR 90894
CUL Listing No: E131600
UL Listing No: E131600

Construction Information

Component1: Panel
Component2: Six-port jack housing
Component3: Linear modular contact
Component4: 110D connecting block housing
Component5: IDC contact
Finish Plating1: Painted black - texture, with white silkscreen
Finish Plating3: 50 micro inch gold or GTX
Finish Plating5: 63/37 Tin Lead Plating
Material1: 0.125" Aluminum
Material2: ABS UL94V-0
Material3: Phosphor Bronze
Material4: ABS UL94V-0
Material5: Phosphor Bronze

Dimensions

Cable Diameter Range: 22-26 AWG
Depth Metric: 3.175 mm
Height Metric: 177.8 mm
Height U S: 7"
Width Metric: 482.6 mm

Technical Information

Category Rating: Category 5e
Performance Rating: Category 5e
Product Fits Into: Mighty Mo Racks and Cabinets