


TracJack USOC six-position RJ25C, Fog White

OR-63700005

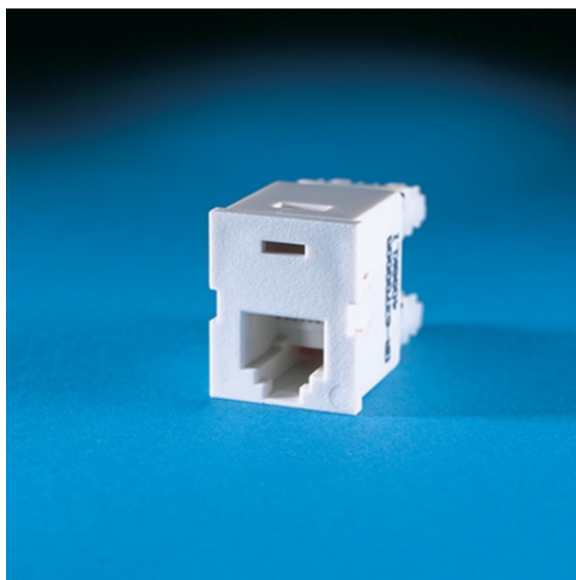

TracJack Module provides a single RJ25C six-position jack. TracJack is a versatile single jack solution in a front-load footprint which allows a choice of up to six jacks/connectors to fit in a single gang plate

features & benefits

- Front removable
- Traditional 110 termination
- Standard TracJack footprint
- Icon compatible, with Category 5e marking on jack face



specifications

General Info

Category Performance Application: USOC six-position
Color: Fog White
Footprint: TracJack
Number Of Ports: 1-port

Listing Agencies/Third Party Information

CUL Listing No: E131600
UL Listing No: E131600

Construction Information

Component1: Plastic TracJack Housing
Component2: Array of six linear modular contacts

Component3: IDC contacts, 110 D2

Component4: Printed circuit board

Finish Plating2: Nickel plating and a minimum of 50 micro inches of selective gold plating in contact area

Finish Plating3: Nickel plating and tin lead over plate

Material1: High Impact Thermoplastic ABS 94V-0

Material2: Phosphor bronze

Material3: Phosphor bronze

Material4: Two-sided FR-4 epoxy resin/glass base with solder mask

Dimensions

Depth Metric: 34.04 mm

Height Metric: 23.37 mm

Height U S: .92"

Width Metric: 18.54 mm

Buy American Act Compliance

Country of Origin: MEXICO

Buy American Act Status: Trade Agreement Act Compliant