


Shielded TracJack High Density Patch Panel Kit for 24 shielded modules

OR-PHDTJS24

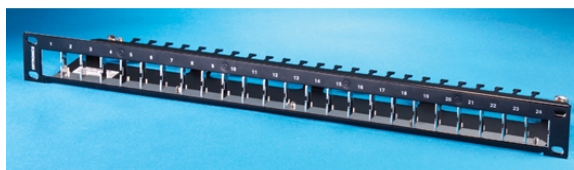

Shielded TracJack high density patch panel kit accepts 24 Shielded TracJack modules, 19" x 1.75".

features & benefits

- **High density design:** Maximizes rack space.
- **Rugged shelf construction:** Provides a means for cable management and strain relief.
- **Grounding lugs are provided on both sides of panel:** Supports up to # 6 ground wire and allows for easy accessibility and termination.
- **Front labels are provided:** Supports customized port identification.



specifications

General Info

Mod Jack Wiring: Field defined
Number Of Ports: Up to 24

Listing Agencies/Third Party Information

ETL Standard: Yes

Construction Information

Component1: Panel
Component2: Designation Bezel
Component3: Designation Cover
Component4: Designation Strip

Component5: Ground terminal
Finish Plating1: Painted Black
Finish Plating3: Clear
Finish Plating4: Yellow/White
Finish Plating5: Tin Plated
Material1: .094" Steel
Material2: ABS UL94V-0
Material3: PVC
Material4: Paper
Material5: Copper

Dimensions

Depth Metric: 101.854 mm
Height Metric: 44.45 mm
Height U S: 1.75"
Width Metric: 482.6 mm

Technical Information

Performance Rating: Field defined