


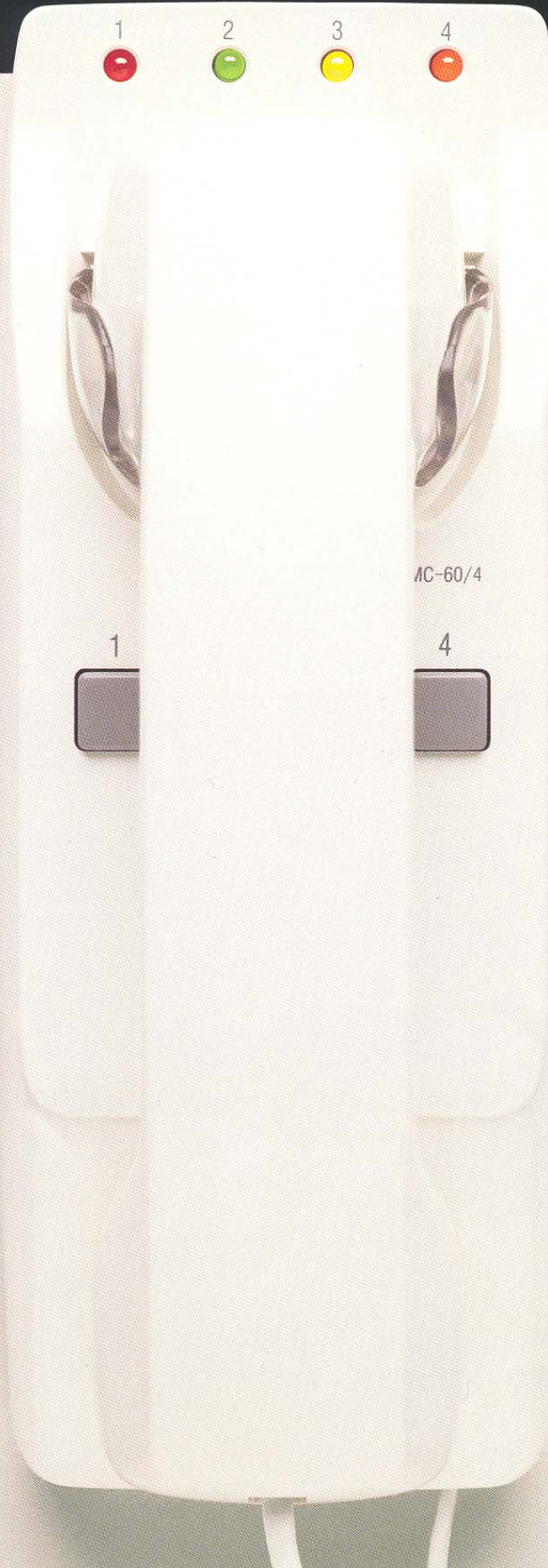

MARKETCOM 60/4 Communications/Paging System



The reinforced telephone-style cord jack makes it a snap to replace the handset cord.



Because more than 80 percent of all retail store communications occurs internally, a separate paging system that complements your phone system makes more sense than ever.

Which is why the improved MarketCom 60/4 paging system makes more sense than ever. Proven in thousands of retail stores, it is the most versatile and reliable paging system available.

Besides being technically superior to other paging systems, it also provides years of trouble-free use. Everything but the easy-to-replace coil cord has a long three-year warranty.

Plus the MarketCom 60/4 is simpler to use than a telephone. Push one button to page, and another to answer. The 60/4 now features a different color indicator light for each communication channel for quick call identification. Which means training time is next to nothing.

If you want a paging system that you can install today and literally forget about during many long years of use, consider the improved MarketCom 60/4.

The paging button is located on the underside of the handset to protect it and to help prevent accidental paging.

The MarketCom 60/4 is a "people finder" paging system designed for large retail stores, manufacturing plants, and warehouses.



How the MarketCom 60/4 Paging System Earns Its Reputation For Simple Reliable Performance.

*Four communication
channels, plus a separate
paging channel.*

*Color-differentiated
channel indicator lights.*

*Oversized, shatter-proof
Lexan® cradle.*

*Up to 60-station
capacity.*

*Easy, push-button
channel selection.*

*Durable, high-impact
ABS plastic handset
and body.*

*Reinforced cord
jacks.*







*Heavy-duty
telephone-style
coil cord.*



MarketCom 60/4 System Specifications

Power Source:	DC 24V. Use PS-24N Power Supply.	Wiring:	7 conductor, low capacitance. Use Aiphone wire #852207. (Do not use twisted paired wire.)
Consumption:	Max 70mA (in paging mode).	Wiring Distance:	1700' w/22 AWG. 4000' w/18AWG. (Between MC-A/A or PG-C series amplifier and farthest MC-60/4.)
Calling:	By page.		
Communication:	Simultaneous via handset after pressing a channel selector button. Conference calling up to 3 stations.		
Communication Paths:	4 channels: red, green, amber, orange.		32' w/18 AWG. (Between MC-A/A or PG-C series amplifier and power supply PS-24N.)
Station Capacity:	Max. 60 stations (in 6 blocks each with 10 MC-60/4A stations max. per block).	Dimensions:	9 1/4" H x 3 1/2" W x 3 1/2" D.
Paging Adaptor:	Built into all PG-C series amplifiers or use MC-A/A page adaptor.	Weight:	MC-60/4A: 1.06 lbs. MC-60/4B: 2.6 lbs.
Specifications subject to change without notice.			

MarketCom 60/4 System Components

					
Amplifiers Wall mount with built-in paging adaptor PG-20C 20-watt PG-50C 50-watt PG-100C 100-watt	Tuner PGT-8: AM/FM for background music	Power Supply PS-24N: 24V DC, 2.0A	Speakers Ceiling: (SP-5N) Horn: (AH-16TN, AH-32TN)	Desk Station MC-60/4B: matching red, green, amber and orange channel indicators	Pedestal Stands MC-S12: 12" MC-S23: 23"

The expanded capacity MarketCom 60/4A is compatible with, and priced the same, as the older model MC-3 paging system. For particulars, please ask your Aiphone qualified installer.



ISO 9001 CERTIFIED



Communication systems for business, home & industry.



DEMING PRIZE