

## AXIS T97A10 Enclosure

IP66-rated wall-mount enclosure



- > Outdoor ready
- > Easy to install
- > Wall-mount

AXIS T97A10 is a protective enclosure that allows Axis video network products to be installed outdoors and protected against the weather.

AXIS T97A10 is IP66-rated, and allows the protected unit to operate in a temperature range of 0 °C to 45 °C (32 °F to 113 °F).

The network video unit is easily mounted inside the enclosure with two screws. Fastening the top cover secures and guarantees the installation.

The enclosure is designed for wall mounting, and for vandal-resistant protection, a metal wall mount box can be used. AXIS T97A10 can also be installed on a pole, using the wall mount box together with a pole mount plate.


Supported Axis video products: AXIS Q7401 Video Encoder, AXIS P8221 Network I/O Audio Module and AXIS P7701 Video Decoder.

## Technical specifications – AXIS T97A10 Enclosure

General	
<b>Supported products</b>	AXIS Q7401 Video Encoder AXIS P8221 Network I/O Audio Module AXIS P7701 Video Decoder
<b>Casing</b>	Polycarbonate Color: White NCS S 1002-B
<b>Dimensions (HxWxD):</b>	187 x 147 x 75 mm (7.4" x 5.8" x 3.0")
<b>Environment</b>	Outdoor Wall-mount Pole-mount (requires use of optional accessories)
<b>Operating conditions</b>	<b>AXIS P8221:</b> For the unit inside the enclosure: 0 °C to 45 °C (32 °F to 113 °F) <b>AXIS P7701:</b> For the unit inside the enclosure: 0 °C to 45 °C (32 °F to 113 °F) <b>AXIS Q7401:</b> For the unit inside the enclosure: 0 °C to 45 °C (32 °F to 113 °F)
<b>Protection rating</b>	IEC 60529 IP66-rated, ABS UL-94V0 rated
<b>Weight</b>	0.7 kg (1.5 lb.)
<b>Included accessories (for wall mounting)</b>	Holders, wood screws, screws for holders, concrete screws, concrete plugs (5mm drill)

More information and a configuration tool is available at [www.axis.com/accessories](http://www.axis.com/accessories)

### Dimensions mm (inch)

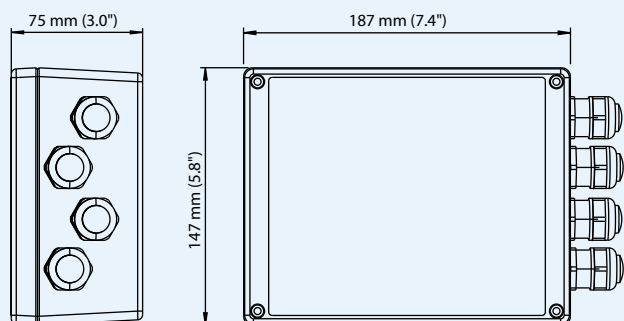

### Optional accessories

Pole mount plate\*



\* Requires wall mount and use of mounting tool

Wall mount



Mounting tool

