

Product Information Sheet

DOUBLE-SIDED NARROW VERTICAL CABLING SECTION

Provides double-sided 3.65" cable run between equipment racks. Mounts to any CPI rack upright channel post; 1.38" x 2.25" oval ports spaced at 11.62" intervals along center separator allow for convenient cable and wiring pass through. Vertical slots secure optional Saf-T-Grip® Cable Management straps for neatly bundled cables.

- Bolts to CPI Standard and Universal racks and the 6" Deep High-Density Frame
- Includes formed cabling section, lockable cabling latches (12" between latches.), protective edge guards, and mounting hardware
- 3.65"W x 12.75"D; double-sided cable trough
- 1.38" x 2.25" oval pass through ports every 11.62"
- 9' version consists of 7' section with a 2' extension
- Mounting hardware included
- Sold individually

Part Number	Description	Shipping Weight
12096-X03	7' Double Sided Narrow	24 lb
12096-X15	8' Double Sided Narrow	27 lb
12096-X08	9' Double Sided Narrow	28 lb


* Note: X=color: 1=Gray, 2=White, 5=Clear, 7=Black

Double-Sided Narrow Vertical Cabling Section Extensions


Part Number	Description	Shipping Weight
11781-X02	One-Foot Extension, 3.65"W x 12.75"D	4 lb
11782-X02	Two-Foot Extension, 3.65"W x 12.75"D	7 lb

* Note: X=color: 1=Gray, 2=White, 5=Clear, 7=Black


Double-Sided Narrow

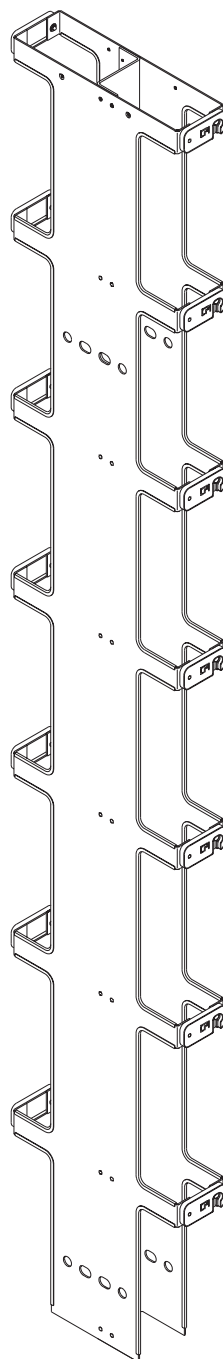

One-Foot Extension

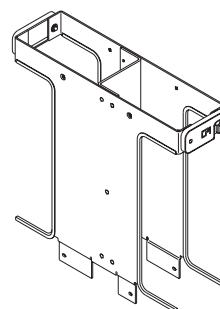

Two-Foot Extension

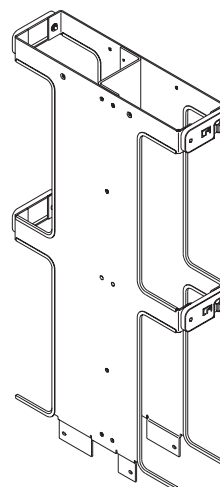

800-834-4969 in US & Canada • www.chatsworth.com



CHATSWORTH PRODUCTS, INC.

©2002 Chatsworth Products, Inc. 5/02/GT