

Product Information Sheet


UNIVERSAL HORIZONTAL CABLE MANAGER

Provides an attractive and highly functional horizontal pathway for patch cords and multimedia applications using coax, copper and fiber optic cables. Patch cords may also be routed to the back of the rack through the flanged pass-through slot. After routing the cables or cords, simply snap-on the hinged cover for a clean, professional appearance.

- Single-sided designs manage patch cords.
Double-sided designs manage patch cords and premise cables.
- Use with CPI's Vertical cabling sections to create a complete cable management system.
- Patented cable guide fingers ensure proper cable bend and withstand wear.
- Snap-on, hinged covers create a professional look.

Estimated cable capacities:

See the cable fill table at www.chatsworth.com/cablefill

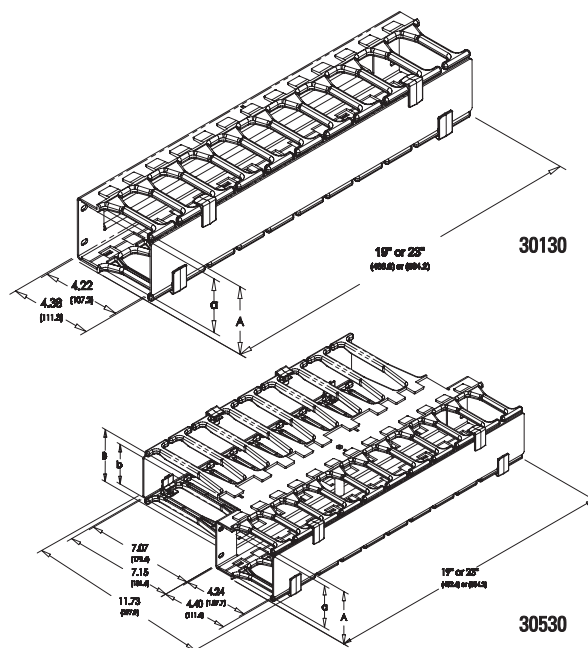

Double-Sided Cable Manager

Part Number	Description	Shipping Weight
30529-719	19"W x 11.73"D x 1 RMU, Black	5 lb
30529-723	23"W x 11.73"D x 1 RMU, Black	6 lb
30530-719	19"W x 11.73"D x 2 RMU, Black	6 lb
30530-723	23"W x 11.73"D x 2 RMU, Black	7 lb
30531-719	19"W x 11.73"D x 3 RMU, Black	6 lb
30531-723	23"W x 11.73"D x 3 RMU, Black	7 lb

Single-Sided Cable Manager

Part Number	Description	Shipping Weight
30139-719	19"W x 4.96"D x 1 RMU, Black	2 lb
30139-723	23"W x 4.96"D x 1 RMU, Black	3 lb
30130-719	19"W x 5.14"D x 2 RMU, Black	3 lb
30130-723	23"W x 5.14"D x 2 RMU, Black	4 lb
30131-719	19"W x 5.14"D x 3 RMU, Black	4 lb
30131-723	23"W x 5.14"D x 3 RMU, Black	5 lb
30339-719*	19"W x 6.26"D x 1 RMU, Black	3 lb
30339-723*	23"W x 6.26"D x 1 RMU, Black	3 lb
30330-719*	19"W x 6.44"D x 2 RMU, Black	4 lb
30330-723*	23"W x 6.44"D x 2 RMU, Black	5 lb
30331-719*	19"W x 6.44"D x 3 RMU, Black	5 lb
30331-723*	23"W x 6.44"D x 3 RMU, Black	6 lb

Note: The deep panel is used when Double-Sided MCS Master Cabling Sections are center-mounted on 3"D Racks.

Part Number		Dimensions			
19"	23"	A	a	B	b
30139-719	30139-723	1.73 (43.9)	1.02 (25.9)		
30130-719	30130-723	3.48 (88.4)	2.77 (70.4)		
30131-719	30131-723	5.23 (132.8)	4.52 (114.8)		
30339-719	30339-723	1.73 (43.9)	1.02 (25.9)		
30330-719	30330-723	3.48 (88.4)	2.77 (70.4)		
30331-719	30331-723	5.23 (132.8)	4.52 (114.8)		
30529-719	30529-723	1.73 (43.9)	1.00 (25.4)	1.67 (42.4)	0.85 (21.6)
30530-719	30530-723	3.46 (87.9)	2.75 (69.9)	3.42 (86.9)	2.60 (66.0)
30531-719	30531-723	5.23 (132.8)	4.50 (114.3)	5.17 (131.3)	4.44 (112.8)

800-834-4969 in U.S. & Canada • www.chatsworth.com



CHATSWORTH PRODUCTS, INC.

©2008 Chatsworth Products, Inc. All rights reserved. CPI, Saf-T-Grip, Seismic Frame, SlimFrame and MegaFrame are federally registered trademarks of Chatsworth Products, Inc. CPI Passive Cooling, Cube-iT Plus, TeraFrame, Thinline II and QuadraRack are trademarks of Chatsworth Products, Inc. All other trademarks belong to their respective companies.