


Part Number.....7219-20AR

Made in the USA..... Yes
 Mounting..... Rack Mount
 AC Rating Volts..... 125
 AC Rating Amps..... 20
 AC Rating Watts..... 2400
 AC Rating Frequency-Hz..... 50/60 HZ
 Circuit Breaker..... 20A
 Pilot Light..... Green
 On/Off Switch..... None
 Over Current Protection..... CB
 Power Cable AWG..... 12/3 SJT
 Power Cable Length..... 15'
 Plug Type..... NEMA 5-20P
 Receptacle Type..... NEMA 5-20R
 Receptacle Style..... Duplex
 Receptacle Quantity..... 3
 Max. Output per Powerstrip..... 20 Amp
 Joule Rating..... N/A
 UL Rating..... 60950-1
 Clamping Level..... N/A
 Response Time..... N/A
 Max. Surge Current..... N/A
 EMI/RFI Noise Reduction..... N/A
 Surge Indicator Red LED..... N/A
 Connected Equipment Warranty.... N/A
 Product Warranty-GLCC..... 1 year
 Certification/Agency Approvals..... UR & CSA Approved
 Unit Weight lbs..... 8

Rev.	Date	Dr.	CKD./APVD.	Description
A	02/04/02	TK	--	CHANGED INDICATOR LIGHT TO PILOT LIGHT

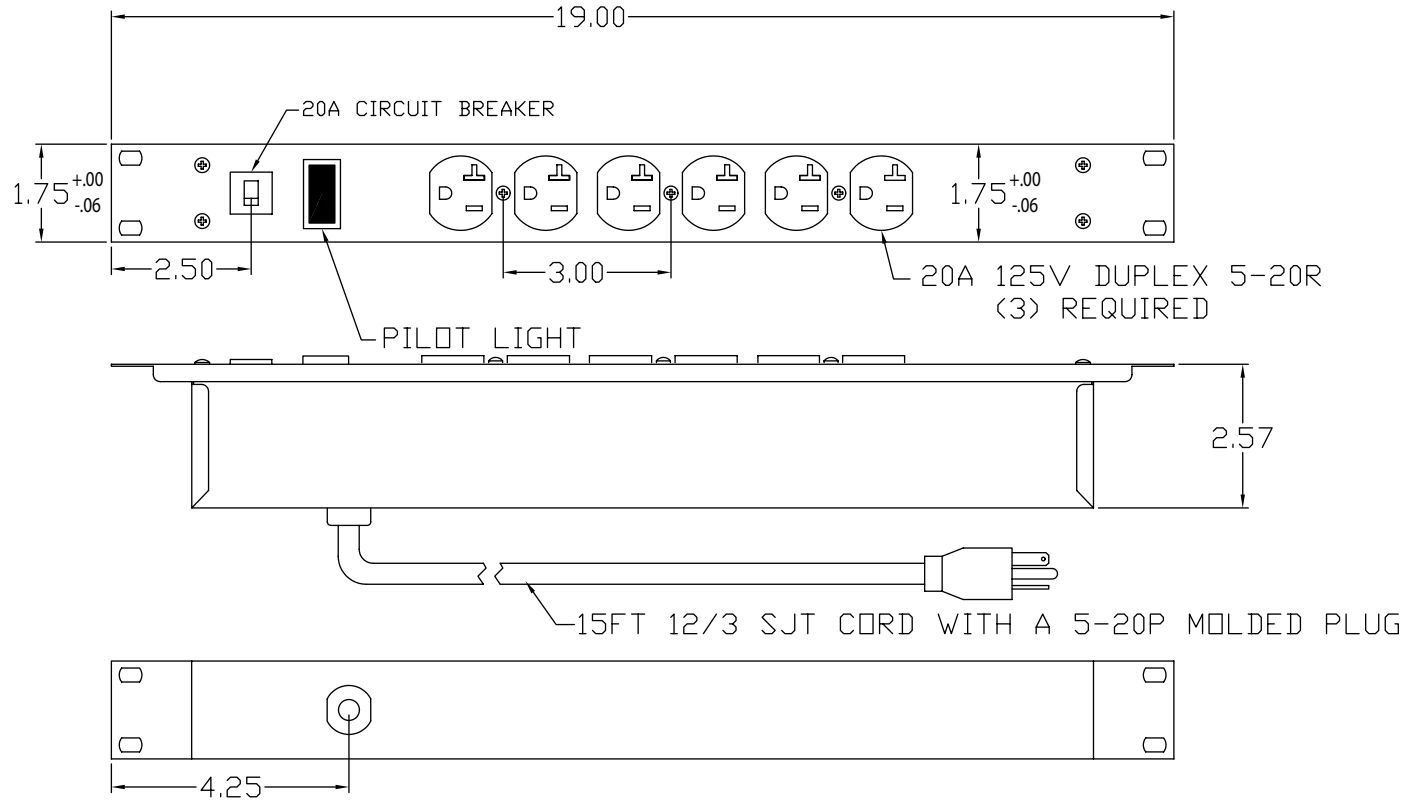

TOLERANCES UNLESS OTHERWISE SPECIFIED	Dr. T. KAUPP	Date 12-20-00	Title
DECIMALS 0.0 = ± 0.100 0.00 = ± 0.020 0.000 = ± 0.005 ANGLES = ± 1°	Des.	Date	721920AR
	APVD.	Date	
	SCALE N/A	SHT 1 of 1	
			DWG No. 721920AR.DWG
			Rev. ---