
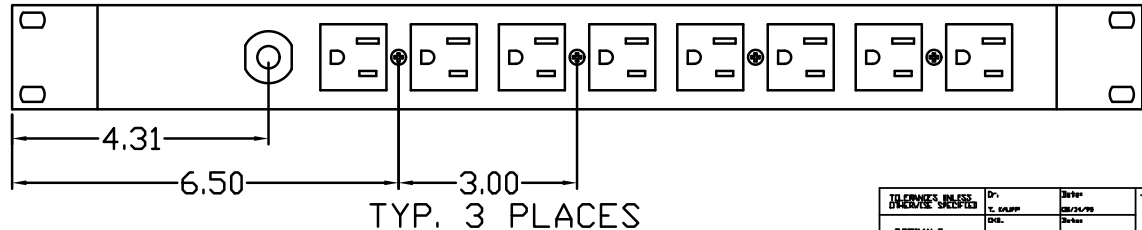


Part Number.....7219-SR14

Made in the USA..... No
 Mounting..... Rack Mount
 AC Rating Volts..... 125
 AC Rating Amps..... 15
 AC Rating Watts..... 1875
 AC Rating Frequency-Hz..... 50/60 HZ
 Circuit Breaker..... 15A
 Pilot Light..... None
 On/Off Switch..... None
 Over Current Protection..... CB
 Power Cable AWG..... 14/3 SJT
 Power Cable Length..... 15'
 Plug Type..... NEMA 5-15P
 Receptacle Type..... NEMA 5-15R
 Receptacle Style..... Single
 Receptacle Quantity..... 14 (6 front, 8 back)
 Max. Output per Powerstrip..... 15 Amp
 Joule Rating..... 600
 UL Rating..... 60950
 Clamping Level..... <330V
 Response Time..... <5 nanoseconds
 Max. Surge Current..... 24,000 Amp
 EMI/RFI Noise Reduction..... 60db
 Surge Indicator Red LED..... Yes
 Connected Equipment Warranty..... N/A
 Product Warranty-GLCC..... 1 year
 Certification/Agency Approvals..... UL & CSA Approved
 Unit Weight lbs..... 5

| Rev. | Date | Dr. | CHK/APP'D | Description |
|------|------|-----|-----------|-------------|
| | | | | |
| | | | | |

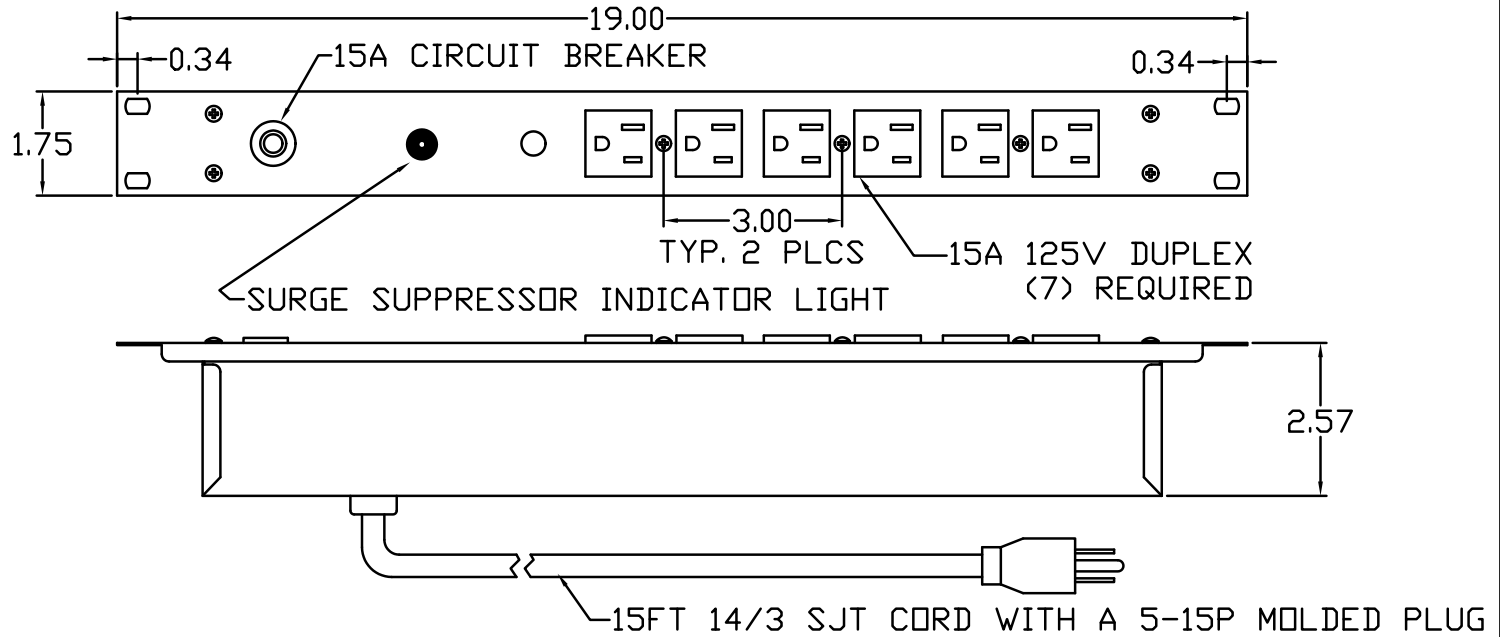

| | | |
|---|-------------------------------------|-------------------|
| UL POWER STRIP UNDERwriters Laboratories 3300 HALS 0.0 = ± 0.180 0.00 = ± 0.021 0.000 = ± 0.003 ANGLES = ± 1° | Dr. E. SHIPP Date 08/24/98 | Title 7219SR14 |
| DWG No. | Rev. -- | SHT 1 of 1 |
| Great Lakes CASE & CALHOUN CO., INC. | | DWG No. |