

AQU126 SERIES



Specifications:

- ANSI/UL 603 Listed
- UL 1418 Listed
- ULC-S527 Listed
- ULC-S318 Listed
- CAN/ULC-S533-M87 Listed
- CSA-C22.2 No.205 Listed
- ANSI/UL 294 Listed

Electrical:

- Available with up to eight (8) Class 2 power limited outputs
- Available with configurable access control input/outputs with fire trigger in either PTC or with fuse/dry contact option, fire relay only, or configurable outputs with fire relay input
- Universal input 90-240VAC
- LED indicators and form "C" contacts for supervision
- Supports up to two (2) sealed gel, AGM or wet lead acid batteries

Operating

Temperature:

-4° to +104° F
[-20° to +40° C]

Shipping Weight:


7.65lbs. [3.47 Kg.]

6 Amp / 12VDC Single Voltage

The Securitron AccuPower™ AQU126 Series of switching power supplies are single voltage, supervised units with a battery charger. These units provide 6 Amps at 12VDC, with up to eight (8) independently controlled, power limited outputs.

PRODUCT FEATURES

- Provides 6 Amp/12VDC continuous output
- Internal transformer included
- Tolerates brownout or overvoltage input from 60-260VAC
- Includes thermal shutdown protection with auto restart
- Circuit breaker protects against over current and reverse battery faults
- Low battery disconnect prevents deep discharge
- Dedicated voltage enables faster battery charging even under full load
- 14" x 9" x 3.5" enclosure
- MagnaCare Lifetime Replacement No Fault Warranty included

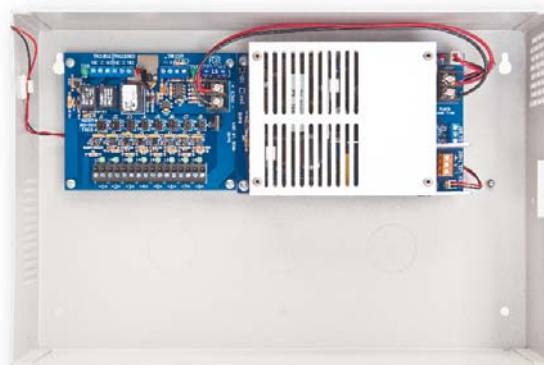

AQU126-8C1R

Product Number	Amps	Outputs	Class 2 Power Limited	Fuse Rating	Fuse Type	# of Relays	Relay Type	UL294	UL603	ULCS318-96
AQU126	6	1	N	N/A	N/A	-	-	Listed	Listed	Listed
AQU126-8C	6	8	Y	1.5A	PTC	-	-	Listed	Listed	Listed
AQU126-8C1R	6	8	Y	1.23A	PTC	1	Fire Relay	Recognized*	Recognized*	-
AQU126-8F8R	6	8	N	0.5A	Fuse	8	Access Control w/Fire	Recognized*	-	-
AQU126-8C8R	6	8	Y	1.04A	PTC	8	Access Control w/Fire	-	-	-

* UL recognized components

SECURITRON™
ASSA ABLOY

