

MODEL	A	B	C	D	DEPTH
PB	4.5	2.75	.625	1.375	3
NOTE: FASTENERS NOT SHOWN ALL DIMENSIONS IN INCHES.					

PUSH BUTTON - MODEL PB

Features

- Industrial grade 1-1/2" mushroom button
- 7 amp DPST contacts
- Waterproof NEMA 4 rated
- 12/24 VDC bi-color illumination
- Available in momentary or alternate
- Stainless steel single gang plate

Options

- **A** - Alternate
- **R** - Red button

Operating Temperature

-40 to 60C [-40 to 140F]

How to Order

Part

PB

PBA

PBR

Description

Mushroom Round Push Button 1-1/2" Single Gang

Mushroom Round Push Button 1-1/2" Single Gang Alternate


Mushroom Round Push Button 1-1/2" Single Gang Red

Tel 775.355.5625

Fax 775.355.5636

info@securitron.com

www.securitron.com

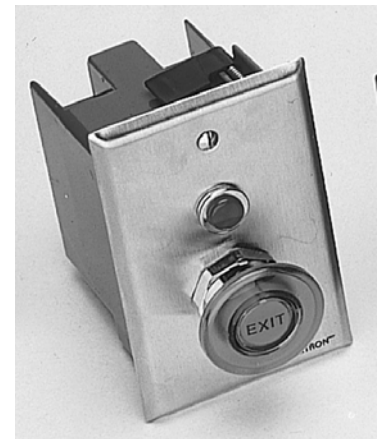

PUSH BUTTON - MODEL PB (cont'd)

Architectural Specification

- A. The Push Button shall be produced by an ISO 9001 certified manufacturer.
- B. The Push Button shall be an industrial grade 1.5" diameter mushroom button.
- C. The Button shall be labeled 'EXIT" and shall be green back lit using a multi-chip LED. A separate red LED shall be provided as an additional indicator.
- D. The LED's shall operate on 12 or 24 VDC (field selectable).
- E. The switch shall be DP/ST and rated at 7 Amps at 12 or 24 VDC.
- F. The push button shall be mounted on a Stainless Steel - 630/US32D single gang face-plate.
- G. The switch shall be available in either momentary or alternate action versions.