


1. **CSA Certified For:**
 - A. 302° F (150° C) maximum temperature rating
 - B. Stranded copper wire only
2. **Material:**
 - A. Stamping: .018" (0.46) thick tin plated brass
3. **Package quantity:**
 - A. Standard: -C = 100,
 - B. Bulk : -M = 1000,
4. **First insertion force:** 12 Lb (53 N) maximum
First withdrawal force: 12 Lb (53 N) maximum
6 Lb (27 N) minimum
5. **Dimensions in brackets are in millimeters or mm²**
6. **Installation tools:**
 - A. CSA Certified: CT-100
 - B. Panduit Approved: CT-200
7. **Wire Strip Length:** 9/32 ^{+1/32}₋₀ (7.1 ⁺⁸₋₀)

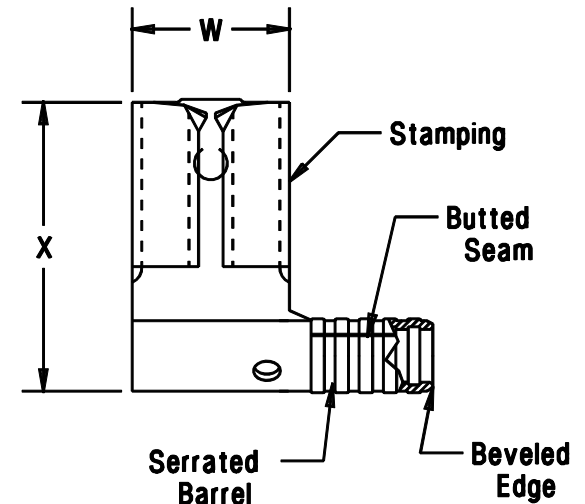

CERTIFIED
LR31212

A41326_04

								 PANDUIT CORP. TINLEY PARK, ILLINOIS			
04	1/01	RM		FILESPEC WAS N41326AA_PCD_03				Non-insulated right angle Butted Seam female disconnect, .250 X .032 Male Tab			
03	11-94	TH		Updated Notes and Dimensions	02680						
REV	DATE	BY	CHK	DESCRIPTION	ECN #	CUST	PM	DRAWN BY DAW	CHK'D	SCALE None	DRAWING NO. A41326