
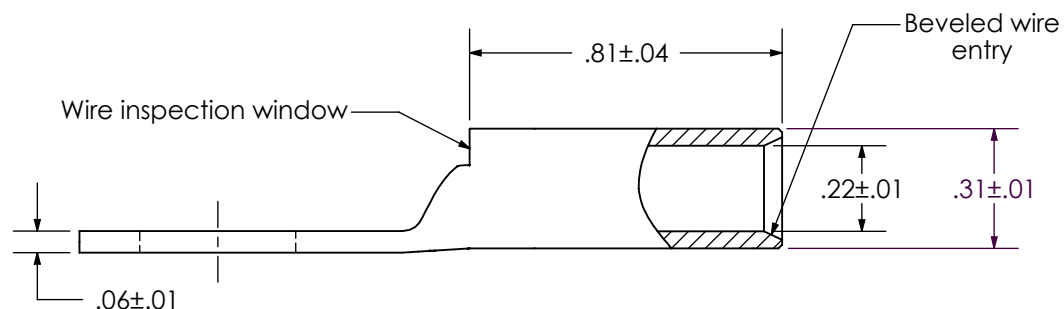



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	6 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	7/8 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P24
Alternate Industry Die Index No. ( ) on Barrel	(7)

LISTED  
Wire Connector

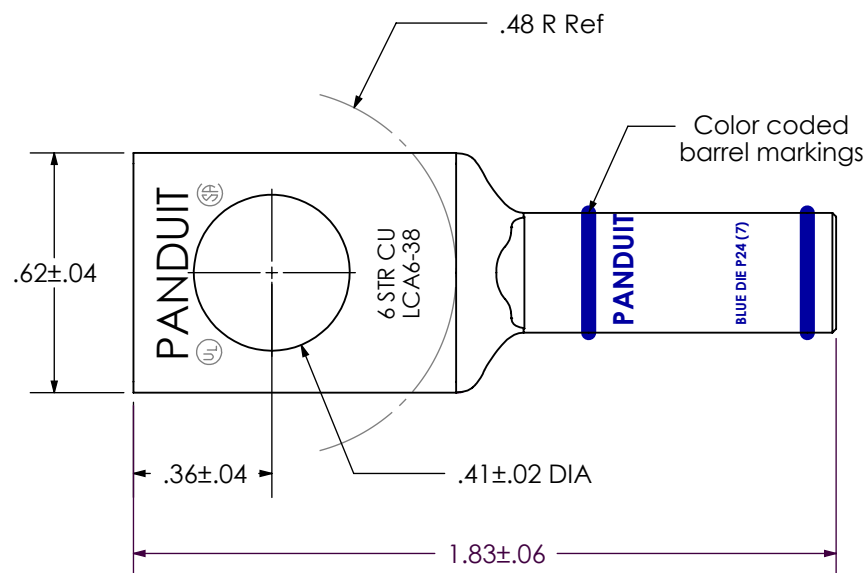

								 <b>PANDUIT CORP.</b> TINLEY PARK, ILLINOIS
01	3/12	JHNU	JHNU	REMOVED NAVY NUMBER FROM STAMP	N10881BN-LCA6-38-CUST	RGB	RGB	
<b>REV</b>	<b>DATE</b>	<b>BY</b>	<b>CHK</b>	<b>DESCRIPTION</b>	<b>ECN</b>	<b>BY</b>	<b>CHK</b>	SCALE N/A DRAWING NO / CAD FILE LCA6-38-CUST