




Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	600 kcmil
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-13/16 in.
Stud Size	7/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	GREEN
Panduit Die Index No. on Barrel	P94
Alternate Industry Die Index No. ( ) on Barrel	(22)

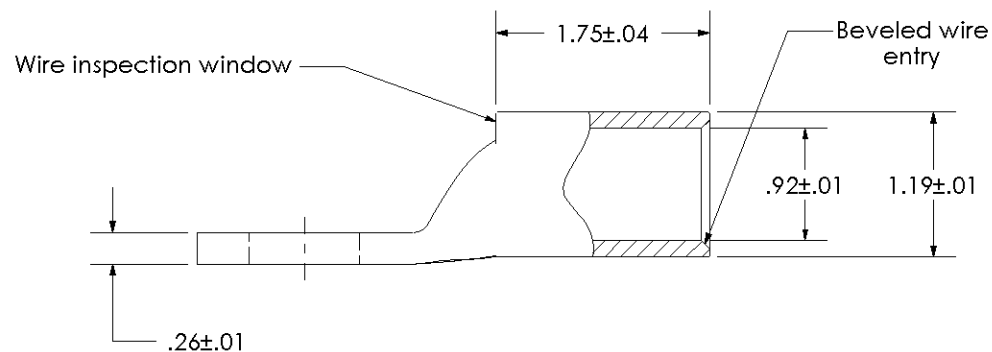

LISTED  
Wire Connector

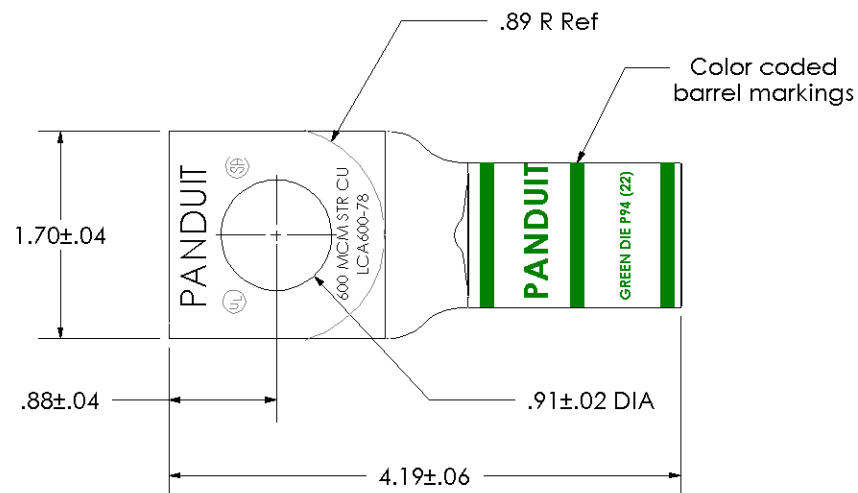

						 <b>PANDUIT CORP. TINLEY PARK, ILLINOIS</b>	
						LCA600-78-6 Copper Lug - One-Hole, Standard Barrel	
00	9/02	SAB	DRL	RELEASED	10318		
<b>REV</b>	<b>DATE</b>	<b>BY</b>	<b>CHK</b>	<b>DESCRIPTION</b>	<b>ECN</b>	<b>SCALE</b> N/A	<b>DRAWING NO / CAD FILE</b> LCA600-78-CUST