



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	6 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	7/8 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P24
Alternate Industry Die Index No. ( ) on Barrel	(7)

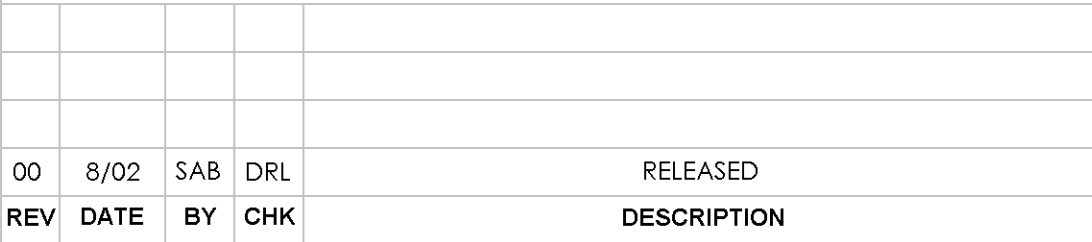

 <b>PANDUIT CORP. TINLEY PARK, ILLINOIS</b>	
<p style="text-align: center;">LCA6-14H-L</p> <p style="text-align: center;">Copper Lug - One-Hole, Standard Barrel, 45° Angle Tongue</p>	
<b>SCALE</b> N/A	<b>DRAWING NO / CAD FILE</b> LCA6-14H-CUST