



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	15/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P33
Alternate Industry Die Index No. () on Barrel	(10)

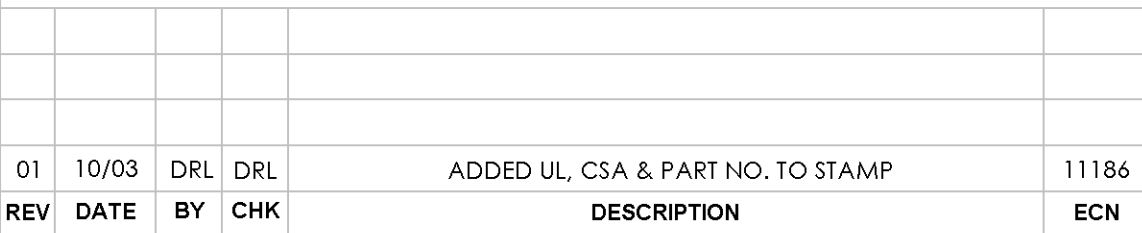

Technical drawing of a wire probe assembly. The drawing shows a rectangular body with a circular feature on the left and a circular feature on the right. The left circular feature is labeled "PANDUIT" and "2 STR CU LCD2-38DF". The right circular feature is labeled ".41±.02 DIA (2) PLS". The drawing includes dimensions: .66±.04 for the height of the body, .39±.04 for the distance from the left edge to the center of the left circular feature, and 1.00±.02 for the distance between the centers of the two circular features. A label "Wire inspection window" points to a feature on the right side of the body.

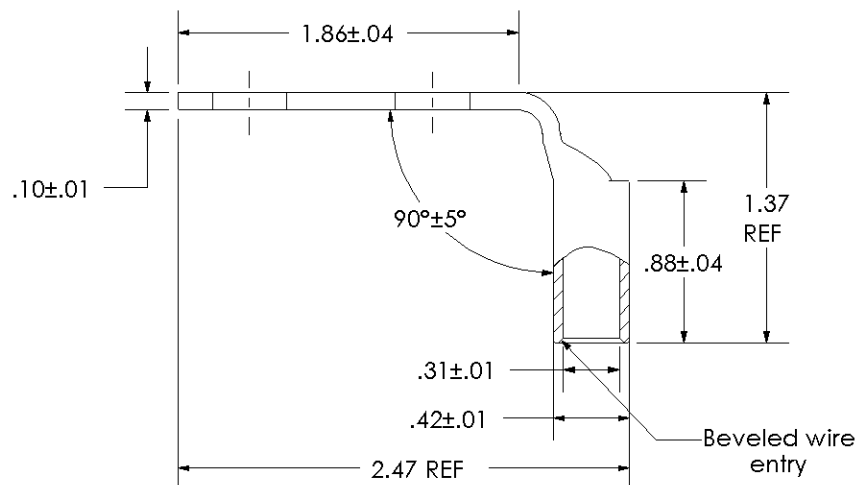

PANDUIT CORP. TINLEY PARK, ILLINOIS

LCD2-38DF-Q
Copper Lug - Two-Hole, Standard Barrel, 90° Angle Tongue

SCALE N/A	DRAWING NO / CAD FILE LCD2-38DF-CUST
---------------------	--