


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	15/16 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90 ° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P33
Alternate Industry Die Index No. () on Barrel	(10)

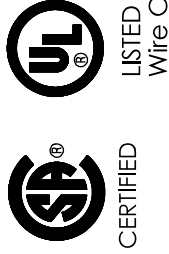

												PANDUIT CORP.	TINLEY PARK, ILLINOIS
												LCDN2-14A-Q	Copper Lug - Narrow Tongue, Two-Hole, Standard Barrel
												SCALE N/A	DRAWING NO / CAD FILE LCDN2-14A-CUST
02	11/08	DRL	DRL		TONGUE THICKNESS WAS .11±.01								
REV	DATE	BY	CHK		DESCRIPTION					ECN			