


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2 STR/FLEX
Wire Type	Stranded Copper: Class B & C, Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	11/16 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P33
Alternate Industry Die Index No. () on Barrel	(10)



Technical drawing of a Panduit LCAX2-14F connector. The drawing shows a side view of the connector with dimensions and labels. The main body is rectangular with a circular port on the left. The port has a diameter of .27±.02 DIA. The main body has a height of .70±.04 and a width of .25±.04. The port is labeled 'PANDUIT' and '2 STR/FLEX LCAX2-14F'. A 'Wire inspection window' is indicated on the right side of the connector.

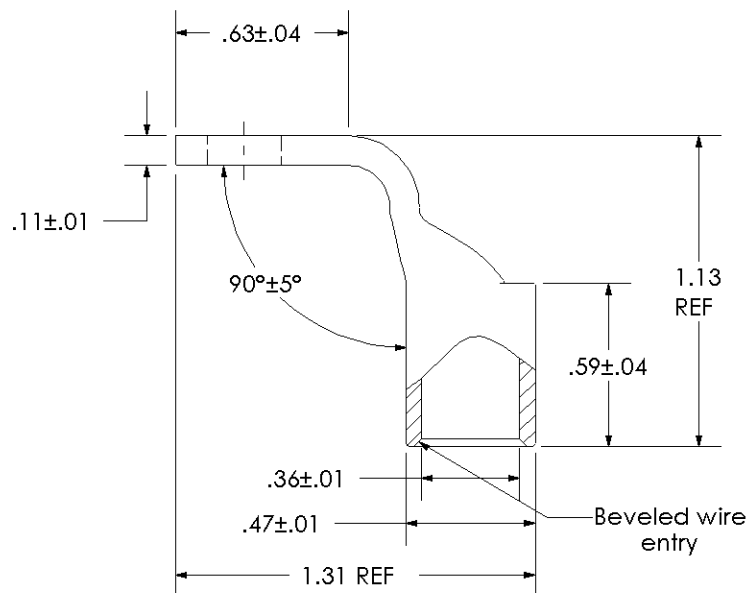

00	6/03	CJW	SAC	RELEASED	10850
REV	DATE	BY	CHK	DESCRIPTION	ECN

SCALE	N/A
-------	-----

DRAWING NO / CAD FILE

LCAX2-14F-CUST