


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2/0 STR/FLEX
Wire Type	Stranded Copper: Class B & C Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	1-9/16 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLACK
Panduit Die Index No. on Barrel	P45
Alternate Industry Die Index No. () on Barrel	(13)



Technical drawing of a Panduit LCCX2/0-14B cable connector. The drawing shows a side view of the connector with various dimensions and labels. Key features include:

- Overall length: $3.39 \pm .06$
- Main body height: $.96 \pm .04$
- Neck height: $.35 \pm .04$
- Distance from left edge to hole center: $.75 \pm .02$
- Hole diameter: $.27 \pm .02$ DIA (2) PLS
- Neck markings: PANDUIT, BLACK DIE P45 (13)
- Color coded barrel markings
- R.43 REF

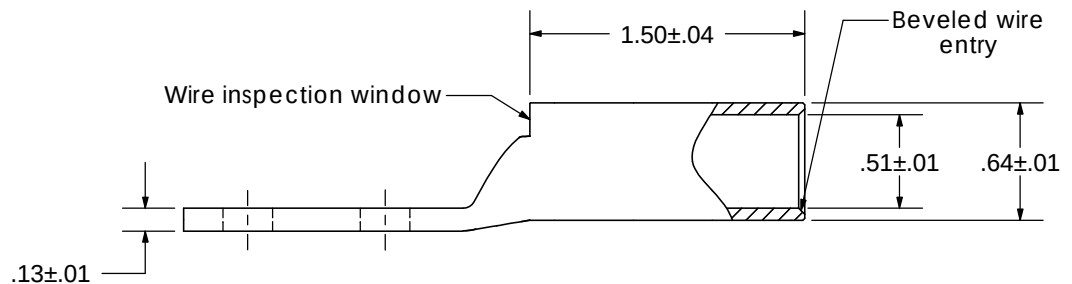

						 PANDUIT CORP. TINLEY PARK, ILLINOIS	
						LCCX2/0-14B-X Copper Lug - Two-Hole, Long Flex Barrel with Window	
00	6/03	SAC	SAC	RELEASED	10850		
REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCCX2 0-14B-CUST