

PANDUIT PART NUMBER	WEIGHT
DPA24688TGY	1.26 lb (1070.48 g)

1. SEE CURRENT CATALOG FOR VARIOUS APPLICATIONS AS WELL AS OPTIONAL ICONS.

2 MATERIALS •

PANEL HOUSING: STEEL
RJ45 MODULES: THERMOPLASTIC RESIN
UL94V-0

PUNCHDOWN BLOCKS: THERMOPLASTIC
RESIN UL94V-0
BEZEL ASSEMBLY: THERMOPLASTIC RESIN
UL94H-B

RETENTION CAP:

3. 24 PORT ANGLED PATCH PANEL 8 POSITION
THERMOPLASTIC RESIN UL94V-0
R WIRE.



4. THE PATCH PANEL IS DESIGNED FOR MOUNTING TO 19" UNIVERSAL RACKS

5. FOUR (4) 12-24 X 1/2" ROUND HEAD SCREWS AND (4) M6x1x15MM METRIC SCREWS ARE PROVIDED FOR FASTENING TO RACKS.

6. DIMENSIONS IN BRACKETS ARE IN METRIC.

7. USE I10 STYLE TERMINATION TOOL FOR PUNCHDOWN.

8. RETENTION CAPS (ONE PER CONNECTOR) PROVIDED FOR SNAP-1 CONNECTORS.

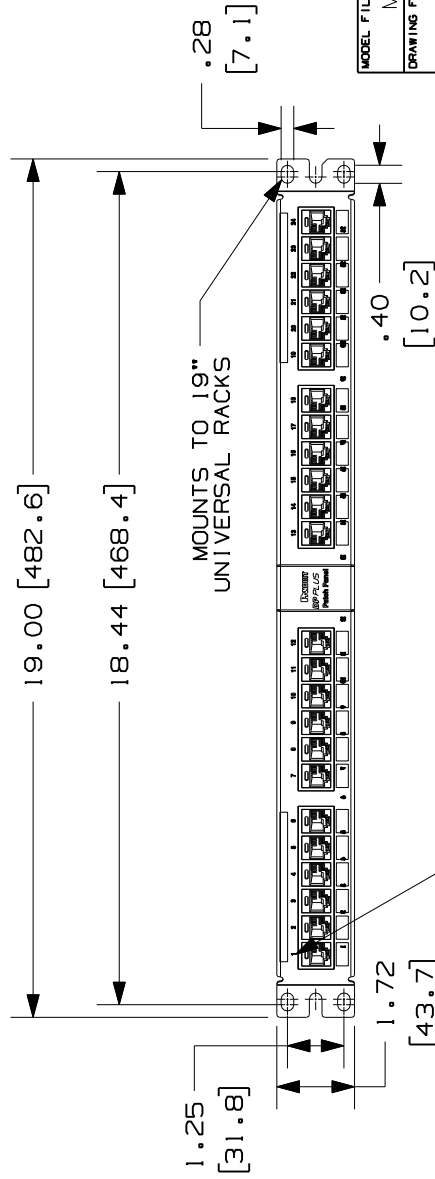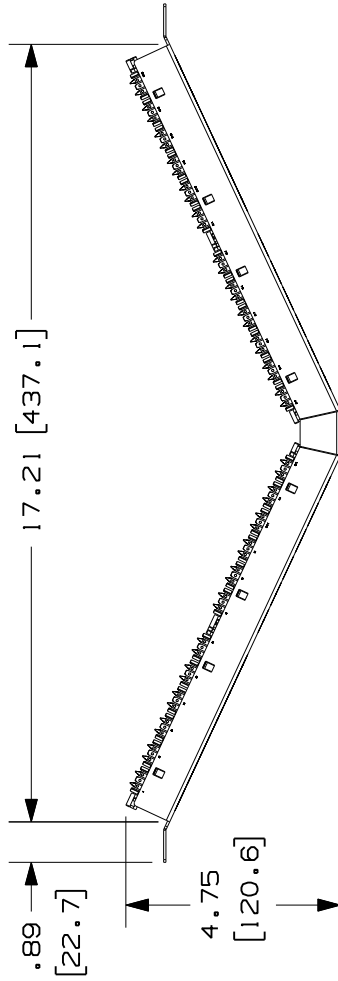

CID**-C & CIP**-C, PHONE OR DATA ICON LOCATES HERE. IDENTIFIES INDIVIDUAL PORT. OPTIONAL. NOT SUPPLIED.

[illegible]