


NOTES:

1. SEE CURRENT CATALOG FOR VARIOUS APPLICATIONS AND TO INDICATE PACKAGE QUANTITY.
2. 110 CONNECTORS ON BOTH ENDS. THE PATCH CORDS CAN BE USED WITH PAN-PUNCH™ 110 CONNECTING BLOCKS.
3. FEATURES INCLUDE A CLEAR CAP TO ENSURE PROPER WIRE SEQUENCE AND CONNECTOR ORIENTATION, RETAINING CLIPS SECURE THE JACKET CLOSE TO THE POINT OF TERMINATION WHICH MINIMIZES WIRE UNWISTING.
4. INTEGRAL STRAIN RELIEF MINIMIZES STRESS ON WIRES DURING DISCONNECTION.
5. POLARIZED TO PREVENT REVERSE INSTALLATION TO CONNECTOR BLOCK.
6. CATEGORY 5e UNSHIELDED TWISTED PAIR CABLE WITH 24AWG STRANDED TINNED COPPER CONDUCTORS.
7. DIMENSIONS IN PARENTHESES ARE IN METRIC.

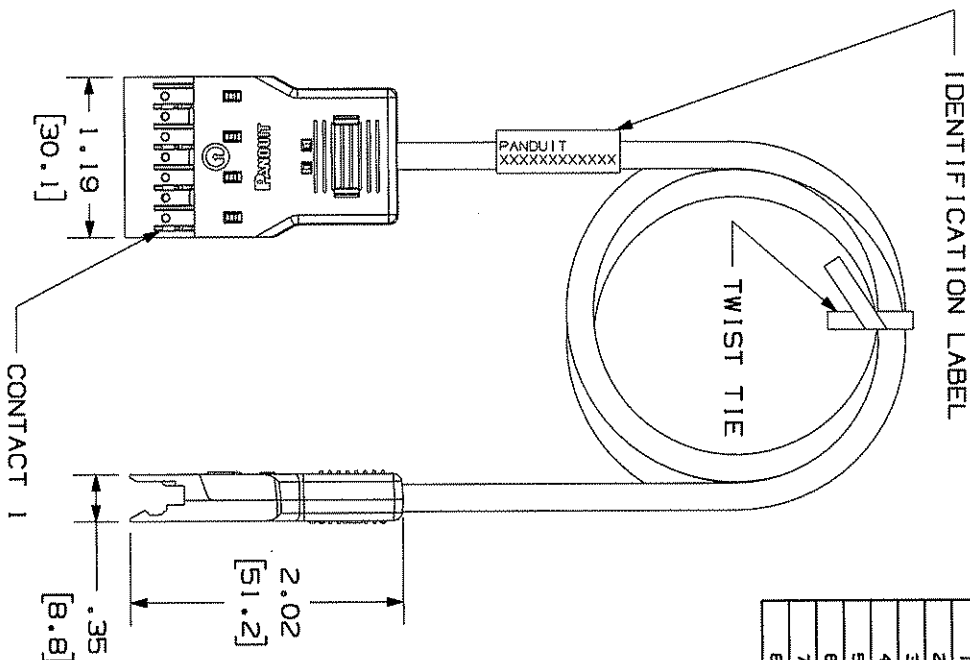

CONTACT	WIRE COLOR
1	WHITE/BLUE
2	BLUE
3	WHITE/ORANGE
4	ORANGE
5	WHITE/GREEN
6	GREEN
7	WHITE/BROWN
8	BROWN

PANOUT P/N	MIN. CABLE LENGTH	WEIGHT
P110FC41G2Y	2 FT.	.83 LB./ 10 PCS 1376.5 g./ 10PCS
P110FC41G3Y	3 FT.	1.05 LB./ 10 PCS 1478.3 g./ 10PCS
P110FC41G4Y	4 FT.	1.25 LB./ 10 PCS 1563.9 g./ 10PCS
P110FC41G5Y	5 FT.	1.46 LB./ 10 PCS 1662.2 g./ 10PCS
P110FC41G6Y	6 FT.	1.67 LB./ 10 PCS 1751.5 g./ 10PCS
P110FC41G7Y	7 FT.	1.88 LB./ 10 PCS 1852.8 g./ 10PCS
P110FC41G8Y	8 FT.	2.08 LB./ 10 PCS 1948.0 g./ 10PCS
P110FC41G9Y	9 FT.	2.30 LB./ 10 PCS 1943.3 g./ 10PCS
P110FC41G12Y	12 FT.	2.83 LB./ 10 PCS 1328.0 g./ 10PCS
P110FC41G15Y	15 FT.	3.56 LB./ 10 PCS 1161.4 g./ 10PCS
P110FC41G18Y	18 FT.	4.19 LB./ 10 PCS 1790.6 g./ 10PCS
P110FC41G..5MY	.5M	7.75 LB./ 10 PCS 1342.0 g./ 10PCS
P110FC41G1..MY	1M	1.09 LB./ 10 PCS 1489.4 g./ 10PCS
P110FC41G1..5MY	1.5M	1.44 LB./ 10 PCS 1655.2 g./ 10PCS
P110FC41G2..MY	2M	1.78 LB./ 10 PCS 1807.4 g./ 10PCS
P110FC41G3..MY	3M	2.48 LB./ 10 PCS 1120.4 g./ 10PCS
P110FC41G6..MY	6M	3.85 LB./ 10 PCS 1748.1 g./ 10PCS

[illegible]

DRAWING FILENAME M02479JS_DC255_00A.PRT	SIZE A
TITLE CATEGORY 5e 110 PATCHCORD CUSTOMER DRAWING	