


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
CP24WS**Y	11.15 LB/10 PCS (5076.3 g/10 PCS)

NOTES:

- SEE CURRENT CATALOG FOR VARIOUS APPLICATIONS WITH THIS WIRING SYSTEM.
- THE HIGH DENSITY PATCH PANEL IS DESIGNED FOR MOUNTING TO 19" UNIVERSAL RACKS.
- PACKAGE CONTENTS:

- CP24WSBLY:
 - 24 PORT STAMPING
 - CABLE TIE
 - SCREW KIT (INCLUDES FOUR #12-24 SCREWS AND FOUR LOCK WASHERS)
 - SCREW KIT (INCLUDES FOUR M6 SCREWS)
 - REMOVAL TOOL (CPT)
- CP24WSLGY AND CP24WSSTGY:
 - 24 PORT STAMPING
 - CABLE TIE
 - SCREW KIT (INCLUDES FOUR M6 SCREWS, CAGE NUTS, AND WASHERS)
- REMOVAL TOOL (CPT)
- PATCH PANELS ACCEPT SNAP-IN MINI-COM MODULES.
- DIMENSIONS IN PARENTHESIS ARE IN METRIC.

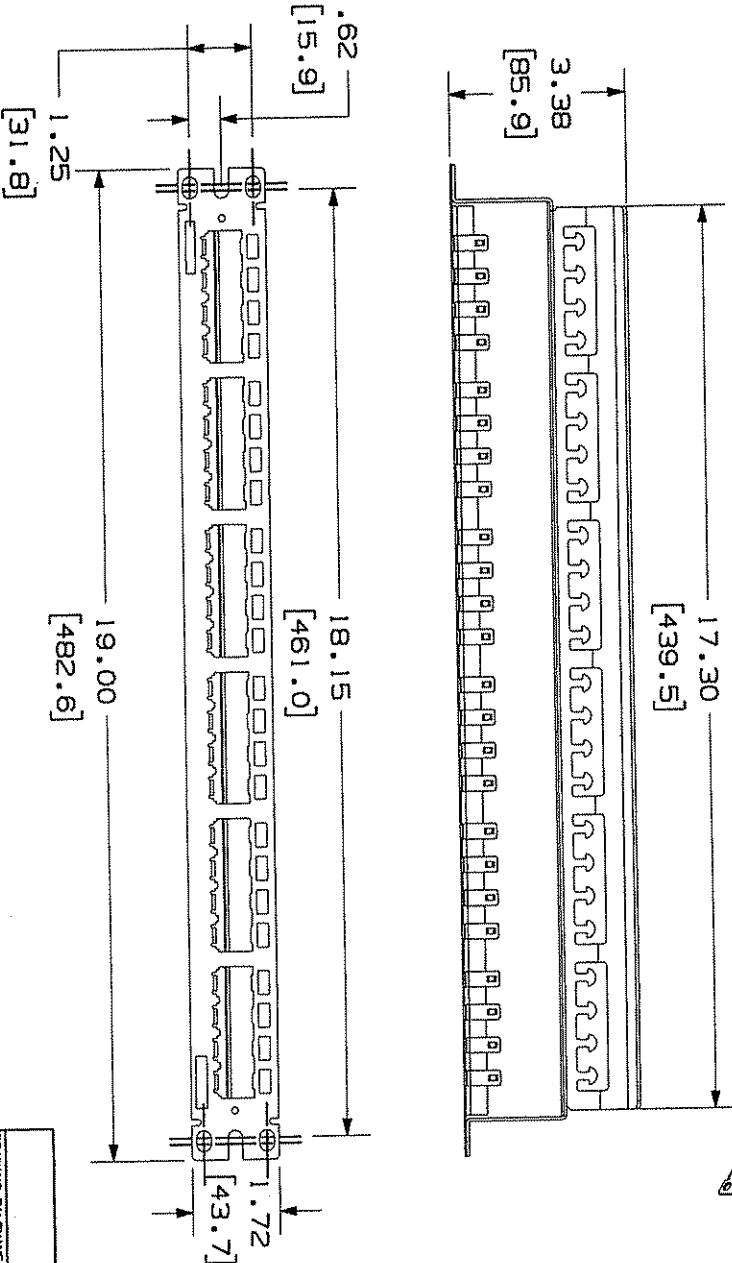

DRAWING FILENAME

MO2479CM-DC66-00A.PRT

SIZE
A

MINI-COM 24 PORT ALL METAL MODULAR
PATCH PANEL WITH SUPPORT BAR
CUSTOMER DRAWING



1.1. NUMBER
N/A

PRODUCT SPEC
N/A

WORK INSTRUCTION
N/A

SCALE
NONE

PART NO.
CP24WS**Y

DRAWING NO.
02479-066

PANEL - SS
STRAIN RELIEF - CRS

REV	DATE	BY	CHK	DESCRIPTION	ECN	R	CUST	SUP	OTH
R	4-19-06	JSP		RELEASED TO PRODUCTION	02479-066				