

ProxCard® II Card

125 kHz Proximity

Durable, Value Priced Proximity Access Card • I326



ACCESS reliability.

Application

The RF-programmable ProxCard® II proximity access card is the industry choice for a cost-effective solution to proximity access control.

Features

- ▶ Offers universal compatibility with all HID proximity readers.
- ▶ Provides durable packaging and consistent read range.
- ▶ Provides an external number for easy identification and control.
- ▶ Supports formats up to 85 bits, with over 137 billion codes.
- ▶ Custom pre-printed artwork available.
- ▶ A PVC overlay allows for on-site photo ID using most direct image printers.
- ▶ Using HID's ProxProgrammer®, card vendors can ship ProxCard II proximity cards, custom programmed to their customers' requirements, from their own inventory. Enables smaller order quantities and overnight delivery. (Check with vendor for availability.)

Features

Specifications

Proven, Reliable Technology

Offers extremely consistent read range. Unaffected by body shielding or variable environmental conditions, even when close to keys and coins.

Convenient To Use

Can fit into a wallet or purse. Use with a strap and clip as a photo ID badge.

Cross-reference

A cross-reference list correlating the external card number and the programmed ID number is provided for easy system administration.

Security

Offers over 137 billion unique codes.

Long Life

Passive, no-battery design allows for an infinite number of reads.

Durability

Strong, flexible and resistant to cracking and breaking.

Companion Products:

1321 Photo pouch overlay
1324 PVC Direct print overlay

Warranty

Lifetime warranty against defects in materials and workmanship (see complete sales policy for details).

Typical Maximum* Read Range

ProxPoint® Plus reader-up to 3" (7.5 cm)
MiniProx® reader-up to 5.5" (14 cm)
ThinLine® II reader-up to 5.5" (14 cm)
ProxPro® reader-up to 8" (20 cm)
ProxPro® II reader-up to 9" (22.9 cm)
Prox80™-up to 5.5" (14 cm)
MaxiProx® reader-up to 24" (60 cm)

*Dependent on local installation conditions.

Dimensions

2.135" x 3.385" x 0.075" MAX.
(5.4 x 8.6 x 0.19 cm)

Operating Temperature

-50° to 160° F (-45° to 70° C)

Weight

0.24 oz. (6.8 gm)

Part Number

Base Part No.: 1326


Description

RF-programmable, 125 kHz, HID artwork, customer-specified ID numbers, vertical slot punch.

Options

- External card numbering (inkjet only; no laser engraving)
- Custom artwork (text or graphics)

(Please see "How to Order Guide" for a description of the options and associated part numbers.)

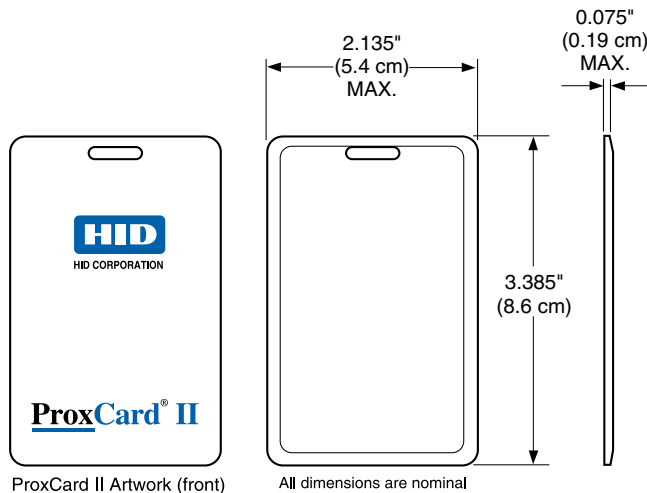

ACCESS experience.

HID Global Offices:

 
Corporate North America
9292 Jeronimo Road
Irvine, CA 92618-1905
U.S.A.
Phone: (800) 237-7769
Phone: (949) 598-1600
Fax: (949) 598-1690

Asia Pacific
19/F 625 King's Road
North Point
Island East
Hong Kong
Phone: +852 3160-9800
Fax: +852 3160-4809

Latin America
Circunvalacion Ote. #201 B
Despacho 2
Col. Jardines del Moral
Leon 37160, Gto.
Mexico
Phone: +52 477 779 1492
Fax: +52 477 779 1493

Europe, Middle East & Africa
Homefield Road
Haverhill, Suffolk
CB9 8QP
England
Phone: +44 (0) 1440 714 850
Fax: +44 (0) 1440 714 840

© 2007 HID Global. All rights reserved. HID, and the HID logo are trademarks or registered trademarks of HID Global in the U.S. and/or other countries. All other trademarks, service marks, and product or service names are trademarks or registered trademarks of their respective owners. Rev. 4/2007



For best results, please print on recycled paper.

MKT-PROXCARDii_DS_EN

hidcorp.com